

CADDY PYRAMID

Rooftop Support System



- Protects roof membranes
- Superior load distribution
- Broad range of applications
- Fast and easy to install



CADDY SPEED LINK




CADDY SPEED LINK

CADDY SPEED LINK

CADDY SPEED LINK SLK Locking Device

- Push/pull keyless release allows easy adjustments
- Suitable for 1.5 mm and 2 mm CADDY SPEED LINK cable
- Low-profile locking device minimizes visual impact
- Cable spread of 90 degrees allows positioning the device closer to the load
- Keyless release tubes are easy to operate while wearing gloves
- Double-sided locking mechanism enables simple height adjustment

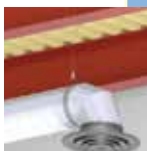

Patent Pending

Material: Steel; Polypropylene; Zinc Alloy

Part Number	Description
SLK2C200	1.5–2 mm Wire

Locking device is only to be used with SLC15L50MSP, SLC15L1000SP and SLC2L1000SP wire spools or 1.5 mm and 2 mm CADDY SPEED LINK accessories. Do not use with any other wires.

CADDY SPEED LINK SLK with Angle Bracket

- Complete system includes wire, locking device and pre-assembled angle bracket end fitting
- Ideal for attaching to concrete, steel or wood surfaces
- Simple alternative to jack chain and additional hardware



Patent Pending

Material: Steel; Zinc Alloy; Polypropylene
Finish: Electrogalvanized
Static Load Safety Factor: 5:1



Part Number	Description	F ↓
Wire Rope Diameter: 1.5 mm		
SLK15L1AB	1.5 mm Wire, 3.3' Length	44 lb
SLK15L2AB	1.5 mm Wire, 6.6' Length	44 lb
SLK15L3AB	1.5 mm Wire, 9.9' Length	44 lb
SLK15L5AB	1.5 mm Wire, 16.4' Length	44 lb
Wire Rope Diameter: 2.0 mm		
SLK2L2AB	2 mm Wire, 6.6' Length	100 lb
SLK2L3AB	2 mm Wire, 9.9' Length	100 lb
SLK2L5AB	2 mm Wire, 16.4' Length	100 lb

CADDY SPEED LINK

