

Weatherproof junction boxes

- Quick Features :**
- Seamless welding
 - Slip-on screw cover
 - Powder coated



Visit
www.eurobex.com
for details.


Call us
toll free
1-800-363-2423

The 1300 are used as junction boxes in outdoor installations or indoors where dripping water is a problem. These enclosures are designed to protect equipment against rain, sleet and snow. Enclosures are made from 14 GA or 16 GA steel. The top of the


enclosure serves as a dripshield and the continuously welded seams prevent rain, sleet and snow from entering. Knockouts are provided on the bottom only. The cover slips on and is fastened by screws. Four internal mounting holes are provided.

Enclosures are finished with heat fused polyester powder, electrostatically applied on a phosphatized base. Box is ANSI/ASA 61 gray (other colors available).

CSA Certified / UL Listed
NEMA 3R / IP22

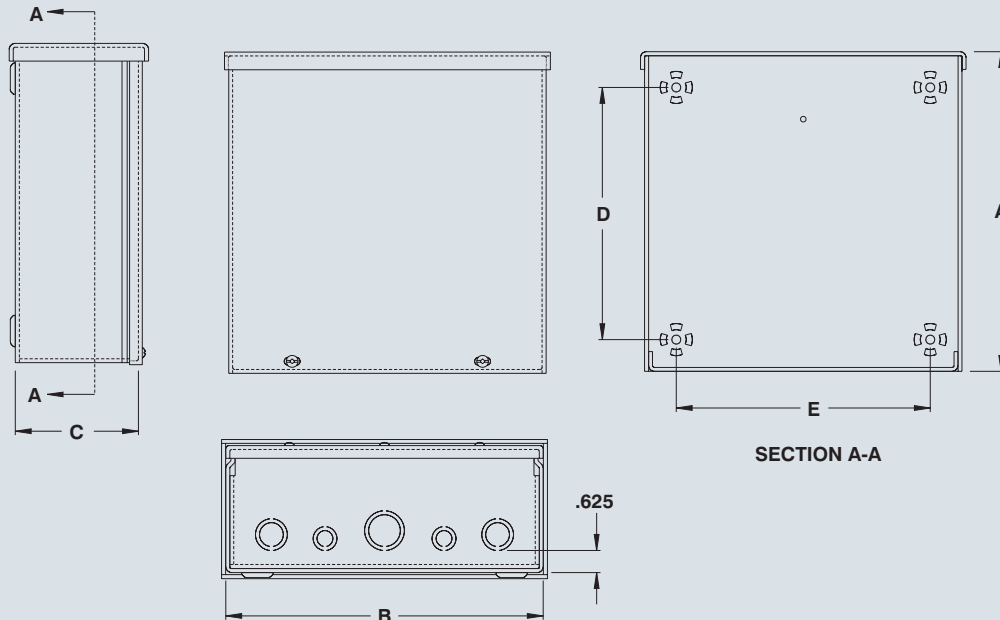

CATALOG NUMBER	DIMENSIONS					KNOCKOUT PATTERN	SHIP WGHT LBS.
	A	B	C	D	E		
1300 060603	6	6	3	4	4	2-3-4	3
1300 060604	6	6	4	4	4	2-3-4	4
1300 080604	8	6	4	6	4	2-3-4	5
1300 080804	8	8	4	6	6	6-7-8-9	6
1300 100804	10	8	4	8	6	6-7-8-9	7
1300 101004	10	10	4	8	8	3-4-5-6-7	8
1300 120804	12	8	4	10	6	6-7-8-9	7
1300 121204	12	12	4	10	10	3-4-5-6-7	10
1300 151204	15	12	4	13	10	3-4-5-6-7	12
1300 080806	8	8	6	6	6	6-7-8-9	7
1300 100806	10	8	6	8	6	6-7-8-9	8
1300 101006	10	10	6	8	8	3-4-5-6-7	9
1300 120806	12	8	6	10	6	6-7-8-9	9
1300 121006	12	10	6	10	8	3-4-5-6-7	10
1300 121206	12	12	6	10	10	3-4-5-6-7	12
1300 151206	15	12	6	13	10	3-4-5-6-7	14
1300 181206	18	12	6	16	10	3-4-5-6-7	16
1300 181506	18	15	6	16	13	2-3-4-5-6-7-8	22
1300 181806	18	18	6	16	16	1-2-3-4-5-6-7-8-9	24
1300 241806	24	18	6	22	16	1-2-3-4-5-6-7-8-9	31

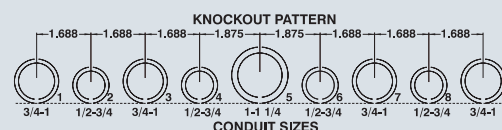

Data subject to
change without
notice.

Suggested Accessories



p.369



p.369



p.368