


STRAIGHT BLADE RECEPTACLES

Specification Grade Decorator & Combination Receptacles 15 & 20A, 125 & 250V; 20A, 120/125VAC

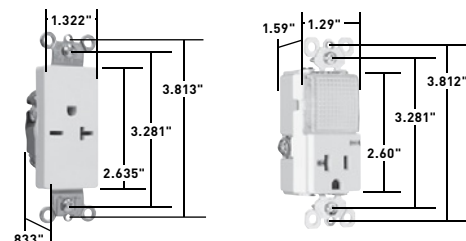

26861LA

PS8HWLLA


Features

- Corrosion-resistant, plated wraparound steel strap locked into assembly to prohibit strap from bending away from body.
- One-piece, brass, triple-wipe power contacts for lasting retention.
- Heavy-duty compact design for easier installation and long lasting performance.
- Easily accessed break-off, line-contact connecting tab for fast, easy split-circuit wiring.
- Impact-resistant nylon face.
- Terminal compartments isolated from each other for positive conductor containment.
- Side and internal screw-pressure-plate back wire accepts #14 – #10 AWG solid or stranded wire.
- All devices fit standard #26 opening wall plate.
- Tri-drive terminal and mounting screws.
- Auto-ground clip assures positive ground.

CATALOG NUMBER	RATING		COLOR	NEMA CONFIG. NO.	3rd PARTY COMPLIANCE		
	A.	V.				FSUL	cUL/CSA
					UL498	WC596	
HEAVY-DUTY SPECIFICATION GRADE SINGLE RECEPTACLES BACK & SIDE WIRE							
26661I	15	250	Ivory	6-15R	•	•	•
26661W	15	250	White	6-15R	•	•	•
26661GRY	15	250	Gray	6-15R	•	•	•
26661BK	15	250	Black	6-15R	•	•	•
26861I	20	250	Ivory	6-20R	•	•	
26861W	20	250	White	6-20R	•	•	
26861	20	250	Brown	6-20R	•	•	
26861GRY	20	250	Gray	6-20R	•	•	
26861BK	20	250	Black	6-20R	•	•	
26861LA	20	250	Light Almond	6-20R	•	•	

Features

 - Impact-resistant face and body.
- GE Lexan™ high impact-resistant lens.
- External screw-pressure-plate back and side wired. Accepts #12 and #14 AWG.
- Ground screw position under the end of the strap minimizes the risk of contact.
- Energy-efficient LED has average 20-year life expectancy: eliminates bulb replacement.
- Sensor automatically turns light ON in the dark.
- Increased light output for better illumination.
- Light sensor for enhanced sensitivity.

CATALOG NUMBER	RATING		LIGHT OUTPUT IN 1' FCD*	COLOR	NEMA CONFIG. NO.	3rd PARTY COMPLIANCE
	A.	VAC				 UL498
SPECIFICATION GRADE DECORATOR HALLWAY LIGHT & SINGLE RECEPTACLE						
PS8HWLI	20	120/125	0.2561	Ivory	5-20R	•
PS8HWLW	20	120/125	0.2561	White	5-20R	•
PS8HWLLA	20	120/125	0.2561	Light Almond	5-20R	•

*FCD = Foot Candle Distance. 1 Lumen = 1 FCD. See Page R-68 for more information.

For Bulk Packaging Solutions consult factory.

2 Pole, 3 Wire



NEMA 5-20R



NEMA 6-15R




NEMA 6-20R

DEVICES & WALL PLATES

Color Selection Chart

Devices & Plastic Wall Plate Colors

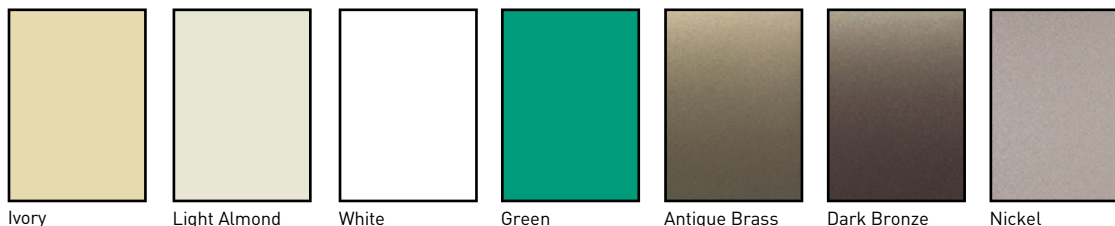

Ivory

Light Almond


White

Green

Antique Brass

Dark Bronze

Nickel

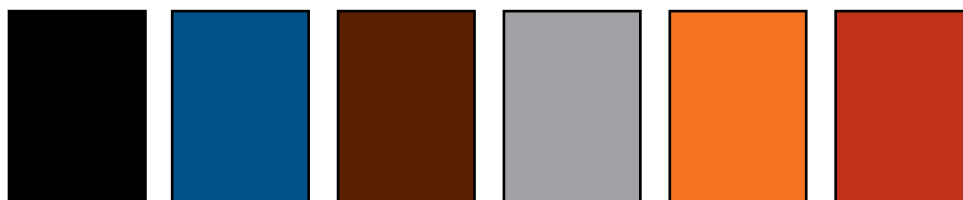

Black

Blue

Brown

Gray


Orange

Red

See specific device and wall plate catalog charts for particular color availabilities.

Metal Wall Plates

Metal Finish

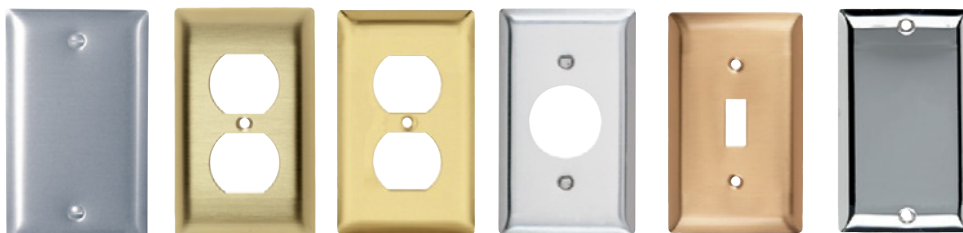

Aluminum

Brass (Brushed)

Polished Brass


Stainless Steel

Brushed Bronze

Chrome

Custom Metal Wall Plates Paint Finish Colors

Paint Color

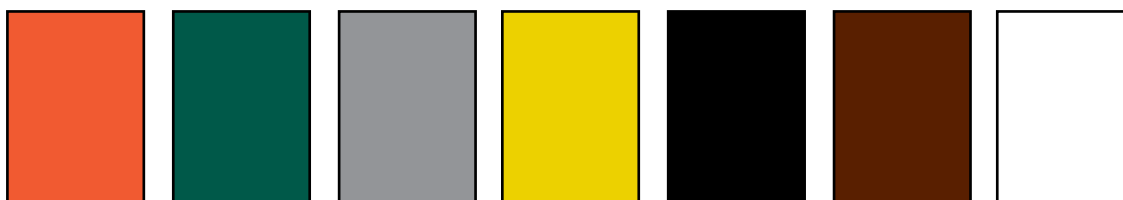

Orange

Green


Gray

Yellow

Glossy Black

Brown

White

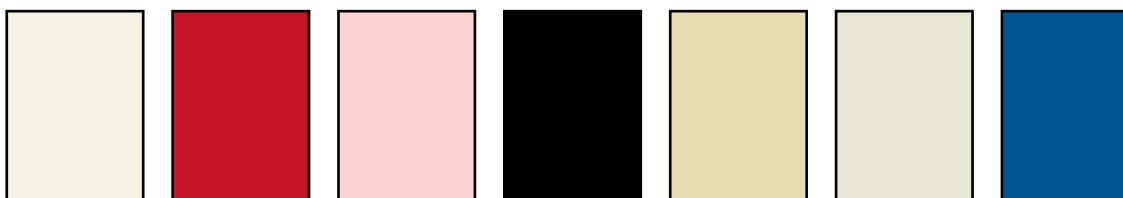

Primer

Red

Pink

Flat Black

Ivory

Light Almond

Blue

To order custom metal wall plates, see Pages P-40 – P-44.

For additional colors consult factory.