


## 4-11/16 in. Square Boxes


### Conduit Knockouts

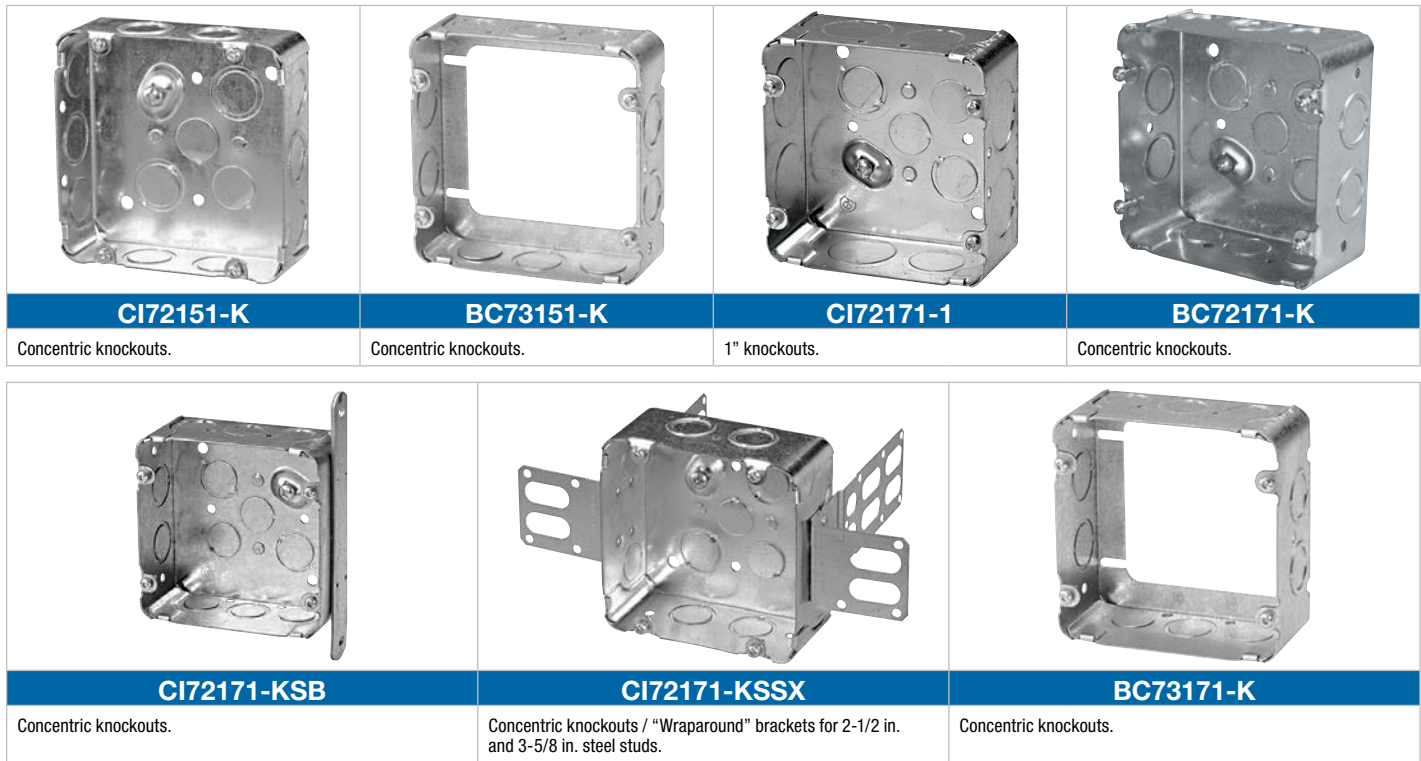

| Cat. No.              | Volume (Cu. in.) | Features |                     | Knockouts     |                |               |                |             |
|-----------------------|------------------|----------|---------------------|---------------|----------------|---------------|----------------|-------------|
|                       |                  | Bracket  | Raised Ground Screw | 1/2 in. sides | 1/2 in. bottom | 3/4 in. sides | 3/4 in. bottom | 1 in. sides |
| <b>1-1/2 in. Deep</b> |                  |          |                     |               |                |               |                |             |
| <b>CI72151-K</b>      | 30.0             | -        | yes                 | 10            | 4              | 6             | 2              | -           |
| <b>BC73151-K</b>      | 30.0             | -        | -                   | 10            | -              | 6             | -              | -           |
| <b>2-1/8 in. Deep</b> |                  |          |                     |               |                |               |                |             |
| <b>CI72171-1</b>      | 42.0             | -        | yes                 | -             | 4              | 2             | 2              | 6           |
| <b>BC72171-K</b>      | 42.0             | -        | yes                 | 10            | 4              | 6             | 2              | -           |
| <b>CI72171-KSB</b>    | 42.0             | "SB"     | yes                 | 8             | 4              | 2             | 2              | -           |
| <b>CI72171-KSSX</b>   | 42.0             | "SSX"    | yes                 | 4             | 4              | 4             | 2              | -           |
| <b>CI72171-1-SSX</b>  | 42.0             | "SSX"    | yes                 | -             | 4              | 2             | 2              | 4           |
| <b>BC73171-K</b>      | 42.0             | -        | -                   | 10            | -              | 6             | -              | -           |

## Steel Stud Boxes

### 4 in. and 4-11/16 in. Square Boxes and 4 in. Octagonal Boxes

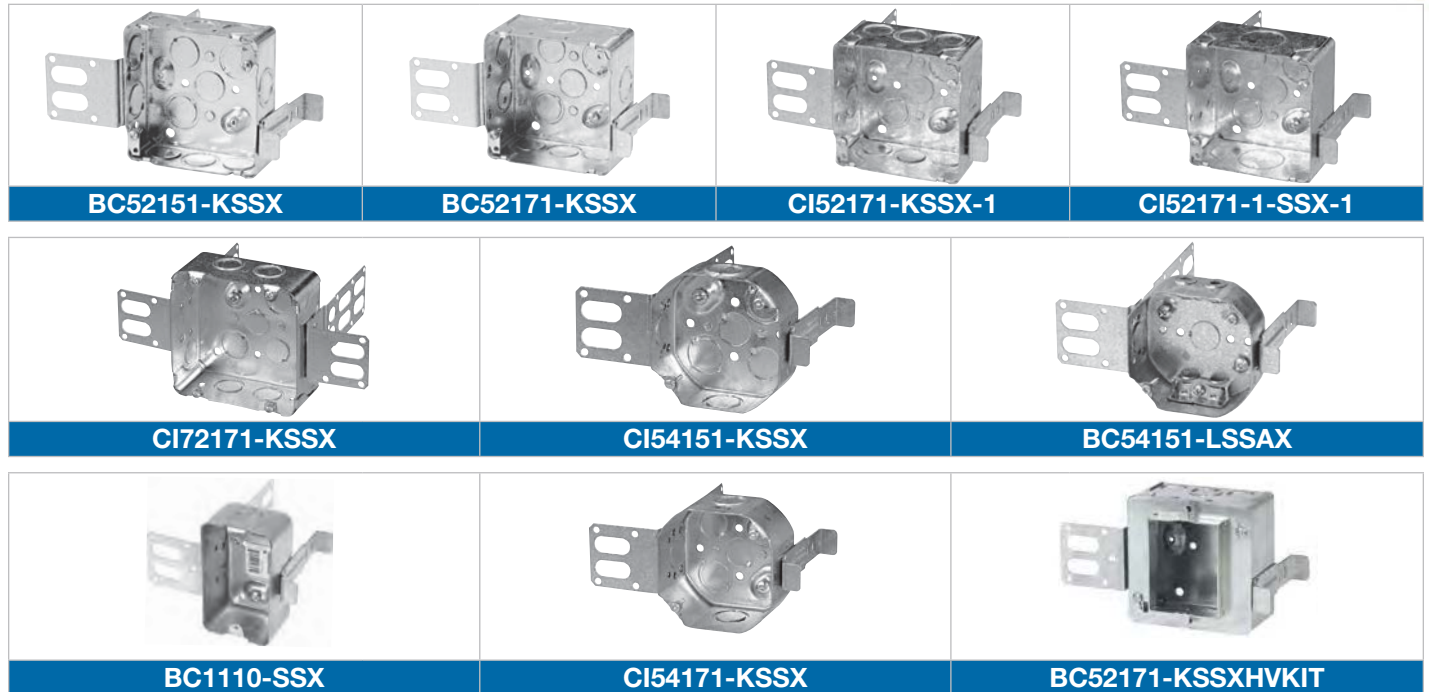

| Cat. No.   | Volume (Cu. in.) | Clamps    | Knockouts     |                |               |                |             | Pryouts sides |
|--|------------------|-----------|---------------|----------------|---------------|----------------|-------------|---------------|
|  |                  |           | 1/2 in. sides | 1/2 in. bottom | 3/4 in. sides | 3/4 in. bottom | 1 in. sides |               |
| <b>4 in. Square Boxes – 1-1/2 in. Deep</b>       |                  |           |               |                |               |                |             |               |
| BC52151-KSSX                                     | 21.0             | -         | 7             | 4              | 3             | 2              | -           | -             |
| BC52151-KSSX-NG*                                 | 21.0             | -         | 7             | 4              | 3             | 2              | -           | -             |
| <b>4 in. Square Boxes – 2-1/8 in. Deep</b>       |                  |           |               |                |               |                |             |               |
| BC52171-KSSX                                     | 30.0             | -         | 7             | 4              | 3             | 2              | -           | -             |
| BC52171-KSSX-NG*                                 | 30.0             | -         | 7             | 4              | 3             | 2              | -           | -             |
| CI52171-KSSX-1                                   | 30.0             | -         | 7             | 4              | 3             | 2              | -           | -             |
| CI52171-1-SSX-1                                  | 30.0             | -         | -             | 4              | -             | 2              | 2           | -             |
| <b>4-11/16 in. Square Boxes – 2-1/8 in. Deep</b> |                  |           |               |                |               |                |             |               |
| CI72171-KSSX                                     | 42.0             | -         | 8             | 4              | 4             | 2              | -           | -             |
| <b>4 in. Octagonal Boxes – 1-1/2 in. Deep</b>    |                  |           |               |                |               |                |             |               |
| CI54151-KSSX                                     | 15.0             | -         | 2             | 4              | 2             | 2              | -           | -             |
| BC54151-LSSAX                                    | 15.0             | loomex/BX | -             | 1              | -             | -              | -           | 4             |
| BC54151-LSSAX-NG*                                | 15.0             | loomex/BX | -             | 1              | -             | -              | -           | 4             |
| <b>4 in. Octagonal Boxes – 2-1/8 in. Deep</b>    |                  |           |               |                |               |                |             |               |
| CI54171-KSSX                                     | 21.0             | -         | 2             | 4              | 2             | 2              | -           | -             |
| <b>4 in. Square – 2-1/8 in. Deep</b>             |                  |           |               |                |               |                |             |               |
| BC52171-KSSXHVKIT                                | 33.6             | "SSX"     | 6             | -              | 2             | -              | -           | -             |

\* With raised ground screws. New generation robust adjustable support.

| Cat. No.                                   | Volume (Cu. in.) | Features |                     | Knockouts    |                |               |
|--|------------------|----------|---------------------|--------------|----------------|---------------|
|  |                  | Brackets | Raised Ground Screw | 1/2 in. ends | 1/2 in. bottom | 1/2 in. sides |
| <b>4 in. Square Boxes – 1-1/2 in. Deep</b> |                  |          |                     |              |                |               |
| BC1110-SSX                                 | 16.5             | "SSX"    | oui                 | 7            | 4              | 3             |