
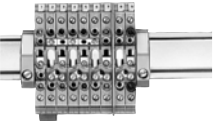
 







8WA1 Screw Terminals

8WA measuring transformer terminals

Version	DT	Article No.	Price per PU	PU (UNIT, SET, M)	PS*/P. unit	PG																																																																				
 8WA1011-1MH15		Instrument isolating terminals, terminal size 6 mm² <ul style="list-style-type: none"> • Mounting width 8 mm • Terminal height 33 mm • Terminal length 83 mm • Open isolating distance • With recessed test sockets • AWG 14 ... 8 • AWG 16 ... 10 			1 20 units	041																																																																				
 Typical circuit diagram  NSH0_00028 8WA1011-1MH15		<table border="1"> <thead> <tr> <th>Accessories</th> <th>Section</th> <th>Page</th> </tr> </thead> <tbody> <tr> <td>Covers, for connection bars</td> <td></td> <td></td> </tr> <tr> <td>• Transparent</td> <td>Accessories</td> <td>9/30</td> </tr> <tr> <td>• White, facility for labeling</td> <td>Accessories</td> <td>9/30</td> </tr> <tr> <td>Test sockets</td> <td></td> <td></td> </tr> <tr> <td>• Rated voltage between test socket and bypassed connection bar: 16 V, recessed</td> <td>Accessories</td> <td>9/30</td> </tr> <tr> <td>• Rated voltage between two test sockets: 125 V</td> <td></td> <td></td> </tr> <tr> <td>- Green</td> <td>Accessories</td> <td>9/30</td> </tr> <tr> <td>- Black</td> <td>Accessories</td> <td>9/30</td> </tr> <tr> <td>- Red</td> <td>Accessories</td> <td>9/30</td> </tr> <tr> <td>Test plugs</td> <td>Accessories</td> <td>9/30</td> </tr> <tr> <td>Disconnecting links</td> <td>Accessories</td> <td>9/30</td> </tr> <tr> <td>Insulation plates, for terminal size 2.5 ... 6 mm²</td> <td>Accessories</td> <td>9/30</td> </tr> <tr> <td>Connection combs</td> <td></td> <td></td> </tr> <tr> <td>• 10-pole for measuring transformer terminals, can be shortened as required</td> <td>Accessories</td> <td>9/31</td> </tr> <tr> <td>• 2-pole</td> <td>Accessories</td> <td>9/31</td> </tr> <tr> <td>Connection bars, for terminal size 6 mm²</td> <td></td> <td></td> </tr> <tr> <td>• Two terminals</td> <td>Accessories</td> <td>9/31</td> </tr> <tr> <td>• Three terminals</td> <td>Accessories</td> <td>9/31</td> </tr> <tr> <td>• Four terminals</td> <td>Accessories</td> <td>9/31</td> </tr> <tr> <td>• Ten terminals</td> <td>Accessories</td> <td>9/31</td> </tr> <tr> <td>• Unmounted for ten terminals</td> <td>Accessories</td> <td>9/31</td> </tr> <tr> <td>Barriers, for Insta terminals, terminal size 2.5 mm² and measuring transformer terminals, terminal size 6 mm²</td> <td>Accessories</td> <td>9/31</td> </tr> </tbody> </table>	Accessories	Section	Page	Covers, for connection bars			• Transparent	Accessories	9/30	• White, facility for labeling	Accessories	9/30	Test sockets			• Rated voltage between test socket and bypassed connection bar: 16 V, recessed	Accessories	9/30	• Rated voltage between two test sockets: 125 V			- Green	Accessories	9/30	- Black	Accessories	9/30	- Red	Accessories	9/30	Test plugs	Accessories	9/30	Disconnecting links	Accessories	9/30	Insulation plates, for terminal size 2.5 ... 6 mm²	Accessories	9/30	Connection combs			• 10-pole for measuring transformer terminals, can be shortened as required	Accessories	9/31	• 2-pole	Accessories	9/31	Connection bars, for terminal size 6 mm²			• Two terminals	Accessories	9/31	• Three terminals	Accessories	9/31	• Four terminals	Accessories	9/31	• Ten terminals	Accessories	9/31	• Unmounted for ten terminals	Accessories	9/31	Barriers, for Insta terminals, terminal size 2.5 mm² and measuring transformer terminals, terminal size 6 mm²	Accessories	9/31			
Accessories	Section	Page																																																																								
Covers, for connection bars																																																																										
• Transparent	Accessories	9/30																																																																								
• White, facility for labeling	Accessories	9/30																																																																								
Test sockets																																																																										
• Rated voltage between test socket and bypassed connection bar: 16 V, recessed	Accessories	9/30																																																																								
• Rated voltage between two test sockets: 125 V																																																																										
- Green	Accessories	9/30																																																																								
- Black	Accessories	9/30																																																																								
- Red	Accessories	9/30																																																																								
Test plugs	Accessories	9/30																																																																								
Disconnecting links	Accessories	9/30																																																																								
Insulation plates, for terminal size 2.5 ... 6 mm²	Accessories	9/30																																																																								
Connection combs																																																																										
• 10-pole for measuring transformer terminals, can be shortened as required	Accessories	9/31																																																																								
• 2-pole	Accessories	9/31																																																																								
Connection bars, for terminal size 6 mm²																																																																										
• Two terminals	Accessories	9/31																																																																								
• Three terminals	Accessories	9/31																																																																								
• Four terminals	Accessories	9/31																																																																								
• Ten terminals	Accessories	9/31																																																																								
• Unmounted for ten terminals	Accessories	9/31																																																																								
Barriers, for Insta terminals, terminal size 2.5 mm² and measuring transformer terminals, terminal size 6 mm²	Accessories	9/31																																																																								
		8WA1011-1MH15																																																																								
		8WA1822-7AX01		1 10 units	041																																																																					
		8WA1822-7AX03		1 10 units	041																																																																					
		8WA1822-7PH00		1 50 units	041																																																																					
		8WA1822-7PH03		1 50 units	041																																																																					
		8WA1822-7PH06		1 50 units	041																																																																					
		8WA1822-7PH08		1 50 units	041																																																																					
		8WA1868		1 10 units	041																																																																					
		8WA1822-7VH01		1 50 units	041																																																																					
		8WA1825		1 50 units	041																																																																					
		8WA7163		1 10 units	041																																																																					
		8WA1822-7VH22		1 10 units	041																																																																					
		8WA1885		1 50 units	041																																																																					
		8WA1886		1 50 units	041																																																																					
		8WA1887		1 20 units	041																																																																					
		8WA1888		1 10 units	041																																																																					
		8WA1822-7VH10		1 50 units	041																																																																					
		8WA1822-7TH00		1 50 units	041																																																																					
Accessories																																																																										
		Covers, for connection bars For through-type terminals, size 2.5 ... 6 mm ²																																																																								
		<table border="1"> <thead> <tr> <th>Versions</th> </tr> </thead> <tbody> <tr> <td>• Transparent</td> </tr> <tr> <td>• White, facility for labeling</td> </tr> </tbody> </table>	Versions	• Transparent	• White, facility for labeling																																																																					
Versions																																																																										
• Transparent																																																																										
• White, facility for labeling																																																																										
		Test sockets Ø 4 mm																																																																								
		<table border="1"> <thead> <tr> <th>Versions</th> </tr> </thead> <tbody> <tr> <td>• Rated voltage between test socket and bypassed connection bar: 16 V, recessed</td> </tr> <tr> <td>• Rated voltage between two test sockets: 125 V</td> </tr> <tr> <td>- Green</td> </tr> <tr> <td>- Black</td> </tr> <tr> <td>- Red</td> </tr> </tbody> </table>	Versions	• Rated voltage between test socket and bypassed connection bar: 16 V, recessed	• Rated voltage between two test sockets: 125 V	- Green	- Black	- Red																																																																		
Versions																																																																										
• Rated voltage between test socket and bypassed connection bar: 16 V, recessed																																																																										
• Rated voltage between two test sockets: 125 V																																																																										
- Green																																																																										
- Black																																																																										
- Red																																																																										
 8WA1822-7PH00																																																																										
 8WA1822-7PH03																																																																										
		Test plugs Red																																																																								
 8WA1868																																																																										
		Disconnecting links Rated insulation voltage with disconnecting link open according to DIN VDE 0110: 125 V Gr. C or 250 V Gr. B																																																																								
 8WA1822-7VH01																																																																										
		Insulation plates, for terminal size 2.5 ... 6 mm²																																																																								
 8WA1825																																																																										