

Journeyman™ T-Handle Hex-Keys

Features:


Tip-Ident® sizes marked on individual T-handles.

JOURNEYMAN™

Blade through handle design for high torque applications.

T-handle design delivers maximum power.

Soft touch grips for maximum control and comfort.

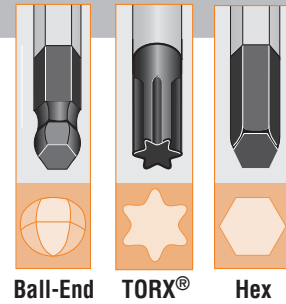

Ball-End

TORX®

Hex

Chamfered end for ease of use.



T-Handle Ball-End Hex-Key Set with Stand – Inch

JOURNEYMAN™

Additional features

- Metal stand for convenient hanging, storage on bench or wall.
- Short blade through handle provides maximum tool versatility.

6" Length - Inch

Cat. No.	Set Contains	Weight (lbs.)
JTH610EB		3.0
Cat. No.	Hex Size	Blade Length
JTH6E06BE	3/32"	6" (152 mm)
JTH6E07BE	7/64"	6" (152 mm)
JTH6E08BE	1/8"	6" (152 mm)
JTH6E09BE	9/64"	6" (152 mm)
JTH6E10BE	5/32"	6" (152 mm)
JTH6E11BE	3/16"	6" (152 mm)
JTH6E12BE	7/32"	6" (152 mm)
JTH6E13BE	1/4"	6" (152 mm)
JTH6E14BE	5/16"	6" (152 mm)
JTH6E15BE	3/8"	6" (152 mm)



JTH610EB

T-Handle Ball-End Hex-Keys – Inch


JOURNEYMAN™

Additional features

- Short blade through handle provides maximum tool versatility.
- Black oxide tips for precision fit.

6" Length - Inch

Cat. No.	Hex Size	Blade Length	Weight (lbs.)
JTH6E06BE	3/32"	6" (152 mm)	.04
JTH6E07BE	7/64"	6" (152 mm)	.05
JTH6E08BE	1/8"	6" (152 mm)	.06
JTH6E09BE	9/64"	6" (152 mm)	.07
JTH6E10BE	5/32"	6" (152 mm)	.12
JTH6E11BE	3/16"	6" (152 mm)	.14

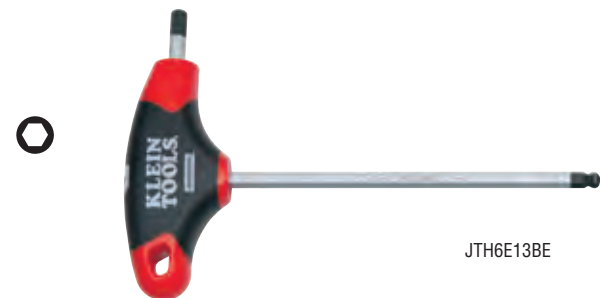

JTH6E13BE

Cat. No.	Hex Size	Blade Length	Weight (lbs.)
JTH6E12BE	7/32"	6" (152 mm)	.17
JTH6E13BE	1/4"	6" (152 mm)	.27
JTH6E14BE	5/16"	6" (152 mm)	.35
JTH6E15BE	3/8"	6" (152 mm)	.45
JTH6E17BE	1/2"	6" (152 mm)	.70

▲WARNING: Always wear approved eye protection.

▲WARNING: NOT insulated. Will NOT protect against electrical shock.

▲WARNING: Never use on or near live electrical circuits.

