



Steel City® Cable Lok®

- Simple, one-piece installation with no locknuts
- Screw designed for exceptional pullout resistance
- Captive screw ensures that the screw is intact for installation and resists backing out after installation
- Corrosion-resistant, zinc-chromatic plating
- Positive grounding
- Vibration-resistant screw design
- UL Listed and CSA Certified

Material: Body: Steel (spring steel);
Finish: Zinc;
Insulator: Nylon;
Temp.: 105°C


Listing: UL, CSA Listed



Simple, fast steps to install the Steel City® Cable Lok®.



1. Simply snap into place. No locknuts required!

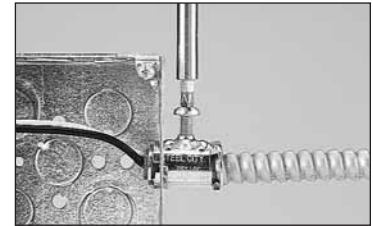

2. Insert cord and twist set screw. Connector tightens as screw is set.

- O.D. for over armor 0.400"–0.510"
- No set screws, locknuts or tools are required to attach MC cable to a box or enclosure
- One-piece spring-steel construction
- Accommodates the widest range of MC cable sizes in the industry — 14-2 to 10-3

- Compact, low-profile design saves space in the box or enclosure
- Fittings can be used in adjacent knockouts in the corner of the box
- Removable and reusable
- Ideal for commercial construction or prefabricated electrical wiring assemblies

Steel City® Cable Lok®



CAT. NO.	SIZE RANGE (IN.)	AC STEEL	AC ALUMINUM INTERLOCKED	MC (I) STEEL	MC (I) ALUMINUM	FLEX RW	STD. CTN.
XC-730	.450/.610 ½ KO	14/2 14/3 14/4	14/2 14/3 14/4	14/2 14/3 14/4	14/2 14/3 14/4	¾ Steel & AL	50
		12/2 12/3 12/4	12/2 12/3 12/4	12/2 12/3 12/4	12/2 12/3 12/4		
		10/2	10/2 10/3	½" KO	10/2 10/3		
XC-731	.450/.610 ½ KO	14/2 14/3 14/4	14/2 14/3 14/4	14/2 14/3 14/4	14/2 14/3 14/4	—	50
		12/2 12/3 12/4	12/2 12/3 12/4	12/2 12/3 12/4	12/2 12/3 12/4		
		10/2	10/2 10/3	½" KO	10/2 10/3		
XC-732	.610/.875 ¾ KO	10/3 10/4 10/5	—	10/4 10/5	—	¾ Steel & AL	25
		8/3 8/4	—	8/3 8/4	—		
		6/2	6/2	¾" KO	—		
XC-7300	.450/.610 ½ KO	14/2 14/3 14/4	14/2 14/3 14/4	14/2 14/3 14/4	14/2 14/3 14/4	—	25
		12/2 12/3 12/4	12/2 12/3 12/4	12/2 12/3 12/4	12/2 12/3 12/4		
		10/2	10/2 10/3	½" KO	10/2 10/3		

UL File No. E-1383.

CSA File No. LR-12798.



Snap-In Fitting for MC Cable — Steel



CAT. NO.	DESCRIPTION	STD. CTN.
XC-130	Steel Snap-In Fitting for MC cable (14-2+G to 10-3+G)	500