

# 861 SERIES™ FLOOR BOXES



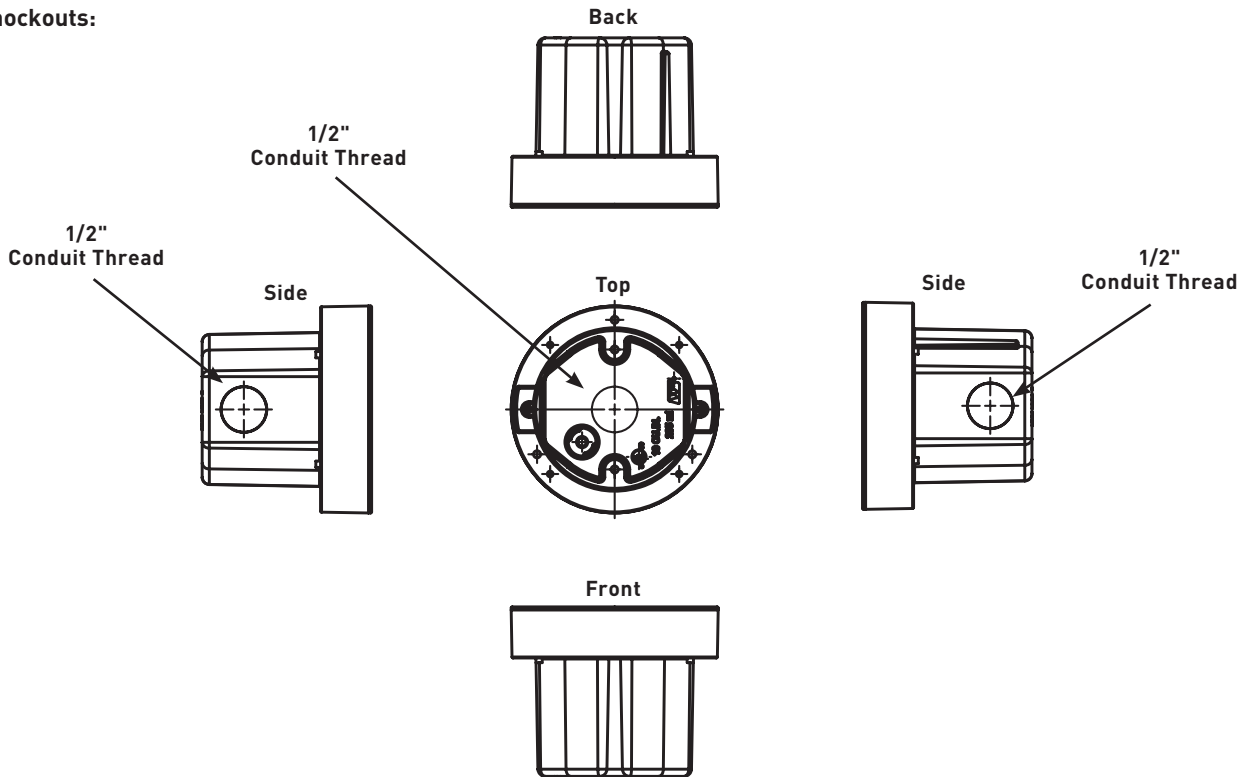
861 Series™ Single Service Wood Floor Boxes bring power or communication service directly to the open space. Available with poke-thru style covers.

### CODE REFERENCE

**cULus Listed**  
**Metallic Outlet Boxes:**  
 File E2961 Guide QCIT.  
 Meets Article 314.27(C) of NEC.

## 861 Series Floor Boxes Ordering Information

### Knockouts:



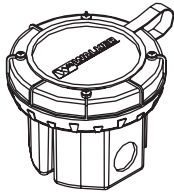
### COLOR OPTIONS



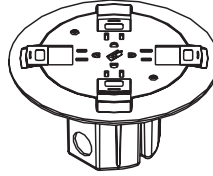
861 Series™ Cover Plates are available in these colors as indicated in the part number descriptions.  
**Custom color options are also available. Consult the factory for more information.**

## 861 SERIES™ FLOOR BOXES

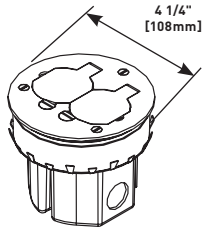
## 861 Series Floor Boxes Ordering Information (continued)

**861 Wood Floor Box**

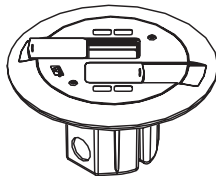
Die-cast aluminum construction with three 1/2" [12.7mm] knockouts; two on the sides and one on the bottom. 18 cu. in. [295ml<sup>3</sup>] of capacity. Requires a 4" [102mm] diameter hole. Comes complete with a disposable cover, receptacle and cover sold separately.

**861QTC Wood Floor Box Assembly**

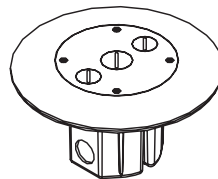
Complete with prewired 15A quad receptacle can be wired as standard or isolated ground. Flush poke-thru-style cover is available in painted gray (861QTCGY), black (861QTCBK), ivory (861QTCVY), or brushed metal finishes in aluminum (861QTCAL) and brass (861QTCBS). Slide covers match painted flange colors. Aluminum and brass covers shipped with black slide covers. Brass flange also available with nonmetallic brass-color (AB) slide holder. Die-cast aluminum construction with three 1/2" trade size knockouts: two on the sides and one on the bottom. 18 cu. in. [295 cu.cm] capacity. Requires a 4" [102mm] diameter hole and overall floor depth of 1" [25mm]. Assembled with scrub water gasket. For use on tile, wood, or carpet floors.

**861DB Wood Floor Box Assembly**

Complete with 20A duplex receptacle and brass cover plate. Die-cast aluminum construction with three 1/2" [12.7mm] knockouts; two on the sides and one on the bottom. 18 cu. in. [295ml<sup>3</sup>] of capacity. Requires a 4" [102mm] diameter hole.

**861AMDTC Wood Floor Box Assembly**

All communication floor boxes accept up to four UTP connectors. Flush poke-thru-style flanges available in painted gray (861AMDTCGY), black (861AMDTCBK), ivory (861AMDTCVY), or brushed metal finishes in aluminum (861AMDTCAL) and brass (861AMDTCBS). Slide covers match painted flange colors. Aluminum and brass flanges shipped with black slide cover. Brass flange also available with nonmetallic brass-color (AB) slide holder. Die-cast aluminum construction with three 1/2" trade size knockouts: two on the sides and one on the bottom. 18 cu. in. [295 cu.cm] capacity. Requires a 4" [102mm] diameter hole and overall floor depth of 1" [25mm]. Includes two (2) Ortronics TracJack inserts, two (2) Ortronics Series II adapters and two Wiremold Open System adapters. Assembled with scrub water gasket. For use on tile, wood, or carpet floors. Modular jacks sold separately.

**861FFTC Furniture Feed Raised Floor Box Assembly**

Cover has two 1/2" trade size conduits and one 3/4" trade size threaded conduit opening for feeding cables and wires through floor. Flush flanges available in painted gray (861FFTCGY), black (861FFTCBK), ivory (861FFTCVY), or brushed metal finishes in aluminum (861FFTCAL) and brass (861FFTCBS). Die-cast aluminum construction with three 1/2" trade size knockouts; two on the sides and one on the bottom, 18 cu. in. [295 cu. cm] capacity. Requires a 4" [102mm] diameter hole.