


AF09 ... AF38 3-pole contactors

Main accessories

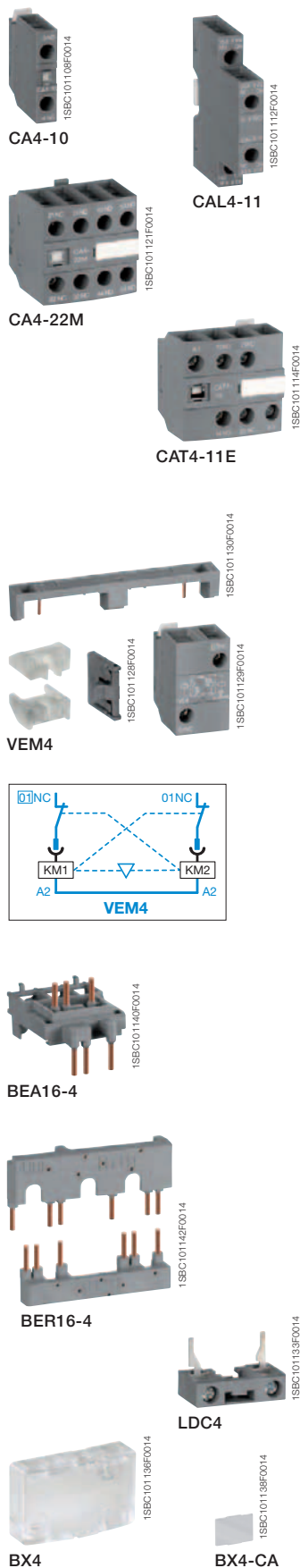

Ordering details (1)

For contactors	Auxiliary contacts	Type	Order code	Pkg qty	Weight (1 pce)
					kg

Front-mounted instantaneous auxiliary contact blocks

AF09 ... AF38	1 0	- -	CA4-10	1SBN010110R1010	1	0.014
	1 0	- -	CA4-10-T	1SBN010110T1010	10	0.014
	0 1	- -	CA4-01	1SBN010110R1001	1	0.014
	0 1	- -	CA4-01-T	1SBN010110T1001	10	0.014
AF09 ... AF16...-30-10	2 2	- -	CA4-22M	1SBN010140R1122	1	0.055
	3 1	- -	CA4-31M	1SBN010140R1131	1	0.055
	1 3	- -	CA4-13M	1SBN010140R1113	1	0.055
	0 4	- -	CA4-04M	1SBN010140R1104	1	0.055
AF26 ... AF38...-30-00	2 2	- -	CA4-22E	1SBN010140R1022	1	0.055
	3 1	- -	CA4-31E	1SBN010140R1031	1	0.055
	4 0	- -	CA4-40E	1SBN010140R1040	1	0.055
	0 4	- -	CA4-04E	1SBN010140R1004	1	0.055
AF09 ... AF16...-30-01	2 2	- -	CA4-22U	1SBN010140R1322	1	0.055
	3 1	- -	CA4-31U	1SBN010140R1331	1	0.055
	4 0	- -	CA4-40U	1SBN010140R1340	1	0.055

Front-mounted auxiliary contact blocks with N.O. leading contact and N.C. lagging contact

AF09 ... AF38	- -	1 0	CC4-10	1SBN010111R1010	1	0.014
	- -	0 1	CC4-01	1SBN010111R1001	1	0.014

Side-mounted instantaneous auxiliary contact blocks

AF09 ... AF38	1 1	- -	CAL4-11	1SBN010120R1011	1	0.040
	1 1	- -	CAL4-11-T	1SBN010120T1011	10	0.040

Front-mounted instantaneous auxiliary contact and A1/A2 coil terminal blocks

AF09 ... AF16...-30-10	1 1	- -	CAT4-11M	1SBN010151R1111	1	0.040
AF26 ... AF38...-30-00	1 1	- -	CAT4-11E	1SBN010151R1011	1	0.040
AF09 ... AF16...-30-01	1 1	- -	CAT4-11U	1SBN010151R1311	1	0.040

Note: CAT4 not fittable on AF.Z contactors with DC control voltage 12...20 V DC.

Mechanical interlock unit

AF09 ... AF38			VM4	1SBN030105T1000	10	0.005
---------------	--	--	-----	-----------------	----	-------

Note: VM4 includes 2 fixing clips (BB4) to maintain together both contactors.

Mechanical and electrical interlock set

AF09 ... AF16	1 1	- -	VEM4	1SBN030111R1000	1	0.035
AF26 ... AF38						

Note: - VEM4 includes a VM4 mechanical interlock unit with 2 fixing clips (BB4), a VE4 electrical interlock block. VE4 block must be used with A2-A2 connection to respect the electrical connection diagram.
- VEM4 not fittable on AF.Z contactors with DC control voltage 12...20 V DC.

Connecting links with manual motor starters

AF09 ... AF16	with	MS116-0.16 ... MS116-25, MS132-0.16 ... MS132-25	BEA16-4	1SBN081306T1000	10	0.025
AF26 ... AF38	with	MS116-0.16 ... MS116-16, MS132-0.16 ... MS132-10	BEA26-4	1SBN082306T1000	10	0.025
		MS116-20 ... MS116-32, MS132-12 ... MS132-32	BEA38-4	1SBN082306T2000	10	0.030

Connection sets for reversing contactors

AF09 ... AF16			BER16-4	1SBN081311R1000	1	0.045
AF26 ... AF38			BER38-4	1SBN082311R1000	1	0.100

Connection sets for star-delta starting

AF09 ... AF16			BEY16-4	1SBN081313R2000	1	0.050
AF26 ... AF38			BEY38-4	1SBN082713R2000	1	0.110

Note: with or without VM4 or VEM4

Additional coil terminal block

AF09 ... AF38			LDC4	1SBN070156T1000	10	0.010
---------------	--	--	------	-----------------	----	-------

Protective covers

All 1-stack contactors			BX4	1SBN110108T1000	10	0.006
For 4-pole CA4 and 2-pole CAT4 auxiliary contact blocks			BX4-CA	1SBN110109W1000	50	0.001

(1) See "Main accessory fitting details" table.