 


## Tools and Dies

### TBM45S Comfort Crimp® Tool

- Requires the lowest handle force of any tool in its class — up to 75% less than competing tools
- Wide installing range of #8–#2 AWG copper and #10–#6 AWG aluminum lugs and splices
- Also installs up to green color-coded C-taps and MD2 Series motor lead disconnects
- Shure-Stake® mechanism ensures a complete crimp cycle before release for a proper crimp every time
- Color-coded die wheel for easy matching with Blackburn® lugs and splices featuring the Color-Keyed® system
- CrimpAssist® foot provides stability when work surface leverage is needed to crimp larger connectors
- UL® Listed for use with Blackburn® compression connectors featuring the Color-Keyed® system




Creates diamond-style crimp



CAT. NO.	DESCRIPTION	PKG. QTY.
TBM45S	Crimp tool with Shure-Stake® mechanism for #8–#2 copper and #10–#6 AWG aluminum Lugs and Splices	1

### TBM4S Dieless Crimp Tool

- Wide range of #8 AWG to 250 kcmil for copper lugs and #8 to 4/0 AWG for aluminum lugs
- Adjustable indenter eliminates the need to buy and maintain numerous individual dies
- Shure-Stake® mechanism ensures a properly completed crimp each time
- Easily adjusted by turning knurled adjusting wheel and aligning pointer with proper terminal size
- Dieless, adjustable crimper for Blackburn® compression connectors featuring the Color-Keyed® system

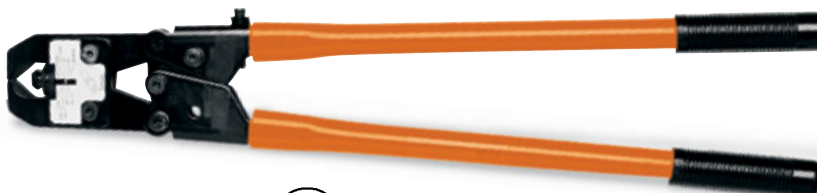

Creates indent-style crimp

CAT. NO.	DESCRIPTION	PKG. QTY.
TBM4S	Dieless crimp tool with Shure-Stake® mechanism for #8 AWG–250 kcmil copper and #8–4/0 AWG aluminum	1

### TBM5S Crimp Tool



Creates diamond-style crimp



- Wide range of #8 AWG to 250 kcmil for copper and #10 to 4/0 AWG for aluminum lugs and splices
- Also installs C-taps from 54705 to 54750
- Shure-Stake® mechanism ensures a properly completed crimp each time
- Includes color-coded, die code-embossed installation dies

CAT. NO.	COLOR CODE	DIE CAT. NO	PKG. QTY.
TBM5S	RED	13454	1
	BLUE		
	GRAY		
	BROWN		
	GREEN	13455	
	PINK		
	BLACK		
	ORANGE		
	PURPLE	13456	
	YELLOW		
	GOLD	13457	
	TAN		
	OLIVE		
	RUBY		
	WHITE	13458	