


WALKERDUCT® PRO SERIES SERVICE FITTINGS

Walkerduct Pro Series Brushed Aluminum Cover Plate Flanges Ordering Information


818TCAL One-Gang Brushed Aluminum Combination Carpet & Tile Flange

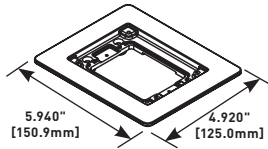

Accepts Ortronics® MAB6TJ TracJack and MAB3S2 Series II adapters and Wiremold CM Series inserts, sold separately.

NOTE: Brushed aluminum flange comes with a beveled edge.


838TCAL Three-Gang Brushed Aluminum Combination Carpet & Tile Flange

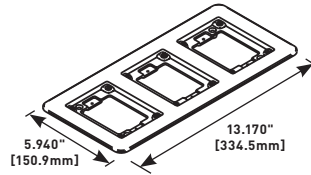

Accepts Ortronics® MAB6TJ TracJack and MAB3S2 Series II adapters and Wiremold CM Series inserts, sold separately.

NOTE: Brushed aluminum flange comes with a beveled edge.

828TCAL Two-Gang Brushed Aluminum Combination Carpet & Tile Flange

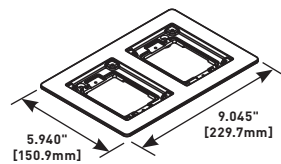


Accepts Ortronics® MAB6TJ TracJack and MAB3S2 Series II adapters and Wiremold CM Series inserts, sold separately.

NOTE: Brushed aluminum flange comes with a beveled edge.


Walkerduct Pro Series Brushed Aluminum Cover Plates Ordering Information

828R-TCAL Brushed Aluminum Duplex Cover Plate

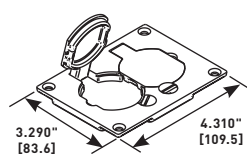


Flip lids. Can also be used with a 106 type communication adapter.

828DPGFITCAL Brushed Aluminum Rectangular Cover Plate

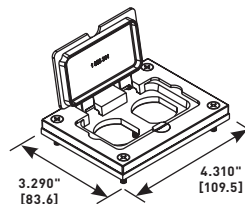


Allows for mounting of a duplex style receptacle with a rectangular style flip lid cover.

828GFITCAL Brushed Aluminum GFI Cover Plate

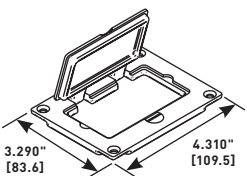

May be used with Activate and Ortronics® Connectivity Systems in conjunction with 817B, 827B, and 837B Flanges.

828DLRAL Brushed Aluminum Single Locking Receptacle Cover Plate

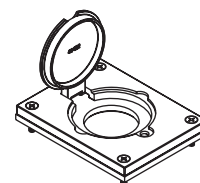

Single flip lid cover for 20A or 30A single locking receptacles. Device opening is 2 5/8" [67mm]. For use with maximum female locking device of 1.58" diameter, and maximum male plug face of 2.25" diameter.

COLOR OPTIONS



Walkerduct® Pro Series Service Fittings are available in brushed aluminum, brass, black or brown as indicated in the part number description.

WALKERDUCT® UNDERFLOOR DUCT SYSTEMS

Walkerduct Underfloor Duct Systems Service Fitting Compatibility

| PRODUCT FAMILY | CATALOG NUMBER | ACTIVATION LOCATION | | SERVICE CAPACITY | | | SERVICE COMPATIBILITY | | | MATERIAL/COLORS | | | | |
|---|----------------|---------------------|----------|------------------|--------------|----------------|-----------------------|---------------|--------------|-----------------|----------|-------|------|-------|
| | | Flush | Pedestal | Single Service | Dual Service | Triple Service | Power | Communication | Audio/Visual | Polycarbonate | Aluminum | Brass | Gray | Black |
|  | 817B | • | | • | | | • | • | | | | • | | |
| | 827B | • | | | • | | • | • | | | • | | | |
| | 837B | • | | | | • | • | • | | | • | | | |
| | 817PCC | • | | • | | | • | • | | • | | | | • |
| | 827PCC | • | | | • | | • | • | | • | | | | • |
| | 837PCC | • | | | | • | • | • | | • | | | | • |
| | 818TCAL | • | | • | | | • | • | | | • | | | |
| | 828TCAL | • | | | • | | • | • | | | • | | | |
| | 838TCAL | • | | | | • | • | • | | | • | | | |
|  | S165B | • | | • | | | • | | | | | • | | |
| | S165BLK/BRN | • | | • | | | | | | • | | | | • |
| | S166B | • | | • | | | | • | | | • | | | |
| | S166BLK/BRN | • | | • | | | | • | | • | | | | • |
| | S175BLK/BRN | • | | • | | | • | | | • | | | | • |
|  | PSRC9TC | • | | • | | | • | | | | • | • | • | • |
| | PSRC9AMDTC | • | | • | | | | • | | | • | • | • | • |
| | PSRC9FFTC | • | | • | | | | • | | | • | • | • | • |
|  | 1204BF | | • | • | | | | • | | | | • | | |
| | 1204AL | | • | • | | | | • | | | • | | | |
| | 1223BF | | • | • | | | • | | | | • | | | |
| | 1223AL | | • | • | | | • | | | | • | | | |
|  | MP4 | | • | • | | | • | • | • | | • | | | |
| | MP8 | | • | | • | | • | • | • | | • | | | |
| | MP8-1 | | • | | • | | • | • | • | | • | | | |
|  | 525A | | • | • | | | | • | • | | • | | | |
| | 525B | | • | • | | | | • | • | | • | | | |
| | 525C | | • | • | | | | • | • | | • | | | |
| | 525D | | • | • | | | | • | • | | • | | | |
| | 525F | | • | • | | | • | | | | • | | | |
| | 25G | | • | • | | | • | | | | • | | | |
| | 525H | | • | • | | | • | | | | • | | | |
| | 525I | | • | • | | | • | | | | • | | | |
| | 525J | | • | • | | | • | • | • | | • | | | |
| | 525RT | | • | • | | | | • | | | • | | | |
| 525ACT | | • | • | | | | • | | | • | | | | |