


Superstrut® Support Systems

1-5/8" x 1-5/8" Channel

Superstrut® Beam Clamps and Hanger Rods

U562HDG

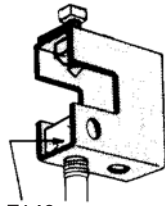


E146

Rod Size	Design Load Load/lbs.
1/2	800

E146 Square nut order separately. 1/2" set screw included.

For 20° swivel application use ES145-1/2 nut.

UM562HDGC

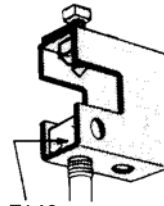


E146

Rod Size	Design Load Load/lbs.
1/2	1200

E146 Square nut order separately. 1/2" set screw included.

For 20° swivel application use ES145-1/2 nut.


US562HDGC

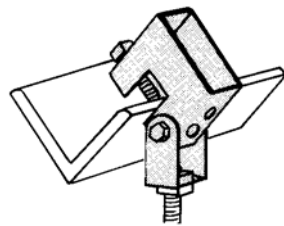

Rod Size	Design Load Load/lbs.
1/2	800

1/2" set screw included.


U568

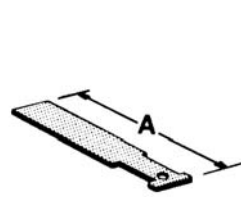

Cat. no.	Beam Flange Width	A
U568-3EG	6	9
U568-4EG	9	12
U568-5EG	12	15


16 ga. material

U514HDGC

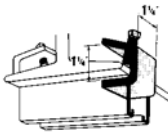


3/8" x 1 1/2" set screw included.
Design Load 750 lbs./per pair

U515HDGC

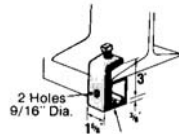

For all "A" series channel.
1/2" x 1 1/2" set screw included.
Design Load 800 lbs.

 ES145



Cat. No.	Size
ES145-3/8EG	3/8
ES145-1/2EG	1/2

E146



Cat. No.	Size
E146-1/4EG	1/4
E146-5/16EG	5/16
E146-3/8EG	3/8
E146-1/2EG	1/2
E146-5/8EG	5/8

H104




Standard length, 10 ft.

Also available in stainless steel (304 and 316) in length of 6 ft.

NATIONAL COARSE THREAD

Cat. No.	Size	Threads per inch	Design Load lbs.
H104-1/4x10EGC	1/4	20	150
H104-3/8x10EGC	3/8	16	610
H104-1/2x10EGC	1/2	13	1130
H104-5/8x10EGC	5/8	11	1810
H104-3/4x10EGC	3/4	10	2710
H104-7/8x10EGC	7/8	9	3770
H104-1x10EGC	1	8	4960

H119

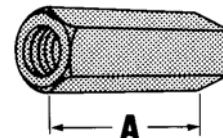

Order by product number, rod size, and finish. Example: H119-1/2EGC

Rod Size	A
1/4	7/8
5/16	7/8
3/8	1-1/8
1/2	1-1/4
5/8	2-1/8
3/4	2-1/4
7/8	2-1/2
1	2-1/4

Finished & Materials: Gold Galv. dichromate (no suffix), Electrogalvanized (EG), Hot dipped Galvanized (HDG), Stainless Steel Type 304 (SS)

For our complete selection, consult our Superstrut® catalogue.

Thomas & Betts