



TYPE SGB

Features

- Manufactured from high strength 6061-T6 aluminum alloy
- Electro-tin plated
- Lay-in feature
- Stainless steel hardware
- Serrations in conductor wire way
- Unique clamp design
- 1/4" max frame thickness
- Meets ASTM B117-09

Benefits

- Suitable for use with either copper or aluminum conductors
- Provides low contact resistance
- Provides ease of installation
- For corrosion resistance, greater torque and ease of installation
- Cuts oxidation
- No holes to be drilled for mounting
- Mount to solar panel frames
- Resistance to outdoor salt spray

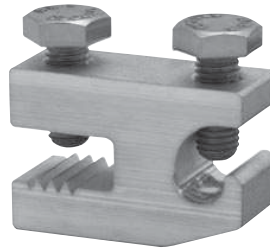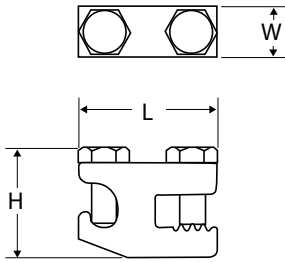

Catalog Number	Ground Wire Range	Dimensions		
		L	W	H
SGB-4	4-14	1.375	.500	1.080

All wire sizes, unless noted otherwise, are American Wire Gauge (AWG) UL 467 for grounding and bonding.

UL File E34440

DE-OX Inhibitor is recommended for all aluminum terminations.

ILSCO