

Color-Keyed®

Standard Barrel Copper Lug

T&B Catalog Number:

54160BS

UPC Number:

78621092064


Status:

Active

Description:

Copper One-Hole Lug - Straight Standard Belled End Barrel - max 35KV, 2/0 AWG Wire, 1/2" Bolt Size, Tin Plated with Inspection Hole, Black 45

General

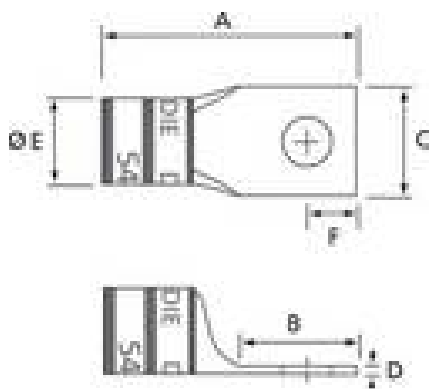

Material	Copper
Finish	Tin Plated
Wire Size	2/0 AWG
Number of Studs	1
Stud Size	1/2
Tongue Angle	Straight
Barrel Length	Standard
Barrel Shape	Belled End
Tongue Width	Standard
Peep Hole	Y
Marking	Standard
Hole Shape	Round
Die Color	Black
Die Code	45

Specifications

Voltage Rating	600V to 35KV
----------------	--------------

Tooling

Connector & Tooling Chart	Available on Website
---------------------------	----------------------

Packaging

T&B Order Multiple	10
T&B Inner Pack	10
Package in Units	100
T&B Sold in UOM	Each
T&B Weight Per UOM	8.1 lbs. per 100

Application Support

Overview	Available on Website
----------	----------------------

Notes

Dimensions given for reference only. Dimensions may vary up to +/- .030.

Certifications

RoHS Compliance	Yes
-----------------	-----

Certifications



File Nbr:
E9809