


# STRAIGHT BLADE PLUGS & CONNECTORS

**IP20**  
Suitability

**Flanged Inlets & Outlets** 2 Pole, 3 Wire Grounding 15 & 20A, 125 & 250V

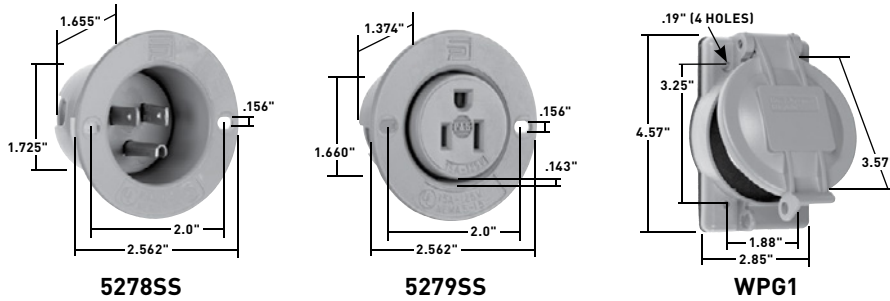


## Features

- All thermoplastic construction, provides excellent impact and chemical resistance.
- Available in Gray or Black.
- NEMA configuration molded on flange, easy field identification.

CATALOG NUMBER	RATING		DESCRIPTION	NEMA CONFIG. NO.	3rd PARTY COMPLIANCE	
	A.	V.			UL498	FSUL WC596
<b>FLANGED INLETS &amp; OUTLETS – GRAY</b>						
5278SS	15	125	Inlet, Gray	5-15P	•	•
5279SS	15	125	Outlet, Gray	5-15R	•	•
5378SS	20	125	Inlet, Gray	5-20P	•	•
5379SS	20	125	Outlet, Gray	5-20R	•	•
5678SS	15	250	Inlet, Gray	6-15P	•	•
5679SS	15	250	Outlet, Gray	6-15R	•	•
5478SS	20	250	Inlet, Gray	6-20P	•	•
5479SS	20	250	Outlet, Gray	6-20R	•	•

CATALOG NUMBER	RATING		DESCRIPTION	NEMA CONFIG. NO.	3rd PARTY COMPLIANCE	
	A.	V.			UL498	FSUL WC596
<b>FLANGED INLETS &amp; OUTLETS – BLACK</b>						
5278SSBK	15	125	Inlet, Black	5-15P	•	•
5279SSBK	15	125	Outlet, Black	5-15R	•	•

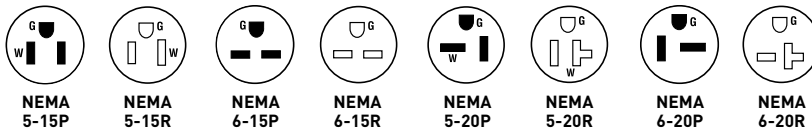

## Features


- Glass-filled polycarbonate, impact- and corrosion-resistant.
- Stainless steel hardware.
- Molded-in flat surface label area.
- OSHA lock-out/tag-out provision molded-in.
- Accepts competitor inlets and outlets.

CATALOG NUMBER	DESCRIPTION
<b>WEATHERPROOF COVER FOR FLANGED DEVICES</b>	
WPG1	Weatherproof Cover for Flanged Inlets and Outlets


For further information consult the Weatherproof Section O.

# INDUSTRIAL SPEC GRADE TURNLOK® LOCKING DEVICES


20 Amp NEMA L520 2 Pole, 3 Wire 20A, 125V

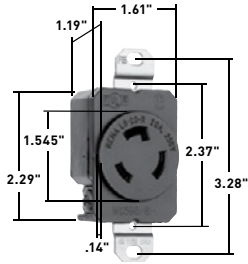


20A Receptacle

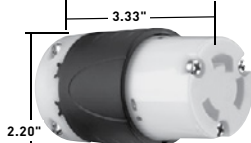


20A Connector

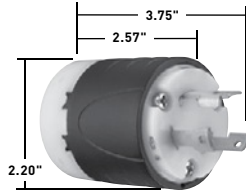


20A Plug

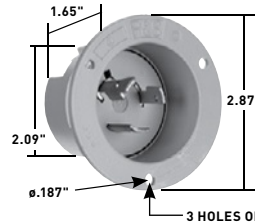

20A Flanged Inlet & Outlet

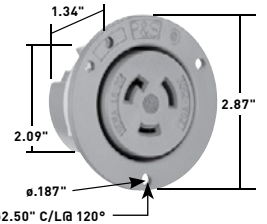

CATALOG NUMBER	RATING		DESCRIPTION/COLOR	CORD DIAMETER	NEMA CONFIG. NO.	3rd PARTY COMPLIANCE		
	A.	V.				UL498	FSUL WC596	CSA
<b>RECEPTACLES</b>								
L520R	20	125	Single Receptacle		L5-20R	•	•	•
IGL520R	20	125	Single Receptacle, Orange, Isolated Ground		L5-20R	•	•	•
CRL520R	20	125	Single Receptacle, Yellow, Corrosion-Resistant		L5-20R	•	•	•
<b>CONNECTORS IP20 SUITABILITY</b>								
L520C	20	125	Black Back, White Front Body	.225"-1.150"	L5-20R	•	•	•
L520CBK	20	125	Black Back, Black Front Body	.225"-1.150"	L5-20R	•	•	•
CRL520C	20	125	Yellow Back, White Front Body, Corrosion-Resistant	.225"-1.150"	L5-20R	•	•	•
<b>PLUGS IP20 SUITABILITY</b>								
L520P	20	125	Black Back, White Front Body	.225"-1.150"	L5-20P	•	•	•
L520PBK	20	125	Black Back, Black Front Body	.225"-1.150"	L5-20P	•	•	•
CRL520P	20	125	Yellow Back, White Front Body, Corrosion-Resistant	.225"-1.150"	L5-20P	•	•	•
<b>FLANGED INLETS &amp; OUTLETS</b>								
L520FI	20	125	Gray Inlet		L5-20P	•		•
L520FO	20	125	Gray Outlet		L5-20R	•		•

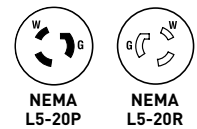

Reference Pages G-38 and G-39 for Accessories.

CATALOG NUMBER	DESCRIPTION	COLOR
<b>WEATHERPROOF COVER</b>		
WPG2	Cover for 20 and 30A Turnlok Flanged Inlets and Outlets	Gray
<b>STAINLESS STEEL WALL PLATE</b>		
SS720	Wall Plate for Locking Receptacles	302/304
<b>WEATHERPROOF BOOTS</b>		
L15RBC	Boot for 15A Locking Connector	Black
L15RBP	Boot for 15A Locking Plug	Black
L2030RBC	Boot for 20/30A Locking Connector	Black
L2030RBP	Boot for 20/30A Locking Plug	Black
<b>CORROSION-RESISTANT BOOTS</b>		
CRL2030RBC	Boot for 20/30A Locking Connector	Yellow
CRL2030RBP	Boot for 20/30A Locking Plug	Yellow
CR7716N	Boot for 50A Locking Connector	Yellow
CR7717N	Boot for 50A Locking Plug	Yellow



SS720




L15RBC


All devices listed on this page conform to NEMA WD-1 and WD-6.

# INDUSTRIAL SPEC GRADE TURNLOK® LOCKING DEVICES


20 Amp NEMA L620 & L720 2 Pole, 3 Wire 20A, 250 & 277V

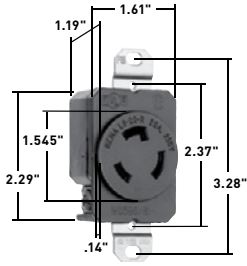


20A Receptacle

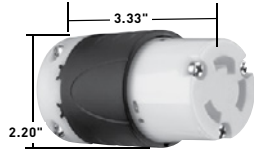

20A Connector


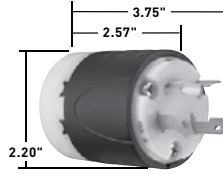


20A Plug

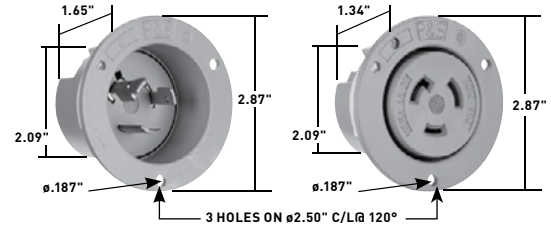


20A Flanged Inlet & Outlet

CATALOG NUMBER	RATING		DESCRIPTION/COLOR	CORD DIAMETER	NEMA CONFIG. NO.	3rd PARTY COMPLIANCE		
	A.	V.				UL498	FSUL WC596	CSA
<b>RECEPTACLES</b>								
L620R	20	250	Single Receptacle		L6-20R	•	•	•
IGL620R	20	250	Single Receptacle, Orange, Isolated Ground		L6-20R	•	•	•
L720R	20	277	Single Receptacle		L7-20R	•	•	•
IGL720R	20	277	Single Receptacle, Orange, Isolated Ground		L7-20R	•	•	•
<b>CONNECTORS IP20 SUITABILITY</b>								
L620C	20	250	Black Back, White Front Body	.225"-.1150"	L6-20R	•	•	•
CRL620C	20	250	Yellow Back, White Front Body, Corrosion-Resistant	.225"-.1150"	L6-20R	•	•	•
L720C	20	277	Black Back, White Front Body	.225"-.1150"	L7-20R	•	•	•
<b>PLUGS IP20 SUITABILITY</b>								
L620P	20	250	Black Back, White Front Body	.225"-.1150"	L6-20P	•	•	•
CRL620P	20	250	Yellow Back, White Front Body, Corrosion-Resistant	.225"-.1150"	L6-20P	•	•	•
L720P	20	277	Black Back, White Front Body	.225"-.1150"	L7-20P	•	•	•
<b>FLANGED INLETS &amp; OUTLETS</b>								
L620FI	20	250	Gray Inlet		L6-20P	•		•
L620FO	20	250	Gray Outlet		L6-20R	•		•
L720FI	20	277	Gray Inlet		L7-20P	•		•
L720FO	20	277	Gray Outlet		L7-20R	•		•

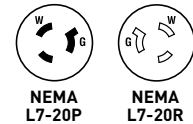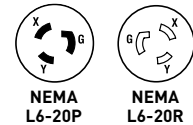

Reference Pages G-38 and G-39 for Accessories.


CATALOG NUMBER	DESCRIPTION	COLOR
<b>WEATHERPROOF COVER</b>		
WPG2	Cover for 20 and 30A Turnlok Flanged Inlets and Outlets	Gray
<b>STAINLESS STEEL WALL PLATE</b>		
SS720	Wall Plate for Locking Receptacles	302/304 S/S
<b>RECEPTACLE COVERS</b>		
7425Y	20/30 Amp Receptacle Cover	Yellow
7425GRY	20/30 Amp Receptacle Cover	Gray

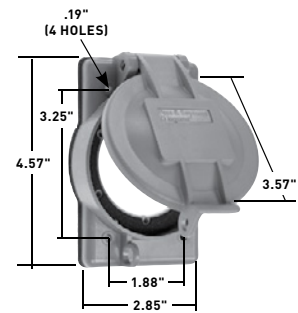


WPG2

# INDUSTRIAL SPEC GRADE TURNLOK® LOCKING DEVICES


20 Amp NEMA L820, L920 & L2420 2 Pole, 3 Wire 20A, 347, 480 & 600V

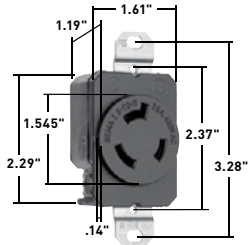


20A Receptacle

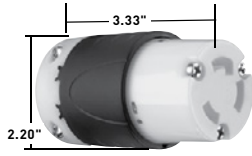


20A Connector

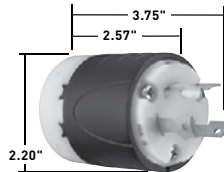


20A Plug

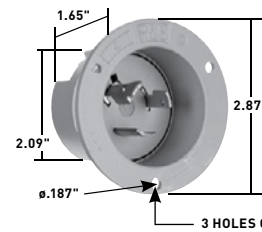

20A Flanged Inlet & Outlet

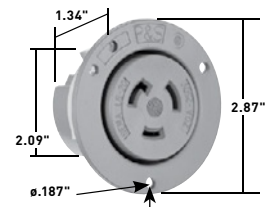

CATALOG NUMBER	RATING		DESCRIPTION/COLOR	CORD DIAMETER	NEMA CONFIG. NO.	3rd PARTY COMPLIANCE		
	A.	V.				UL498	FSUL WC596	CSA
<b>RECEPTACLES</b>								
L820R	20	480	Single Receptacle		L8-20R	•		•
IGL820R	20	480	Single Receptacle, Orange, Isolated Ground		L8-20R	•		•
L920R	20	600	Single Receptacle		L9-20R	•		•
L3720R	20	347	Single Receptacle		L24-20R			•
<b>CONNECTORS IP20 SUITABILITY</b>								
L820C	20	480	Black Back, White Front Body	.225"-1.150"	L8-20R	•		•
L920C	20	600	Black Back, White Front Body	.225"-1.150"	L9-20R	•		•
L3720C	20	347	Black Back, White Front Body	.225"-1.150"	L24-20R			•
<b>PLUGS IP20 SUITABILITY</b>								
L820P	20	480	Black Back, White Front Body	.225"-1.150"	L8-20P	•		•
L920P	20	600	Black Back, White Front Body	.225"-1.150"	L9-20P	•		•
L3720P	20	347	Black Back, White Front Body	.225"-1.150"	L24-20P	•	•	•
<b>FLANGED INLETS &amp; OUTLETS</b>								
L820FI	20	480	Gray Inlet		L8-20P	•		•
L820FO	20	480	Gray Outlet		L8-20R	•		•
L920FI	20	600	Gray Inlet		L9-20P	•		•
L920FO	20	600	Gray Outlet		L9-20R	•		•
L3720FO	20	347	Gray Outlet		L24-20R			•

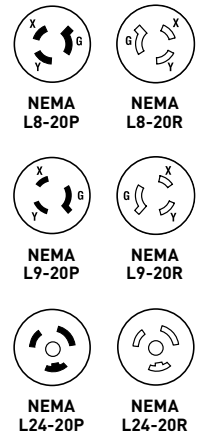

Reference Pages G-38 and G-39 for Accessories.

CATALOG NUMBER	DESCRIPTION	COLOR
<b>WEATHERPROOF COVER</b>		
WPG2	Cover for 20 and 30A Turnlok Flanged Inlets and Outlets	Gray
<b>STAINLESS STEEL WALL PLATE</b>		
SS720	Wall Plate for Locking Receptacles	302/304 S/S



SS720