

Plastic-Handle Screwdrivers

Cabinet-Tip Screwdrivers – Round-Shanks

Additional Features:

- Small-diameter shank for use in recessed holes or tight places.
- Well-suited for electrical and telecommunications work.

Cat. No.	Shank Tip Width	Shank Length	Overall Length	Weight (lbs.)
A230-2	1/8" (3.2 mm)	2" (51 mm)	5" (127 mm)	.05
A216-2	1/8" (3.2 mm)	2" (51 mm)	5" (127 mm)	.05
A216-3	1/8" (3.2 mm)	3" (76 mm)	6" (152 mm)	.05
A216-4	1/8" (3.2 mm)	4" (102 mm)	7" (178 mm)	.05
A216-6	1/8" (3.2 mm)	6" (152 mm)	9" (228 mm)	.05
A216-8	1/8" (3.2 mm)	8" (203 mm)	11" (279 mm)	.05




Cat. No.	Shank Tip Width	Shank Length	Overall Length	Weight (lbs.)
A216-10	1/8" (3.2 mm)	10" (254 mm)	13" (330 mm)	.05
A316-3	3/16" (4.8 mm)	3" (76 mm)	6-5/8" (168 mm)	.10
A316-4	3/16" (4.8 mm)	4" (102 mm)	7-5/8" (194 mm)	.10
A316-6	3/16" (4.8 mm)	6" (152 mm)	9-5/8" (244 mm)	.10
A316-8	3/16" (4.8 mm)	8" (203 mm)	11-5/8" (295 mm)	.15
A316-10	3/16" (4.8 mm)	10" (254 mm)	13-5/8" (346 mm)	.20

Profiliated Phillips-Tip Screwdrivers – Round-Shanks

Additional Features:

- Oversized handle is 35% larger than comparable screwdriver handles.
- Delivers up to 50% extra power to perform tough jobs with minimum effort.

Cat. No.	Point Size	Shank Length	Overall Length	Weight (lbs.)
BD111	No. 1	3" (76 mm)	6-5/8" (168 mm)	.10
BD122	No. 2	4" (102 mm)	8-1/2" (216 mm)	.20
BD133	No. 3	6" (152 mm)	11-3/16" (284 mm)	.35
P18	No. 1	8" (203 mm)	11-1/2" (292 mm)	.15

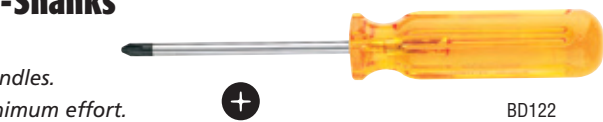

Cat. No.	Point Size	Shank Length	Overall Length	Weight (lbs.)
P28	No. 2	8" (203 mm)	11-5/8" (295 mm)	.20
P212	No. 2	12" (305 mm)	15-5/8" (397 mm)	.25
P202	No. 2	20" (508 mm)	24-1/2" (622 mm)	.55

Specialty Plastic-Handle Screwdrivers

Ratcheting Screwdriver Set


- Slotted and Phillips-tip set.
- Contains a unique 3-position ratcheting screwdriver plus an assortment of blade types and/or sizes.
- Comfortable handle with an easy-to-open snap top.
- Interchangeable bits store inside the handle for quick access.



Cat. No.	Bits Included	Shank Length with Bits	Overall Length	Weight (lbs.)
32473	3/16" and 9/32" slotted plus No. 1 and No. 2 Phillips	4-1/4" (108 mm)	8-3/4" (222 mm)	.40

Magnetic Screwdriver Set

- Each screwdriver has a powerful magnet built into its shank to hold interchangeable bits and also screws.
- Comfortable handle for easier driving.
- Interchangeable bits store inside handle for quick access.
- Wide selection of bits for different screw types.

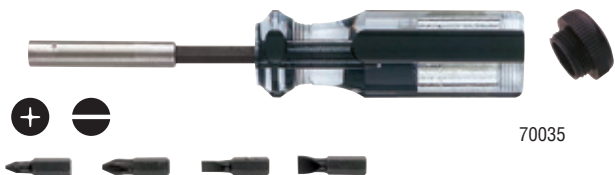

Cat. No.	Bits Included	Shank Length with Bits	Overall Length	Weight (lbs.)
70035	3/16" and 9/32" slotted and No. 1 and No. 2 Phillips	3-3/4" (95 mm)	7-1/4" (184 mm)	.25

All dimensions are in inches and (millimeters).

WARNING: Always wear approved eye protection.

WARNING: NOT insulated. Will NOT protect against electrical shock.

WARNING: Do NOT use to pry or chisel.

