

Ordinary Location Fittings — Hubs

Unique sealing ring and groove design for optimum performance!

OCAL-BLUE Double-Coat and Stainless Steel Hubs




- Captive sealing ring won't buckle or slip during installation and provides a complete 360° seal — even when conduit isn't perpendicular to the enclosure.
- Hexagonal/splined body and locknut enables fast and easy installation.
- Insulated throat molded from 105°C-rated thermoplastic, UL94V0 flammability rated.
- Sharper and deeper teeth provide a more penetrating bite for improved bonding to the enclosure.
- Zinc or copper-free aluminum with a nominal .040" (40 mils) PVC coating bonded to exterior.
- Pressure-sealing sleeves protect your connections.

Ocal™ Corrosion Protection for Electrical Conduit and Fittings

Cat. No.	Colour
HUB 1 -	—
— = space for colour identifier	
G =	Grey
W =	White
B =	Blue
R =	Red

Custom colours also available - Std. min. quantities are required. Please contact your Regional Sales Office.

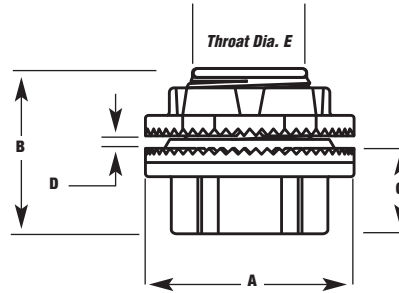

Knockout Hubs

PVC-Coated Zinc Hub Cat. No.	PVC-Coated Aluminum Hub Cat. No.	PVC-Coated Zinc Grounded Hub Cat. No.	Pipe Size in. (mm)	Dimensions (Uncoated Hub)				
				A (Overall Dia.)	B	C	D (Max. Panel Thickness)	E (Throat Dia.)
HUB1/2- <u> </u>	HUB1/2SA- <u> </u>	STG1- <u> </u>	1/2 (16)	1.44 (36.58)	1.56 (39.62)	0.88 (22.35)	0.19 (4.83)	0.59 (14.99)
HUB3/4- <u> </u>	HUB3/4SA- <u> </u>	STG2- <u> </u>	3/4 (21)	1.44 (36.58)	1.59 (40.39)	0.91 (23.11)	0.19 (4.83)	0.78 (19.81)
HUB1- <u> </u>	HUB1SA- <u> </u>	STG3- <u> </u>	1 (27)	2.00 (50.80)	1.81 (45.97)	1.06 (26.92)	0.25 (6.35)	1.00 (25.40)
HUB1-1/4- <u> </u>	HUB1-1/4SA- <u> </u>	STG4- <u> </u>	1-1/4 (35)	2.38 (60.45)	1.88 (47.75)	1.06 (26.92)	0.25 (6.35)	1.31 (6.35)
HUB1-1/2- <u> </u>	HUB1-1/2SA- <u> </u>	STG5- <u> </u>	1-1/2 (41)	2.75 (69.85)	1.88 (47.75)	1.06 (26.92)	0.25 (6.35)	1.53 (38.86)
HUB2- <u> </u>	HUB2SA- <u> </u>	STG6- <u> </u>	2 (53)	3.25 (82.55)	1.94 (49.28)	1.16 (29.46)	0.25 (6.35)	1.97 (50.04)
HUB2-1/2- <u> </u>	HUB2-1/2SA- <u> </u>	STG7- <u> </u>	2-1/2 (63)	3.75 (95.25)	2.56 (65.02)	1.56 (39.62)	0.25 (6.35)	2.41 (61.21)
HUB3- <u> </u>	HUB3SA- <u> </u>	STG8- <u> </u>	3 (78)	4.38 (111.25)	2.44 (61.98)	1.59 (40.39)	0.25 (6.35)	2.97 (75.44)
HUB3-1/2- <u> </u>	HUB3-1/2SA- <u> </u>	STG9- <u> </u>	3-1/2 (91)	5.00 (127.00)	2.72 (69.09)	1.63 (41.40)	0.25 (6.35)	3.41 (86.61)
HUB4- <u> </u>	HUB4SA- <u> </u>	STG10- <u> </u>	4 (103)	5.50 (139.70)	2.72 (69.09)	1.63 (41.40)	0.25 (6.35)	3.88 (98.55)
HUB5- <u> </u>	HUB5SA- <u> </u>	STG11- <u> </u>	5 (129)	6.88 (174.75)	3.03 (76.96)	1.94 (49.28)	0.25 (6.35)	4.94 (125.48)
HUB6- <u> </u>	HUB6SA- <u> </u>	STG12- <u> </u>	6 (155)	7.69 (195.33)	3.16 (80.26)	2.00 (50.80)	0.31 (7.87)	6.00 (152.40)