


## Insulated Metal Grounding Bushings

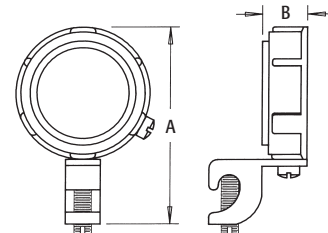

Threaded. With dual rated CU-AL C-clamp grounding lug. Zinc die-cast. 150° C rated.

CATALOG NUMBER	UPC/DCI/NAED MFG #018997	TRADE SIZE	GROUND MIN	WIRE MAX	UNIT PKG	STD PKG	DIM A	DIM B	THREADS/ INCH
450	00450	1/2	14	4	25	100	1.896	.475	14
451	00451	3/4	14	4	25	100	2.082	.520	14
452	00452	1	14	4	25	100	2.364	.575	11-1/2
453	00453	1-1/4	14	4	20	80	2.702	.635	11-1/2
453100	01453	1-1/4	14	1/0	20	20	2.702	.635	11-1/2
454	00454	1-1/2	14	2	20	80	3.120	.760	11-1/2
454100	01454	1-1/2	14	1/0	20	20	3.120	.760	11-1/2
455	00455	2	14	2	10	50	3.650	.755	11-1/2
455100	01455	2	14	1/0	10	10	3.650	.755	11-1/2
456	00456	2-1/2	14	2/0	5	20	4.705	.960	8
456250	01456	2-1/2	6	250MCM	10	10	4.705	.960	8
457	00457	3	14	2/0	5	20	5.275	.920	8
457250	01457	3	6	250MCM	10	10	5.275	.920	8
458	00458	3-1/2	14	2/0	5	20	6.266	.930	8
458250	01458	3-1/2	6	250MCM	5	5	6.266	.930	8
459	00459	4	14	2/0	5	20	6.268	.950	8
459250	01459	4	6	250MCM	5	5	6.268	.950	8
4591	04591	5	8	2/0	5	5	7.050	.990	8
4591250	45912	5	2	250MCM	5	5	7.050	.990	8
4592	04592	6	8	2/0	5	5	8.125	.975	8
4592250	45922	6	2	250MCM	5	5	8.125	.975	8



## Ground Rod Clamps



Conductor range 8 solid, 2-stranded. Approved for direct burial. Solid brass alloy with bronze screw.

CATALOG NUMBER	UPC/DCI/NAED MFG #018997	ROD SIZE	UNIT PKG	STD PKG	DIM A	DIM B
780	00780	1/2	25	25	1.250	.875
781	00781	5/8	25	100	1.275	.593
782	00782	3/4	25	25	1.445	1.030

