


## Hart lock industrial grade 30A locking devices

### Product description

3-pole, 4-wire grounding  
 30A, 3Ø 480V/AC  
 NEMA L16-30

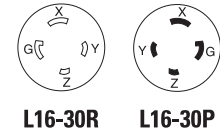

AHL1630R



AHL1630FI



AHL1630P

### Industrial grade plugs & connectors

Rating	V/AC	NEMA	Description	Cord diameter	Color	Plug catalog no.	Connector catalog no.		
30	480	L16-30	3Ø ultra grip straight body	0.38-1.16" (9.5-29.4mm)	BK & W	<input type="checkbox"/> AHL1630P	<input type="checkbox"/> AHL1630C		

### Industrial grade receptacles

Rating	V/AC	NEMA	Description	Color	Single receptacle		
30	480	L16-30	Standard industrial	BK	<input type="checkbox"/> AHL1630R		


### Industrial grade flanged inlets & outlets

Rating	V/AC	NEMA	Description	Color	Flanged inlet	Flanged outlet		
30	480	L16-30	Standard industrial	BK	<input type="checkbox"/> AHL1630FI	—		
			Standard industrial	BK & W	—	<input type="checkbox"/> AHL1630FO**		

\*\*UL Listed only

### Accessories for L16-30 locking devices

Description	Catalog no.		
Neoprene weather protective boot for 4-W & 5-W plugs	<input type="checkbox"/> BL1		
Neoprene weather protective boot for 4-W & 5-W connectors	<input type="checkbox"/> BL2		
Diecast aluminum single receptacle cover, vertical mount, for FS/FD boxes	<input type="checkbox"/> 7420		
Glass-filled nylon flanged inlet/outlet cover, vertical mount, for 30A devices	<input type="checkbox"/> WP2		

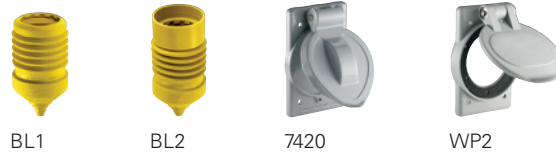

BL1

BL2

7420

WP2

**Dimensional information:**  
 C-76-C-78

**Plug & connector specification information:**

Ultra grip K15-30: C-84

**Receptacle specification information:**

K15-30: C-87

Isolated ground K15-30: C-87

**Flanged inlet & flanged outlet specification information:**

K15-30: C-89

### Color information:

BK (Black), W (White)



(Black)

(White)

Compliances, specifications and availability are subject to change without notice.

Indicates NAFTA compliant - Page Q-30

RoHS compliant - Page Q-30