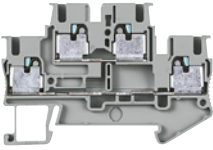
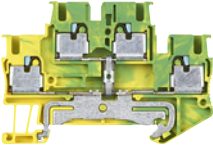

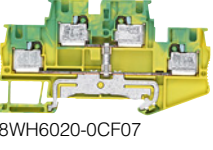

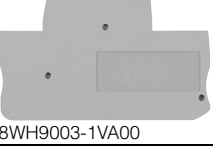



Selection and ordering data

Version	DT	Article No. www.siemens.com/ product?Article No.	Price per PU	PU (UNIT, SET, M)	PS*/ P. unit	PG
Terminal size 2.5 mm²						
 8WH6020-0AF00		Two-tier terminals, terminal size 2.5 mm² <ul style="list-style-type: none"> Terminal width 5.2 mm $I_{max} = 26$ A $U_{max} = 500$ V AWG 26 ... 12 Connection capacity, one conductor <ul style="list-style-type: none"> Rigid 0.14 ... 4 mm² Flexible 0.14 ... 2.5 mm² 				
Versions						
<ul style="list-style-type: none"> Without equipotential bonding <ul style="list-style-type: none"> Gray Blue With equipotential bonding 		8WH6020-0AF00 8WH6020-0AF01 8WH6025-0AF00		1 50 units	1BT	
 8WH6020-0CF07		PE two-tier terminals, terminal size 2.5 mm² <ul style="list-style-type: none"> Terminal width 5.2 mm AWG 26 ... 12 Connection capacity, one conductor <ul style="list-style-type: none"> Rigid 0.14 ... 4 mm² Flexible 0.14 ... 2.5 mm² Green/yellow 				
Note						
Bridging the terminal is only possible in the top tier (in the center).						
Terminal size 4 mm²						
 8WH6025-0AG00		Two-tier terminals, terminal size 4 mm² <ul style="list-style-type: none"> Terminal width 6.2 mm $I_{max} = 32$ A $U_{max} = 500$ V AWG 24 ... 10 Connection capacity, one conductor <ul style="list-style-type: none"> Rigid 0.2 ... 6 mm² Flexible 0.2 ... 4 mm² 				
Versions						
<ul style="list-style-type: none"> Without equipotential bonding <ul style="list-style-type: none"> Gray Blue With equipotential bonding 		8WH6020-0AG00 8WH6020-0AG01 8WH6025-0AG00		1 50 units	1BT	
 8WH6020-0CG07		PE two-tier terminals, terminal size 4 mm² <ul style="list-style-type: none"> Terminal width 6.2 mm AWG 24 ... 10 Connection capacity, one conductor <ul style="list-style-type: none"> Rigid 0.2 ... 6 mm² Flexible 0.2 ... 4 mm² Green/yellow 				
Note						
Bridging the terminal is only possible in the top tier (in the center).						
Accessories						
 8WH9000-4SE00		Covers, for terminal size 1.5 ... 2.5 mm² <ul style="list-style-type: none"> Width 2.2 mm Gray 	8WH9000-4SE00		100 50 units	1BT
 8WH9003-1VA00		Covers, for terminal size 1.5 ... 4 mm² <ul style="list-style-type: none"> For two clamping points Width 2.2 mm 	8WH9003-1VA00		100 50 units	1BT
 8WH9070-0BA00		Compartment partitions, for terminal size 1.5 ... 4 mm² <ul style="list-style-type: none"> For visual and electrical separation of terminal groups 2 mm thick Gray 	8WH9070-0BA00		100 50 units	1BT

For general accessories for 8WH terminal blocks, see chapter "Accessories for 8WH Terminal Blocks"