




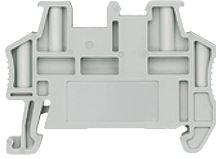


### Selection and ordering data

Version	DT	Article No. <a href="http://www.siemens.com/product?Article No.">www.siemens.com/ product?Article No.</a>	Price per PU	PU (UNIT, SET, M)	PS*/ P. unit	PG
 <p><b>Modular test plugs</b> For individual assembly of test plug connectors</p> <p>Versions</p> <ul style="list-style-type: none"> <li>• For terminal width 4.2 mm and terminal size 1.5 mm<sup>2</sup> 1)</li> <li>• For terminal width 5.2 mm and terminal size 2.5 mm<sup>2</sup> 1)</li> <li>• For terminal width 6.2 mm and terminal size 6 mm<sup>2</sup> 1)</li> </ul> <p>1) Excluding 8WH3</p>		<p>8WH9010-0DB02</p> <p>8WH9010-0EB02</p> <p>8WH9010-0FB02</p>		<p>1</p> <p>1</p> <p>1</p>	<p>10 units</p> <p>10 units</p> <p>10 units</p>	<p>044</p> <p>044</p> <p>044</p>
 <p><b>Spacer plates</b> For leaving out single terminals for individual test plug assembly</p> <p>Versions</p> <ul style="list-style-type: none"> <li>• For terminal width 4.2 mm and terminal size 1.5 mm<sup>2</sup> 1)</li> <li>• For terminal width 5.2 mm and terminal size 2.5 mm<sup>2</sup> 1)</li> <li>• For terminal width 6.2 mm and terminal size 6 mm<sup>2</sup> 1)</li> </ul> <p>1) Excluding 8WH3</p>		<p>8WH9010-2AA02</p> <p>8WH9010-2BA02</p> <p>8WH9010-2CA02</p>		<p>1</p> <p>1</p> <p>1</p>	<p>10 units</p> <p>10 units</p> <p>10 units</p>	<p>044</p> <p>044</p> <p>044</p>
 <p><b>Terminal strip markers, for end retainers</b></p> <ul style="list-style-type: none"> <li>• Height-adjustable</li> <li>• For quick-fit end retainers</li> <li>• Facility for labeling with terminal strip marker or two labels, front, for terminal width 10.2 mm</li> <li>• Labeling field size: 20 x 8 mm</li> </ul>		8WH9150-1CA00		1	100 units	044
 <p><b>Test adapters</b></p> <ul style="list-style-type: none"> <li>• For 4 mm Ø PS test plugs and 4 mm Ø safety test plugs</li> <li>• Makes contact in the bridge shaft</li> </ul>		8WH9010-0JB00		1	10 units	044
 <p><b>Reducing combs</b></p> <p>Versions</p> <ul style="list-style-type: none"> <li>• For bridging of a through-type terminal, terminal size 2.5 or 4 mm<sup>2</sup> <ul style="list-style-type: none"> <li>- For a through-type terminal, terminal size 1.5 mm<sup>2</sup></li> <li>- For a through-type terminal, terminal size 6 mm<sup>2</sup></li> <li>- For a through-type terminal, terminal size 10 mm<sup>2</sup></li> <li>- For a through-type terminal, terminal size 16 mm<sup>2</sup></li> <li>- For a through-type terminal, terminal size 35 mm<sup>2</sup></li> </ul> </li> <li>• For bridging of a through-type terminal, terminal size 16 mm<sup>2</sup> <ul style="list-style-type: none"> <li>- For a through-type terminal, terminal size 35 mm<sup>2</sup></li> </ul> </li> </ul> <p>Note</p> <p>Not for 8WH1 through-type terminals and 8WH3 insulation displacement terminals.</p>		<p>8WH9020-0CC10</p> <p>8WH9020-0FC10</p> <p>8WH9020-0AC10</p> <p>8WH9020-0BC10</p> <p>8WH9020-0EC10</p> <p>8WH9020-0DC10</p>		<p>1</p> <p>1</p> <p>1</p> <p>1</p> <p>1</p> <p>1</p>	<p>10 units</p> <p>10 units</p> <p>10 units</p> <p>10 units</p> <p>10 units</p> <p>10 units</p>	<p>044</p> <p>044</p> <p>044</p> <p>044</p> <p>044</p> <p>044</p>
 <p><b>Quick-fit end retainers</b> Facility for labeling with labels, front, for terminal width 5.2 mm and terminal strip marker</p>		8WH9150-0CA00		1	50 units	044