

PAT600

PATRIOT® 6-Ton, Latch Head Hydraulic Self-Contained, 18V Lithium-Ion

- Permanent functional D3 groove (no die needed)
- Uses W, X, W-VT style dies
- 180° head rotation
- Enhanced clearance for tap connections
- Includes 2 batteries, charger, and polymer carrying case
- **EP Enhanced Power** labeled tools accept 2.0, 3.0, 4.0, and 5.0Ah Makita batteries

For Use On:

Copper #8 -600 kcmil

Terminals: YA, YA-L

Splices: YS-L, YS, YS-T, Y-R

Copper Flex #8 - 350 kcmil Flex

Terminals: YA-FX, YAV, YA-L-FX

Splices: YS, YSV-FXB

Aluminum #8 - 350 kcmil

Terminals: YA-A, YA-A-TN

Splices: YS-A

Variations: (additional variations may be available)

Catalog Number:	Description:
PAT600LI	with 3.0Ah Li-Ion batteries
PAT600L5	with 5.0Ah Li-Ion batteries



Specifications:

Output Force:	6 Tons
Tool Weight:	10.1 lbs
Size:	14.50" x 13.75" x 3.50"
Die Style:	W, V, W-VT style dies
Operating Voltage:	18 V-DC Lithium-Ion
Recharge Time:	30 minutes (3.0Ah) 45 minutes (5.0Ah)
Warranty:	5 year limited warranty Lifetime warranty on INFINITY DRIVE® 3 year on batteries and charger

Accessories:

Catalog Number:	Description:
BAT18VLI:	3.0Ah Li-Ion battery
BAT18V5AHLI:	5.0Ah Li-Ion battery
PATCHGRLLI:	120V-AC Charger
PATCHGRLLIDC:	12/24V-DC Charger
PT208620:	Lanyard
WDIETREE:	W die holder

PAT500SJ6

PATRIOT® 6-Ton, Scissor Action
Hydraulic Self-Contained, 18V Lithium-Ion

- Interchangeable scissor action crimping and cutting jaws
- 180° head rotation
- Uses W and X style dies
- Ergonomically balanced tool design
- Includes 2 batteries, charger, and polymer carrying case
- **EP Enhanced Power** labeled tools accept 2.0, 3.0, 4.0, and 5.0Ah Makita batteries



For Use On:

Copper, Aluminum, ACSR, Steel, Copperweld, Alumoweld, 6201, 5005, Compressed, and Compact Conductors

Taps:

Copper: #10 sol. to 2/0 str.
Aluminum & ACSR: #14 sol. to 4/0 ACSR

Stirrups:

#6 to 4/0 ACSR

Overhead Full Tension Deadends, Full Tension Splices and Terminals:

#10 str. to 4/0 ACSR

Installs Splices, Taps or Terminations:

#8 to 500 kcmil Copper Stranded (YA, YA-L, YS, YS-L)
#8 to 350 kcmil Copper Flex
#8 to 350 kcmil Aluminum (YA-A, YS-A)

Variations: (additional variations may be available)

Catalog Number:	Description:
PAT500SJ6LI	BG and D3 grooves (3.0Ah)
PAT500SJ68LI	O and D3 grooves (3.0Ah)
PAT500SJ66LI	D3 groove only (snub-nose) (3.0Ah)
PAT500SJ6L5	BG and D3 grooves (5.0Ah)
PAT500SJ68L5	O and D3 grooves (5.0Ah)
PAT500SJ66L5	D3 groove only (snub-nose) (5.0Ah)

Kits:

Catalog Number:	Description:
PAT500SJ6LICUTKIT1	Kit includes crimp head with BG & D3 grooves, cutter jaw, 120V charger and 2 batteries (3.0Ah)
PAT500SJ68LICUTKIT1	Kit includes crimp head with O & D3 grooves, cutter jaw, 120V charger and 2 batteries (3.0Ah)

Specifications:

Output Force:	6 Tons
Tool Weight:	11.5 lbs
Size:	17.00" X 14.25" X 3.00"
Die Style:	W and X (with crimping jaws)
Operating Voltage:	18 V-DC Lithium-Ion
Recharge Time:	30 minutes (3.0Ah) 45 minutes (5.0Ah)
Warranty:	5 year limited warranty Lifetime warranty on INFINITY DRIVE® 3 year on batteries and charger

Accessories:

Catalog Number:	Description:
BAT18VLI:	3.0Ah Li-Ion battery
BAT18V5AHLI:	5.0Ah Li-Ion battery
PATCHGRLLI:	120V-AC Charger
PATCHGRLLDC:	12/24V-DC Charger
PATMD6JC:	Jaw covers for PATMD6 and PATMD68 versions
PATMD66JC:	Jaw covers for PATMD66 snub-nose versions
PT10074020:	Wrist strap
W28K:	Cutter Dies (cuts 4-4/0 Cu, Al, ACSR)
WDIETREE:	W-die holder for 6 die sets

Interchangeable Jaw Assemblies:

Catalog Number:	Description:
PATJAWSMD6	BG and D3 grooves
PATJAWSMD68	O and D3 grooves
PATJAWSMD66	D3 groove only (snub-nose)
PATJAWSCUT	Cutter jaw set

See Important Notes on Page N-6.

PATMD6LIWCJ

6-Ton, IN-LINE®, Crimp/Cut Kit
Hydraulic Self-Contained, 18V Lithium-Ion

- Interchangeable scissor action crimping and cutting jaws included
- 350° head rotation; trigger lock
- Actuated blade guide (with cutting jaws)
- Kit includes tool, crimping jaw, cutting jaw, 2 batteries, charger, and soft carrying case

For Use On:

Crimping:

Copper, Aluminum, ACSR, Steel, Copperweld, Alumoweld, 6201, 5005, Compressed, and Compact Conductors

Taps:

Copper: #10 sol. to 2/0 str.
Aluminum & ACSR: #14 sol. to 4/0 ACSR

Stirrups:

#6 to 4/0 ACSR

Overhead Full Tension Deadends, Full Tension Splices and Terminals:

#10 str. to 4/0 ACSR

Installs Splices, Taps or Terminations:

#8 to 500 kcmil Copper Stranded (YA, YA-L, YS, YS-L)
#8 to 350 kcmil Copper Flex
#8 to 350 kcmil Aluminum (YA-A, YS-A)

Cutting Capacity (Maximum):

ACSR:

556 kcmil (26/7 Dove)

AAC:

636 kcmil

Copper:

500 kcmil soft drawn copper



Specifications:

Output Force:	6 Tons
Tool Weight:	7.8 lbs
Size:	21.00" x 5.50" x 3.75"
Die Style:	W and X (with crimping jaws)
Operating Voltage:	18 V-DC Lithium-Ion
Recharge Time:	30 minutes
Warranty:	5 year limited warranty Lifetime warranty on INFINITY DRIVE® 3 year on batteries and charger

Variations: (additional variations may be available)

Catalog Number:	Description:
PATMD6LIWCJ	BG & D3 Grooves, soft case
PATMD68LIWCJ	O & D3 Grooves, soft case
PATMD66LIWCJ	D3 Groove only (Snub-nose), soft case
PATMD6KLIWCJ	KEARNEY™ (Snub-nose), hard case

Accessories:

Catalog Number:	Description:
BAT18VLI:	Hi-capacity LI battery (3.0 AH)
PATCHGRLI:	120V-AC Charger
PATCHGRLLDC:	12/24V-DC Charger
PATMD6JC:	Jaw covers for PATMD6 and PATMD68 versions
PATMD66JC:	Jaw covers for PATMD66 snub-nose versions
PATMD6KJC:	Jaw covers for PATMD6K snub-nose versions
W28K:	Cutter Dies (cuts 4-4/0 Cu, Al, ACSR)
WDIETREE:	W die holder for 6 sets (sold separately)
TOOLBAGMDLI:	Replacement Tool Bag
PT10074020:	Wrist Strap

See Important Notes on Page N-6.

PATMD6LICUTKIT1

6-Ton, IN-LINE®, Crimp/Cut Kit Hydraulic Self-Contained, 18V Lithium-Ion

- Interchangeable scissor action crimping and cutting jaws included
- 350° head rotation; trigger lock
- Actuated blade guide (with cutting jaws)
- Kit includes tool, crimping jaw, cutting jaw, 2 batteries, charger, and hard plastic carrying case

For Use On:

Crimping:

Copper, Aluminum, ACSR, Steel, Copperweld, Alumoweld, 6201, 5005, Compressed, and Compact Conductors

Taps:

Copper: #10 sol. to 2/0 str.

Aluminum & ACSR: #14 sol. to 4/0 ACSR

Stirrups:

#6 to 4/0 ACSR

Overhead Full Tension Deadends, Full Tension Splices and Terminals:

#10 str. to 4/0 ACSR

Installs Splices, Taps or Terminations:

#8 to 500 kcmil Copper Stranded (YA, YA-L, YS, YS-L)

#8 to 350 kcmil Copper Flex

#8 to 350 kcmil Aluminum (YA-A, YS-A)

Cutting Capacity (Maximum):

ACSR:

556 kcmil (26/7 Dove)

AAC:

636 kcmil

Copper:

500 kcmil soft drawn copper



Includes
Case

Specifications:

Output Force:	6 Tons
Tool Weight:	7.8 lbs
Size:	21.00" x 5.50" x 3.75"
Die Style:	W and X (with crimping jaws)
Operating Voltage:	18 V-DC Lithium-Ion
Recharge Time:	30 minutes
Warranty:	5 year limited warranty Lifetime warranty on INFINITY DRIVE® 1 year on batteries and charger

Variations: (additional variations may be available)

Catalog Number:	Description:
PATMD6LICUTKIT1	BG & D3 Grooves, hard case
PATMD68LICUTKIT1	O & D3 Grooves, hard case
PATMD66LICUTKIT1	D3 Groove only (Snub-nose), hard case
PATMD6KLICUTKIT1	KEARNEY™ (Snub-nose), hard case

Accessories:

Catalog Number:	Description:
BAT18VLI:	Hi-capacity LI battery (3.0 AH)
PATCHGRLL:	120V-AC Charger
PATCHGRLLDC:	12/24V-DC Charger
PATMD6JC:	Jaw covers for PATMD6 and PATMD68 versions
PATMD66JC:	Jaw covers for PATMD66 snub-nose versions
PATMD6KJC:	Jaw covers for PATMD6K snub-nose versions
W28K:	Cutter Dies (cuts 4-4/0 Cu, Al, ACSR)
WDIETREE:	W die holder for 6 sets (sold separately)
PT50025151:	Replacement plastic carry case
PT10074020:	Wrist Strap

See Important Notes on Page N-6.

CSMD6LI

Contractor Series, 6-Ton, IN-LINE®
Hydraulic Self-Contained, 18V Lithium-Ion

- 2 economy versions available with a fixed jaw
- 350° head rotation
- Accepts all BURNDY W and X style die sets
- Safety lock, ergonomically balanced, non-slip grip
- Includes 1 (3.0Ah) battery and charger

For Use On:

Copper, Aluminum, ACSR, Steel, Copperweld, Alumoweld, 6201, 5005, Compressed, and Compact Conductors

Taps:

Copper: #10 sol. to 2/0 str.
Aluminum & ACSR: #14 sol. to 4/0 ACSR

Stirrups:

#6 to 4/0 ACSR

Overhead Full Tension Deadends, Full Tension

Splices and Terminals:

#10 str. to 4/0 ACSR

Installs Splices, Taps or Terminations:

#8 to 500 kcmil Copper Stranded (YA, YA-L, YS, YS-L)
#8 to 350 kcmil Copper Flex
#8 to 350 kcmil Aluminum (YA-A, YS-A)

Variations: (additional variations may be available)

Catalog Number:	Description:
CSMD6LI:	BG and D3 grooves
CSMD68LI:	O and D3 grooves



*Shown: CSMD6-LI
Scissor-action jaws,
safety orange*

Specifications:

Output Force:	6 Tons
Tool Weight:	7.8 lbs
Size:	21.00" x 5.50" x 3.75"
Die Style:	W and X
Operating Voltage:	18 V-DC Lithium-Ion
Recharge Time:	30 minutes
Warranty:	1 year limited warranty tool, battery, and charger

Accessories:

Catalog Number:	Description:
BAT18VLI:	Hi-capacity LI battery (3.0 AH)
PATCHGRLL:	120V-AC Charger
PATCHGRLLDC:	12/24V-DC Charger
PATMD6JC:	Jaw covers for CSMD6 and CSMD68 versions
W28K:	Cutter Dies (cuts 4-4/0 Cu, Al, ACSR)
WDIETREE:	W-die holder for 6 die sets
TOOLBAGMDLI:	Tool bag (sold separately)
PT10074020:	Wrist strap

See Important Notes on Page N-6.

MD6 Series

Hand-Operated HYTOOL™
 Installs full range of connectors #14 - 4/0

- Uses BURNDY® W dies
- Spring loaded positive lock die retainer buttons
- Multiple variations available

For Use On:

Copper, Aluminum, ACSR, Steel, Copperweld, Alumoweld, 6201, 5005, Compressed, and Compact Conductors

Taps:

Copper: #10 sol. to 2/0 str.
 Aluminum & ACSR: #14 sol. to 4/0 ACSR

Stirrups:

#6 to 4/0 ACSR

Overhead Full Tension Deadends, Full Tension Splices and Terminals:

#10 str. to 4/0 ACSR

Installs Splices, Taps or Terminations:

- #8 to 500 kcmil Copper Stranded (YA, YA-L, YS, YS-L)
- #8 to 350 kcmil Copper Flex
- #8 to 350 kcmil Aluminum (YA-A, YS-A)

Variations:

Catalog Number:	Description:
MD6	Permanent BG (5/8) and D3 grooves; with WO die (sold separately) can install the CABLELOK CRIMPIT™ and HYCRIMP™ tap connectors
MD68	Permanent O and D3 grooves; with WBG die (sold separately) can install the CABLELOK CRIMPIT™ and HYCRIMP™ tap connectors
MD66	Snub-nose, permanent D3 groove only
MD637	Permanent 161, 162, 163, 171 dies in jaw (J, M & P, T & X)
MD638	Permanent K, BG, C dies in jaw
MD6K	Snub-nose, accepts KEARNEY™ type O dies; using KWADP adapter (sold separately) will accept BURNDY W and X dies

Hotstick Tools Available - Contact Customer Service



Specifications:

Crimp Force:	4.5 Tons
Life Cycle:	Tested over 90,000 cycles with no adjustments or part replacement
Length:	25.50" x 4.50" x 2.00"
Weight:	6.0 lbs
Die Style:	W and X styles
Warranty:	5 year limited warranty

Variations (continued):

Catalog Number: MD64	Description: Permanent BG (5/8) and D3 grooves; straight fiberglass handles 24" long; fiberglass rated 100kV per foot for 5 min.
MD614	Permanent BG (5/8) and D3 grooves; straight fiberglass handles 19" long with grips; fiberglass rated 100kV per foot for 5 min.
MD612	Permanent O and D3 grooves; straight fiberglass handles 24" long; fiberglass rated 100kV per foot for 5 min.

Accessories:

Catalog Number: WBG:	Description: Common die set for MD68, MD612
WO:	Common die set for MD6, MD64, MD614
KWADP:	Adapter to use BURNDY W and X dies with MD6K variation
WDIETREE:	W die holder for 6 die sets

MD7 Series

Hand-Operated HYTOOL™
Installs full range of connectors #14 - 4/0

- Accepts W and X Dies
- Ergonomic, one-piece composite polymer handles
- Nickel plated jaws and jaw links

For Use On:

Copper, Aluminum, ACSR, Steel, Copperweld, Alumoweld, 6201, 5005, Compressed, and Compact Conductors

Taps:

Copper: #10 sol. to 2/0 str.
Aluminum & ACSR: #14 sol. to 4/0 ACSR

Stirrups:

#6 to 4/0 ACSR

Overhead Full Tension Deadends, Full Tension Splices and Terminals:

#10 str. to 4/0 ACSR

Installs Splices, Taps or Terminations:

#8 to 500 kcmil Copper Stranded (YA, YA-L, YS, YS-L)
#8 to 350 kcmil Copper Flex
#8 to 350 kcmil Aluminum (YA-A, YS-A)

Variations:

Catalog Number:	Description:
MD7	Permanent BG (5/8) and D3 grooves; with WO die (sold separately) can install the CABLELOK CRIMPIT™ and HYCRIMP™ tap connectors
MD78	Permanent O and D3 grooves; with WBG die (sold separately) can install the CABLELOK CRIMPIT™ and HYCRIMP™ tap connectors
MD76	Snub-nose, permanent D3 groove only



Specifications:

Output Force:	4.5 Tons
Size:	25.00" x 4.50" x 2.00"
Weight:	7.0 lbs.
Die Style:	W and X styles
Life Cycle:	Tested over 90,000 cycles with no adjustments or part replacement
Warranty:	5 year limited warranty

Accessories:

Catalog Number:	Description:
WBG:	Common die set for MD78
WO:	Common die set for MD7, MD76
WDIETREE:	W die holder for 6 die sets

MD734R

Hand-Operated POSI-PRESS™

Hand-operated full cycle ratchet tool

- Full stroke ratchet mechanism
- Ergonomical one-piece composite polymer handles
- Allows use of complete W-VT, W-RT and X-RT line of BURNDY dies with die embossment

For Use On:

Copper Lugs/Splices #8 - 500 kcmil:

Types: YA, YA-L, YA-L-TC, YA-L-NT, YS-L, YS, YST, YA-TC

Copper Lugs/Splices #8 - 350 kcmil Flex

Types: YAV-L-TC-FX, YA-LB, YA-TC-FXB, YSV-L, YAV-L-NT-FX, YAV-L-FX, YAV-FXB

Copper Battery Lugs #8 - 350 kcmil Flex

Type: YAG-TC-LD

Thin Wall C-Taps #12 - 3/0 AWG

Type: YC-L

Variations:

Catalog Number:	Description:
MD734R	POSI-PRESS™ Full Cycle Ratchet Tool
MD734RC	MD734R tool with EPDM rubber covering
MD734RKIT1	MD734R tool, metal carrying case and all dies for #8 - 500 kcmil copper HYDENT™ and C-Taps for #12 - 3/0 AWG
MD734	Supplied <u>without</u> the ratchet mechanism
MD734KIT1	MD734 tool (no ratchet mechanism), metal carrying case and all dies for #8 - 500 kcmil copper HYDENT™ and C-Taps for #12 - 3/0 AWG



Specifications:

Crimp Force:	4.5 Tons
Length:	26.00" x 4.50" x 2.00"
Width:	8.00" at handles; 4.50" at jaws
Die Style:	W-VT, W-RT, and X-RT Styles
Handle Material:	Reinforced composite polymer
Warranty:	5 year limited warranty

Accessories:

Catalog Number:	Description:
PT49521:	Metal carry case (sold separately)
PT4925:	Canvas bag (sold separately)
WDIETREE:	W die holder for 6 sets of dies (sold separately)

W Dies

For MD6, MD7, Y500CTHS, PAT500SJ, PAT600, PATMD6 and CSMD Series

* These sizes (250 - 500) for Y500CTHS, MD734, and MD734R only.

** For PAT600 and PAT500SJ series and Y500CTHS only.

Note: N/A = not applicable

Suitable for use on YA, YS, YA-A, YS-A type non-tension connectors.

Die Sets sold separately; W Die Kits also available; see following page



W25RT Die Set

Wire Size	Copper (-VT)	Copper (-RT)	Aluminum
#8 AWG	W8CVT	W8CRT	X8CART
#6 AWG	W5CVT	W5CRT	W161
#4 AWG	W4CVT	W4CRT	W162
#3 AWG	W3CRT	W3CRT	N/A
#2 AWG	W2CVT	W2CRT	W239
#1 AWG	W1CVT	W1CRT1	W163
1/0 AWG	W25VT	W25RT	W241
2/0 AWG	W26VT	W26RT	W245
3/0 AWG	W27VT	W27RT	W166
4/0 AWG	W28VT	W28RT	W660
250 kcmil	W29VT*	W29RT*	W249
300 kcmil	W30VT*	W30RT*	N/A
350 kcmil	W31VT*	W31RT*	W31ART*
400 kcmil	W32VT*	W32RT*	N/A
450 kcmil	W33VT*	W33RT*	N/A
500 kcmil	W34VT*	W34RT*	N/A
600 kcmil	N/A	W36RT**	N/A

VT = "V" profile die for reduced handle force when using MD6/MD7 series tools; Twin die (includes both halves)
RT = Round die (circumferential); Twin die (includes both halves)



WDIETREE available (sold separately); holds up to 6 "W" style die sets (dies not included)



CASEWDIES die box available (sold separately); holds up to 12 "W" or "X" style die sets (dies not included)

W Die Related



WBG Die Set

- Double groove die set
- One (1) crimp per end on service entrance sleeves
- Requires half the number of crimps on other 5/8" sleeves



W28K Cutter Die Set

- Cuts #4 - 4/0 ACSR, Aluminum or Copper



WDIETREE W Die Holder

- Innovative die holder as alternative to the standard die case
- Designed to hold up to 6 W dies
- Shown with die sets (not included)



W687 & W702 Non-Bowing Die Sets

- Install one-piece, full-tension UNISPLICE™ sleeves on ACSR conductors without bowing (sold separately)

W687: Installs #4 ACSR 6/1, 7/1; YDS4RL and YDS4RLY
#2 ACSR 6/1; YS2RL and YDS2RLY

W702: Installs #2 ACSR 7/1; YDS021RL and YDS021RLY
1/0 ACSR; YDS25RL and YDS25RLY



CASEWDIES Compact Die Case

- Space for 12 W or X style dies (not included)

PAT500SJCUT

6-Ton, Scissor Action

Hydraulic Self-Contained, 18V Lithium-Ion

- Interchangeable scissor action crimping and cutting jaws
- 180° head rotation
- Uses W and X style dies with available crimping jaws
- Ergonomically balanced tool design
- Includes 2 batteries, charger, and polymer carrying case
- **EP Enhanced Power** labeled tools accept 2.0, 3.0, 4.0, and 5.0Ah Makita batteries



For Use On:

Maximum Cutting Capacity:

ACSR:

556 kcmil (26/7 Dove)

AAC:

636 kcmil

Copper:

500 kcmil soft drawn copper

Variations: (additional variations may be available)

Catalog Number:	Description:
PAT500SJCUTL1	with 3.0Ah battery
PAT500SJCUTL5	with 5.0Ah battery

Interchangeable Jaw Assemblies / Kits:

Catalog Number:	Description:
PATJAWSMD6	BG and D3 grooves
PATJAWSMD68	O and D3 grooves
PATJAWSMD66	D3 groove only (snub-nose)
PAT500SJ6LICUTKIT1	Kit includes crimp head with BG & D3 grooves, cutter jaw, 120V charger and 2 batteries (3.0Ah)
PAT500SJ68LICUTKIT1	Kit includes crimp head with O & D3 grooves, cutter jaw, 120V charger and 2 batteries (3.0Ah)

Specifications:

Output Force:	6 Tons
Tool Weight:	11.5 lbs
Size:	17.00" X 14.25" X 3.00"
Die Style:	W and X (with crimping jaws)
Operating Voltage:	18 V-DC Lithium-Ion
Recharge Time:	30 minutes (3.0Ah) 45 minutes (5.0Ah)
Warranty:	5 year limited warranty Lifetime warranty on INFINITY DRIVE® 3 year on batteries and charger

Accessories:

Catalog Number:	Description:
BAT18VLI:	3.0Ah Li-Ion battery
BAT18V5AHLI:	5.0Ah Li-Ion battery
PATCHGRLL:	120V-AC Charger
PATCHGRLLDC:	12/24V-DC Charger
PT10074020:	Wrist strap
WDIETREE:	W-die holder for 6 die sets

PATMDALLIF Series

IN-LINE® Angle Pole Cutter / Crimper
 Hydraulic Self-Contained, 18V Lithium-Ion; 82"

- Adjustable Angular Head
- ASTM F711 Rated Pole
- Rocker trigger design for controlled actuation of the tool
- Safety lock to prevent accidental operation
- Includes 2 batteries and charger

For Use On:

Maximum Cutting Capacity:

ACSR:

556 kcmil (26/7 Dove)

AAC:

636 kcmil

Copper:


500 kcmil soft drawn copper

Variations: (additional variations may be available)

Catalog Number:	Description:
PATMDCUT82ALLIF	Cutter jaw; 82" F711 Pole
PATMD682ALLIF	Crimp Jaws (BG & D3); 82" F711 Pole
PATMD6882ALLIF	Crimp Jaws (O & D3); 82" F711 Pole
PATMD6682ALLIF	Crimp Jaws (D3 only); 82" F711 Pole

Kits with Tool, Crimping and Cutting Jaws, Pole:

Catalog Number:	Description:
PATMD682ALLIFWCJ	Kit includes crimp head with BG & D3 grooves, cutter jaw, 120V charger and 2 batteries
PATMD6882ALLIFWCJ	Kit includes crimp head with O & D3 grooves, cutter jaw, 120V charger and 2 batteries
PATMD6682ALLIFWCJ	Kit includes crimp head with D3 groove, cutter jaw, 120V charger and 2 batteries

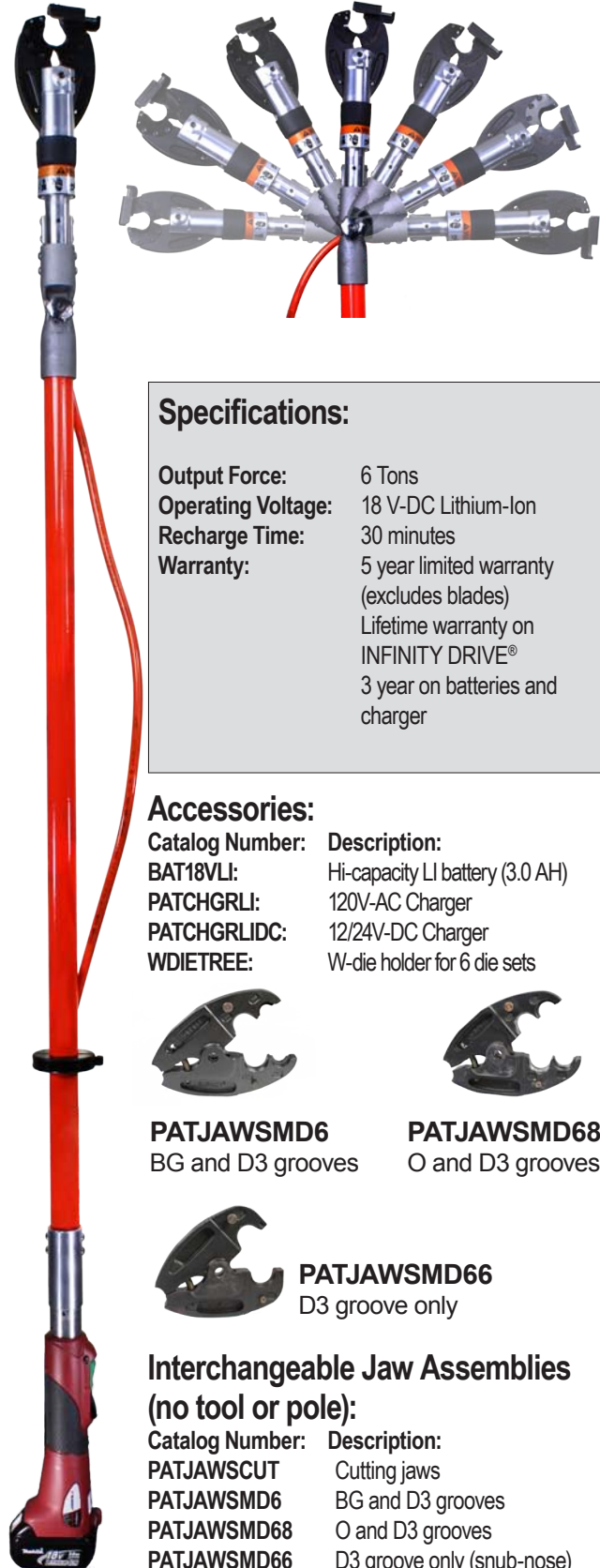

Specifications:

Output Force:	6 Tons
Operating Voltage:	18 V-DC Lithium-Ion
Recharge Time:	30 minutes
Warranty:	5 year limited warranty (excludes blades) Lifetime warranty on INFINITY DRIVE® 3 year on batteries and charger

Accessories:

Catalog Number:	Description:
BAT18VLI:	Hi-capacity LI battery (3.0 AH)
PATCHGRLLI:	120V-AC Charger
PATCHGRLLDC:	12/24V-DC Charger
WDIETREE:	W-die holder for 6 die sets



PATJAWSMD6
BG and D3 grooves



PATJAWSMD68
O and D3 grooves



PATJAWSMD66
D3 groove only

Interchangeable Jaw Assemblies (no tool or pole):

Catalog Number:	Description:
PATJAWSCUT	Cutting jaws
PATJAWSMD6	BG and D3 grooves
PATJAWSMD68	O and D3 grooves
PATJAWSMD66	D3 groove only (snub-nose)

See Important Notes on Page N-6.