

Plastic-Handle Screwdrivers

Midget Screwdriver

Additional Features:

- Specially designed for delicate instrument work.
- Keystone-tip screwdriver.



A000

Cat. No.	Shank Tip Width	Shank Length	Overall Length	Weight (lbs.)
A000	3/32" (2 mm)	1-1/2" (38 mm)	2-7/8" (73 mm)	.02

Pocket-Clip Screwdrivers

Additional Features:

- Round-shank screwdrivers ranging from 3-1/4" (82 mm) to 6-7/16" (164 mm) long.
- Convenient pocket clip.
- Cat. No. A010 has keystone-tip, Cat. No. P12 has Phillips-tip, and all others have cabinet tip.



A116-4



P12

Cat. No.	Shank Tip Width	Shank Length	Overall Length	Weight (lbs.)
Keystone-Tip, and Cabinet-Tip Screwdrivers				
A010	3/32" (2.4 mm)	1-3/8" (35 mm)	3-1/4" (82 mm)	.03
A130-2	1/8" (3.2 mm)	2" (51 mm)	3-7/8" (98 mm)	.05
A130-3	1/8" (3.2 mm)	3" (76 mm)	4-7/8" (124 mm)	.04
A116-2	3/32" (2.4 mm)	2" (51 mm)	4-7/16" (113 mm)	.05
A116-3	3/32" (2.4 mm)	3" (76 mm)	5-7/16" (138 mm)	.03
A116-4	3/32" (2.4 mm)	4" (102 mm)	6-7/16" (164 mm)	.03
A131-2	1/8" (3.2 mm)	2" (51 mm)	4-7/16" (113 mm)	.05

Cat. No.	Point Size	Shank Tip Width	Shank Length	Overall Length	Weight (lbs.)
Phillips-Tip, Pocket-Clip Round-Shank Screwdriver					
P12	No. 0	1/8" (3.2 mm)	2 1/2" (63 mm)	5" (124 mm)	.05

Keystone-Tip Screwdrivers – Square-Shanks

Additional Features:

- Oversized handle is 35% larger than comparable screwdriver handles.
- Delivers up to 50% extra power to perform tough jobs with minimum effort.



BD306

Cat. No.	Shank Tip Width	Shank Length	Overall Length	Weight (lbs.)
BD284	1/4" (6.3 mm)	4" (102 mm)	8-1/2" (216 mm)	.25
BD286	1/4" (6.3 mm)	6" (152 mm)	10-1/2" (267 mm)	.30
BD306	5/16" (7.9 mm)	6" (152 mm)	11-3/16" (284 mm)	.35
BD308	5/16" (7.9 mm)	8" (203 mm)	13-3/16" (335 mm)	.40

Cat. No.	Shank Tip Width	Shank Length	Overall Length	Weight (lbs.)
BD310	5/16" (7.9 mm)	10" (254 mm)	15-3/16" (385 mm)	.50
BD410	3/8" (9.5 mm)	10" (254 mm)	15-3/16" (385 mm)	.60
BD412	3/8" (9.5 mm)	12" (305 mm)	17-3/16" (437 mm)	.75
C718	3/8" (9.5 mm)	18" (457 mm)	23-5/16" (592 mm)	.95

Keystone-Tip Screwdrivers – Round-Shanks

Additional Features:

- Oversized handle is 35% larger than comparable screwdriver handles.
- Delivers up to 50% extra power to perform tough jobs with minimum effort.



BD156

Cat. No.	Shank Tip Width	Shank Length	Overall Length	Weight (lbs.)
BD143	7/32" (5.6 mm)	3" (76 mm)	7-1/2" (190 mm)	.20
BD144	1/4" (6.3 mm)	4" (102 mm)	8-1/2" (216 mm)	.25
BD146	1/4" (6.3 mm)	6" (152 mm)	10-1/2" (267 mm)	.25
BD156	5/16" (7.9 mm)	6" (152 mm)	11-3/16" (284 mm)	.35
BD158	5/16" (7.9 mm)	8" (203 mm)	13-3/16" (335 mm)	.40

Cat. No.	Shank Tip Width	Shank Length	Overall Length	Weight (lbs.)
BD408	3/8" (9.5 mm)	8" (203 mm)	13-3/16" (335 mm)	.50
BD510	3/8" (9.5 mm)	10" (254 mm)	15-3/16" (386 mm)	.55
BD512	3/8" (9.5 mm)	12" (305 mm)	17-3/16" (437 mm)	.60
70155	1/4" (6.3 mm)	20" (508 mm)	24-1/2" (622 mm)	.45

All dimensions are in inches and (millimeters).

WARNING: Always wear approved eye protection.

WARNING: NOT insulated. Will NOT protect against electrical shock.

WARNING: Do NOT use to pry or chisel.



Grip-It® Cabinet-Tip Screwdrivers – Round-Shanks

Additional Feature:

- Narrow cabinet-tip permits blade access where space is limited.

Cat. No.	Shank Tip Width	Shank Length	Overall Length	Weight (lbs.)
19405	7/32" (5.5 mm)	3-15/16" (100 mm)	7-11/16" (195 mm)	.15
19406	7/32" (5.5 mm)	5-7/8" (150 mm)	9-5/8" (245 mm)	.15



19405



Grip-It® Profilated Phillips-Tip Screwdrivers – Round-Shanks

Additional Features:

- Tips are precision-machined to provide a more consistent geometric symmetry than conventional Phillips-tip screwdrivers.
- Provides accurate fit and torque without slippage.

Cat. No.	Point Size	Shank Length	Overall Length	Weight (lbs.)
19445	No. 1	3-1/8" (80 mm)	6-7/8" (175 mm)	.10
19446	No. 2	3-15/16" (100 mm)	8-1/16" (205 mm)	.15



19446



Plastic-Handle Screwdriver Set

Features:

Meets or exceeds applicable ASME / ANSI specifications.

Nickel-chrome, precision-forged and polished blades with black tips.

Smooth Comfortdome® handles fit the palm of the hand comfortably.

Tough amber plastic handle.

Chrome-plated shank helps prevent corrosion.

Internal flanges provide solid, twist-resistant shaft anchor.




7-Piece Combination Screwdriver Set

Additional Features:

- Set contains: Two Phillips-tip screwdrivers, two slotted keystone-tip screwdrivers, three popular cabinet-tip screwdrivers, and plastic POP packaging.

Cat. No.	Set Contains	Weight (lbs.)
85276		1.10

Cat. No.	Description	Shank Length
BD111	No. 1 Phillips-tip	3" (76 mm)
BD122	No. 2 Phillips-tip	4" (102 mm)
BD284	1/4" square-shank, keystone-tip	4" (102 mm)
BD306	5/16" square-shank, keystone-tip	6" (152 mm)
A216-3	1/8" round-shank, cabinet-tip	3" (76 mm)
A216-4	1/8" round-shank, cabinet-tip	4" (102 mm)
A216-6	1/8" round-shank, cabinet-tip	6" (152 mm)

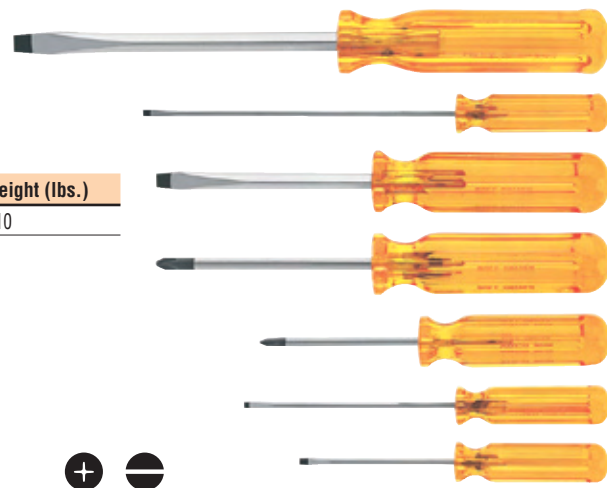

85276



All dimensions are in inches and (millimeters).

⚠ WARNING: NOT insulated. Will NOT protect against electrical shock.

⚠ WARNING: Always wear approved eye protection.

⚠ WARNING: Do NOT use to pry or chisel.

