


Bolted Bronze Connectors

Type 2709T-1 — Ground Connector, Cable to Flat

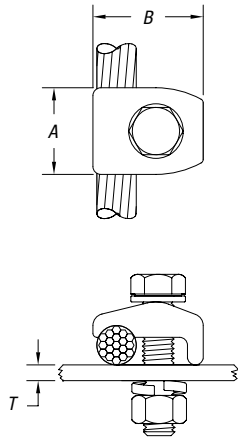


CAT. NO.	CABLE			ROD	A	B
	RANGE	DIAMETER				
2709T-1-4	#8-#4	.129-.232	$\frac{3}{16}$	$1\frac{1}{2}$	$1\frac{1}{16}$	$1\frac{1}{2}$
2709T-1-2/0	#4-2/0	.204-.419	$\frac{3}{8}$			
2709T-1-25	2/0-250	.419-.575	$\frac{1}{2}$	$1\frac{1}{8}$	$1\frac{1}{4}$	$1\frac{1}{4}$
2709T-1-30	#4-300	.204-.630	$\frac{5}{8}$			
2709T-1-50	300-500	.630-.813	$\frac{3}{4}$	$1\frac{1}{2}$	$1\frac{3}{8}$	$2\frac{1}{8}$
2709T-1-75	550-750	.855-.998	$\frac{15}{16}$			
2709T-1-100	800-1000	1.031-1.152	1	$1\frac{1}{8}$	$2\frac{1}{8}$	

1/4" hardware provided for "T".

Specify other "T" if required. e.g. 2709T-1-75-T 1/2

Connectors supplied with clamping hardware in accordance with NEMA standard CC 1.

Type 2709-1 — Ground Connector, Cable to Flat

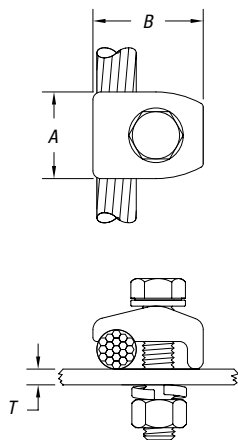


CAT. NO.	CABLE			ROD	A	B
	RANGE	DIAMETER				
2709-1-4	#8-#4	.129-.232	$\frac{3}{16}$	$1\frac{1}{2}$	$1\frac{1}{16}$	$1\frac{1}{16}$
2709-1-2/0	#4-2/0	.204-.419	$\frac{3}{8}$			
2709-1-25	2/0-250	.419-.575	$\frac{1}{2}$	1	$1\frac{1}{8}$	$1\frac{1}{8}$
2709-1-30	#4-300	.204-.630	$\frac{5}{8}$			
2709-1-50	300-500	.630-.813	$\frac{3}{4}$	$1\frac{1}{2}$	$2\frac{1}{4}$	$2\frac{1}{4}$
2709-1-75	550-750	.855-.998	$\frac{15}{16}$			
2709-1-100	800-1000	1.031-1.152	1	$1\frac{1}{8}$	3	

1/4" hardware provided for "T".

Specify other "T" if required. e.g. 2709-1-4-T 1/2

Connectors supplied with clamping hardware in accordance with NEMA standard CC 1.

Type 2709T-2 — Ground Connector, Two Cables to Flat

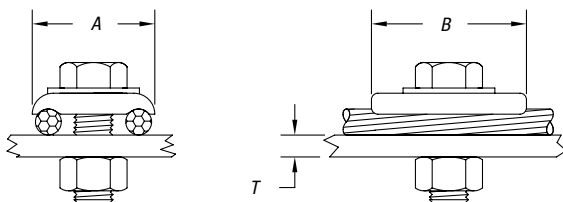

CAT. NO.	CABLE			ROD	A	B
	RANGE	DIAMETER				
2709T-2-4	#8-#4	.129-.232	$\frac{3}{16}$	$1\frac{1}{8}$	$1\frac{1}{2}$	$1\frac{1}{2}$
2709T-2-2/0	#4-2/0	.204-.419	$\frac{3}{8}$			
2709T-2-25	2/0-250	.419-.575	$\frac{1}{2}$	2	$2\frac{1}{2}$	2
2709T-2-30	#4-300	.204-.630	$\frac{5}{8}$			
2709T-2-50	300-500	.630-.813	$\frac{3}{4}$	$2\frac{1}{2}$	$2\frac{3}{4}$	2
2709T-2-75	550-750	.855-.998	$\frac{15}{16}$			
2709T-2-100	800-1000	1.031-1.152	1	$3\frac{1}{8}$		

1/4" hardware provided for "T".

Specify other "T" if required. e.g. 2709-2-4-T 1/2

Connectors supplied with clamping hardware in accordance with NEMA standard CC 1.