



## Down-Lites | 4RLD

4" Basics Series™ LED Retrofit Downlight Baffle Trim

600 Lumen



### Description

Energy efficient LED retrofit module fits into standard 4" IC or Non-IC recessed housings • Replaces 50W incandescent lamp, producing 575 lumens at 11.5W • Dimmable with most standard incandescent dimmers and electronic low voltage dimmers • LED retrofit module is designed to provide 36,000 hours of life • 5 year warranty

### Listings

• UL and cUL classified for use with most standard UL Listed 4" recessed incandescent housings and Juno IC1-LEDT24 and IC1R-LEDT24 • Suitable for wet locations (indoor covered ceilings) • ENERGY STAR® Qualified • Certified to the high efficacy requirements of California T24

### Features

- Installs into existing 4" recessed housings with medium base sockets
- 2700K and 3000K color temperatures available with 90 CRI minimum
- Rated for 36,000 hours at 70% lumen maintenance
- All-in-one design where LED light engine mounts directly to trim for ease of installation
- LED array integrated to one piece high purity aluminum, thermally conductive housing provides uninterrupted heat transfer to ensure long life of the LED
- 120 volts operation
- Dimmable with the use of most standard incandescent, magnetic low voltage and electronic low voltage dimmers
- Retrofit module is compatible with most 4" recessed housings measuring at least 4" high with an inside diameter between 4" and 4 1/2"
- Provided with push-in friction springs
- Trim features quick connect plug installed
- Trim ships with a medium base socket adapter whip for installation into 4" incandescent housings with medium base sockets
- UL and cUL classified for use with 4" incandescent medium based housings and Juno IC1-LEDT24 or IC1R-LEDT24

 

### Ordering Information

Catalog No.	Description
4RLD-927-6-WWH	4" LED retrofit trim, 600 lumen, 2700K, White Baffle
4RLD-930-6-WWH	4" LED retrofit trim, 600 lumen, 3000K, White Baffle

### Options (Compatible Housing)

Catalog No.	Description
IC1-LEDT24	Compatible 4" quick connect housing
IC1R-LEDT24	Compatible 4" quick connect remodel housing

### Dimensions

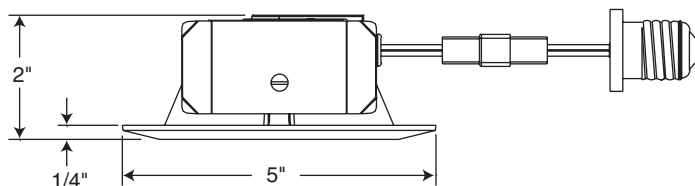

Medium-based socket whip adapter included with trim