

# Wire Strippers/Cutters


## Automatic Wire Stripper – Solid and Stranded Wire

Strips Tefzel® and Teflon® insulation from 16-26 AWG solid and stranded wire.

Applications:

- Tefzel® insulated wire.
- Type-E Teflon® insulated wire.
- Type-EE Teflon® insulated wire.

- Precision blades strip wire without nicking or fraying.
- Fine insulation can be stripped without damage to the conductor.
- To strip, place wire in proper size stripping hole and squeeze handles. Wire is automatically gripped and stripped with the same motion. Release pressure and jaws automatically stay open for removing cleanly stripped wire without crushed end.
- Adjustable wire stop assures uniform stripping lengths.
- Gripper pads firmly hold the Tefzel® and Teflon® wire and prevent damage to the thin insulation.
- Plastic hand grips for comfort.

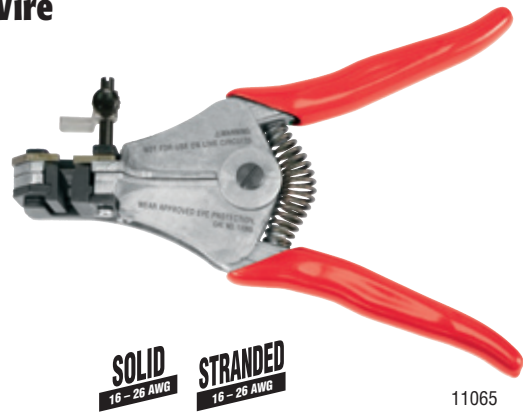

11065

Cat. No.	Length	Handle Color	Strips	Weight (lbs.)
11065	7" (178 mm)	red	16 - 26 AWG solid or stranded (1.0 mm <sup>2</sup> - .14 mm <sup>2</sup> )	.81

Tefzel® and Teflon® are registered trademarks of E.I duPont de Nemours and Company.

## Self-Adjusting Wire Stripper – Solid and Stranded Wire

- Automatically adjusts to the diameter of the wire.
- Cutting blades never touch the conductors, preventing damage to the wire.
- Spring action returns stripper to ready-to-use position.
- Latch holds handles together when not in use.
- Comfortable plastic handles with thumb guard.



74011

Cat. No.	Overall Length	Strips and Cuts	Handle Color	Weight (lbs.)
74011	7" (178 mm)	10 - 24 AWG stranded & solid (4.0 mm <sup>2</sup> - .25 mm <sup>2</sup> )	red	.45

## Combination Wire-Stripping and Cutting Tools

### Multi-Purpose 6-in-1 Tool

- Cleanly shears bolts.
- Easily cuts and strips wire.
- Measures stud sizes.
- Gauges wire sizes.
- Crimps insulated terminals.
- Plastic-covered cushioned handles for comfort.



1000

Cat. No.	Overall Length	Strips and Cuts	Bolt Sizes	Handle Color	Weight (lbs.)
1000	7-3/4" (197 mm)	10 - 22 AWG (4.0 mm <sup>2</sup> - .34 mm <sup>2</sup> )	4-40, 6-32, 8-32, 10-24, 10-32	red	.44

All dimensions are in inches and (millimeters).

**⚠WARNING:** NOT insulated. Plastic-dipped or slip-on plastic handles are NOT intended for protection against electrical shock.

**⚠WARNING:** Never use on or near live electrical circuits.

**⚠WARNING:** Always wear approved eye protection.

