

AF09 ... AF38 4-pole contactors

Main accessories



CA4-10



CAL4-11




CA4-22E



CAT4-11E



VEM4

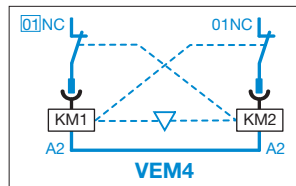

LDC4



BX4



BX4-CA

Ordering details (1)

| For contactors | Auxiliary contacts | | Type | Order code | Pkg qty | Weight (1 pce) |
|----------------|--------------------|--|------|------------|---------|----------------|
| | | | | | | kg |

Front-mounted instantaneous auxiliary contact blocks

| | | | | | | | | |
|------------------------|---|---|---|---|----------|-----------------|----|-------|
| AF09 ... AF38...-40-00 | 1 | 0 | - | - | CA4-10 | 1SBN010110R1010 | 1 | 0.014 |
| AF09 ... AF38...-22-00 | 1 | 0 | - | - | CA4-10-T | 1SBN010110T1010 | 10 | 0.014 |
| | 0 | 1 | - | - | CA4-01 | 1SBN010110R1001 | 1 | 0.014 |
| | 0 | 1 | - | - | CA4-01-T | 1SBN010110T1001 | 10 | 0.014 |
| | 2 | 2 | - | - | CA4-22E | 1SBN010140R1022 | 1 | 0.055 |
| | 3 | 1 | - | - | CA4-31E | 1SBN010140R1031 | 1 | 0.055 |
| | 4 | 0 | - | - | CA4-40E | 1SBN010140R1040 | 1 | 0.055 |
| AF09 ... AF16...-40-00 | 0 | 4 | - | - | CA4-04E | 1SBN010140R1004 | 1 | 0.055 |

Front-mounted auxiliary contact blocks with N.O. leading contact and N.C. lagging contact

| | | | | | | | | |
|------------------------|---|---|---|---|--------|-----------------|---|-------|
| AF09 ... AF38...-40-00 | - | - | 1 | 0 | CC4-10 | 1SBN010111R1010 | 1 | 0.014 |
| AF09 ... AF38...-22-00 | - | - | 0 | 1 | CC4-01 | 1SBN010111R1001 | 1 | 0.014 |

Side-mounted instantaneous auxiliary contact blocks

| | | | | | | | | |
|------------------------|---|---|---|---|-----------|-----------------|----|-------|
| AF09 ... AF38...-40-00 | 1 | 1 | - | - | CAL4-11 | 1SBN010120R1011 | 1 | 0.040 |
| AF09 ... AF38...-22-00 | 1 | 1 | - | - | CAL4-11-T | 1SBN010120T1011 | 10 | 0.040 |

Front-mounted instantaneous auxiliary contact and A1/A2 coil terminal blocks

| | | | | | | | | |
|------------------------|---|---|---|---|----------|-----------------|---|-------|
| AF09 ... AF38...-40-00 | 1 | 1 | - | - | CAT4-11E | 1SBN010151R1011 | 1 | 0.040 |
| AF09 ... AF38...-22-00 | | | | | | | | |

Note: CAT4 not fittable on AF..Z contactors with DC control voltage 12...20 V DC.

Mechanical interlock unit

| | | | | | | | | |
|------------------------|--|--|--|--|-----|-----------------|----|-------|
| AF09 ... AF38...-40-00 | | | | | VM4 | 1SBN030105T1000 | 10 | 0.005 |
|------------------------|--|--|--|--|-----|-----------------|----|-------|

Note: VM4 includes 2 fixing clips (BB4) to maintain together both contactors.

Mechanical and electrical interlock set

| | | | | | | | | |
|---------------------|---|---|---|---|------|-----------------|---|-------|
| AF09, AF16...-40-00 | 1 | 1 | - | - | VEM4 | 1SBN030111R1000 | 1 | 0.035 |
| AF26, AF38...-40-00 | | | | | | | | |

Note: - VEM4 includes a VM4 mechanical interlock unit with 2 fixing clips (BB4), a VE4 electrical interlock block. VE4 block must be used with A2-A2 connection to respect the electrical connection diagram.

- VEM4 not fittable on AF..Z contactors with DC control voltage 12...20 V DC.

Additional coil terminal block

| | | | | | | | | |
|---------------|--|--|--|--|------|-----------------|----|-------|
| AF09 ... AF38 | | | | | LDC4 | 1SBN070156T1000 | 10 | 0.010 |
|---------------|--|--|--|--|------|-----------------|----|-------|

Protective covers

| | | | | | | | | |
|---|--|--|--|--|--------|-----------------|----|-------|
| All 1-stack contactors | | | | | BX4 | 1SBN110108T1000 | 10 | 0.006 |
| For 4-pole CA4 and 2-pole CAT4 auxiliary contact blocks | | | | | BX4-CA | 1SBN110109W1000 | 50 | 0.001 |

(1) See "Main accessory fitting details" table.