




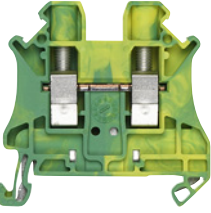


8WH through-type terminals

Version	DT	Article No. www.siemens.com/ product?Article No.	Price per PU	PU (UNIT, SET, M)	PS*/ P. unit	PG
 <p>PE through-type terminals, terminal size 16 mm²</p> <ul style="list-style-type: none"> • I_{NUS}, I_{SC} • Terminal width 12.2 mm • AWG 16-4 • Connection capacity, one conductor <ul style="list-style-type: none"> - Rigid 1.5 ... 25 mm² - Flexible 1.5 ... 25 mm² • Connection capacity, two conductors <ul style="list-style-type: none"> - Rigid 1 ... 6 mm² - Flexible 1 ... 6 mm² • Green/yellow <p>8WH1000-0CK07</p>		8WH1000-0CK07		1 50 units	1BT	
 <p>Through-type terminals, terminal size 35 mm²</p> <ul style="list-style-type: none"> • I_{NUS}, I_{SC} • Terminal width 16 mm • I_{max} = 150 A • U_{max} = 1000 V • AWG 16-1/0 • Connection capacity, one conductor <ul style="list-style-type: none"> - Rigid 1.5 ... 50 mm² - Flexible 1.5 ... 50 mm² • Connection capacity, two conductors <ul style="list-style-type: none"> - Rigid 1.5 ... 16 mm² - Flexible 1.5 ... 10 mm² • Enclosed at both ends <p>8WH1000-0AM00</p>						
<p>Versions</p> <ul style="list-style-type: none"> • Gray • Blue 		8WH1000-0AM00 8WH1000-0AM01		1 50 units 1 50 units	1BT 1BT	
 <p>PE through-type terminals, terminal size 35 mm²</p> <ul style="list-style-type: none"> • I_{NUS}, I_{SC} • Terminal width 16 mm • AWG 16-2 • Connection capacity, one conductor <ul style="list-style-type: none"> - Rigid 1.5 ... 35 mm² - Flexible 1.5 ... 35 mm² • Connection capacity, two conductors <ul style="list-style-type: none"> - Rigid 1.5 ... 16 mm² - Flexible 1.5 ... 10 mm² • Enclosed at both ends • Green/yellow <p>8WH1000-0CM07</p>		8WH1000-0CM07		1 50 units	1BT	
<p>Accessories</p>  <p>Covers, for through-type terminals</p> <ul style="list-style-type: none"> • 2.2 mm wide • Gray <p>8WH9000-1PA00</p>						
<p>Versions</p> <ul style="list-style-type: none"> • For terminal size 2.5 ... 10 mm² • For terminal size 16 mm² 		8WH9000-1PA00 8WH9076-1PA00		100 50 units 100 50 units	1BT 1BT	
 <p>Reducing combs, for connecting terminals, for 8WH1</p> <p>8WH9002-8AC10</p>						
<p>Versions</p> <ul style="list-style-type: none"> • From terminal size 6 mm² to 2.5 or 4 mm² <ul style="list-style-type: none"> - From screw to screw - From screw to spring • From terminal size 10 mm² to 2.5 or 4 mm² <ul style="list-style-type: none"> - From screw to screw - From screw to spring • From terminal size 16 mm² to 2.5 or 4 mm² <ul style="list-style-type: none"> - From screw to screw - From screw to spring • From terminal size 35 mm² to 2.5 or 4 mm² <ul style="list-style-type: none"> - From screw to screw - From screw to spring 		8WH9002-8AC10 8WH9002-8BC10 8WH9002-8CC10 8WH9002-8DC10 8WH9002-8EC10 8WH9002-8FC10 8WH9002-8GC10 8WH9002-8HC10		1 10 units 1 10 units 1 10 units 1 10 units 1 10 units 1 10 units 1 10 units 1 10 units	1BT 1BT 1BT 1BT 1BT 1BT 1BT 1BT	
<p>Compartment partitions, for through-type terminals, for terminal size 2.5 ... 10 mm², for 8WH1</p> <ul style="list-style-type: none"> • For visual and electrical separation of terminal groups • 2 mm thick <p>8WH9070-6BA00</p>		8WH9070-6BA00		100 50 units	1BT	
 <p>Warning covers, for 8WH1</p> <ul style="list-style-type: none"> • Lightning symbol, yellow <p>8WH9066-5BA06</p>						
<p>Versions</p> <ul style="list-style-type: none"> • For terminal size 2.5 mm², width 5.2 mm • For terminal size 4 mm², width 6.2 mm • For terminal size 6 mm², width 8.2 mm • For terminal size 10 mm², width 10.2 mm • For terminal size 16 mm², width 12.2 mm • For terminal size 35 mm², width 16 mm 		8WH9060-5BA06 8WH9063-5BA06 8WH9064-5BA06 8WH9065-5BA06 8WH9066-5BA06 8WH9067-5BA06		100 50 units 100 50 units 100 50 units 100 50 units 100 50 units 100 50 units	1BT 1BT 1BT 1BT 1BT 1BT	

* You can order this quantity or a multiple thereof.