


# Metric wide and narrow slot wiring duct


A

## Lead-free thermoplastic duct


### With 8–12 / 4–6 mm slots

- Shock-resistant and self-extinguishing thermoplastic in conformity with UL94V-0 standard, resistant to abnormal heat and fire up to 960 °C (glow-wire test) in conformity with IEC 60695-2-1 standard
- Minimum storage/transport temperature -5 °C
- Minimum installation/use temperature -15 °C
- Maximum use temperature +60 °C
- DIN standard mounting holes enable use of the same duct for multiple applications
- Standard length 2 meters
- Colour RAL 7030 grey
- Conforms to EN 50085-2-3 standard
- Conforms to RoHS directive
- Lead-free
- Certifications: CSA–File no. 077988, IMQ, UL, RINA

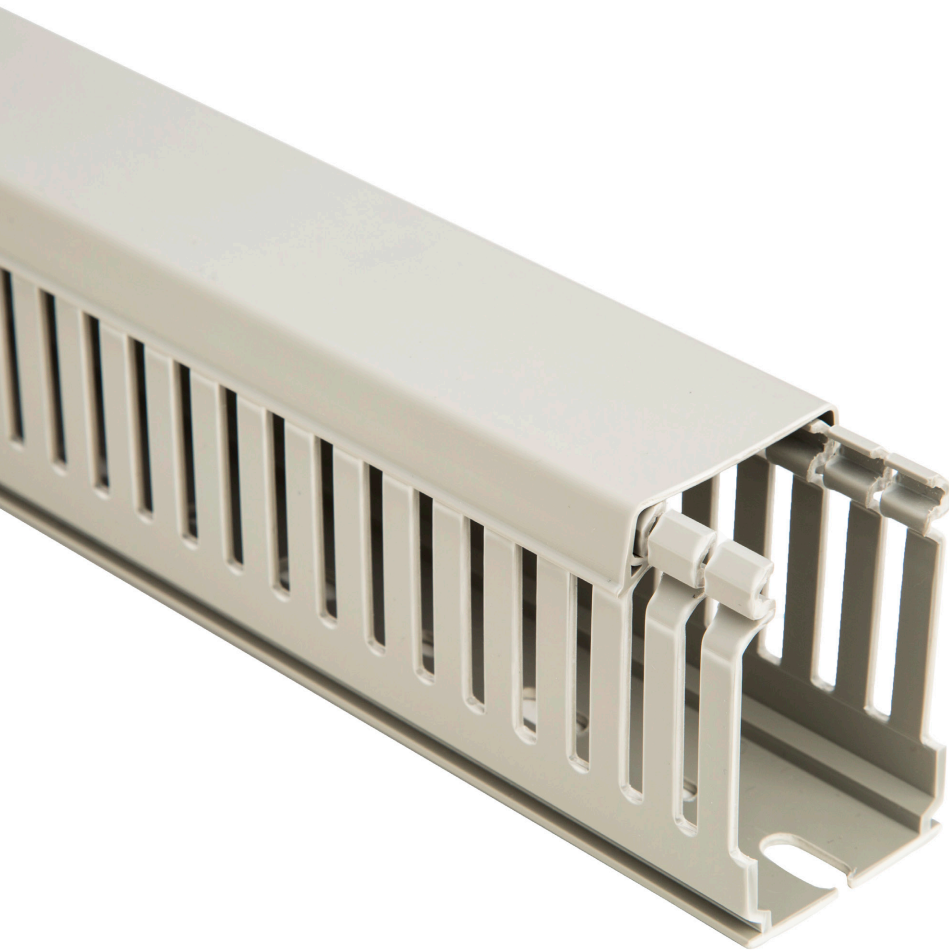


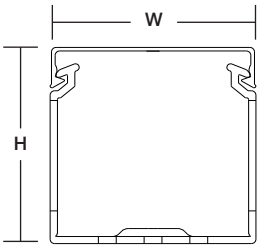

Front view with cover

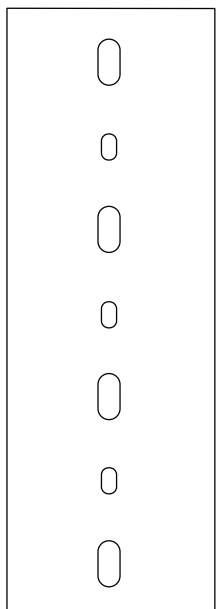

Bottom view

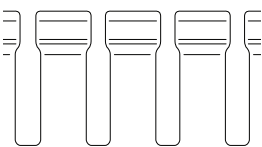

Side view


## Metric wide slot wiring duct

For a complete listing of wide slot dimensional details, see page B-8.


Cat. no.*	Description (mm)	Size (W x H)		Cover cat. no.*	Duct std. ctn. qty. (meters)	Length (meters)
		In.	mm			
05019	15 x 17 Grey wide finger wiring duct	.59 x .67	15 x 17	05300	46	2
05033	25 x 30 Grey wide finger wiring duct	.98 x 1.18	25 x 30	05302	58	2
05035	40 x 30 Grey wide finger wiring duct	1.57 x 1.18	40 x 30	05304	38	2
05037	60 x 30 Grey wide finger wiring duct	2.36 x 1.18	60 x 30	05306	52	2
05043	25 x 40 Grey wide finger wiring duct	0.98 x 1.57	25 x 40	05302	48	2
05045	40 x 40 Grey wide finger wiring duct	1.57 x 1.57	40 x 40	05304	30	2
05047	60 x 40 Grey wide finger wiring duct	2.36 x 1.57	60 x 40	05306	40	2
05049	80 x 40 Grey wide finger wiring duct	3.15 x 1.57	80 x 40	05308	32	2
05051	100 x 40 Grey wide finger wiring duct	3.94 x 1.57	100 x 40	05310	24	2
05053	120 x 40 Grey wide finger wiring duct	4.72 x 1.57	120 x 40	05312	20	2
05063	25 x 60 Grey wide finger wiring duct	0.98 x 2.36	25 x 60	05302	34	2
05065	40 x 60 Grey wide finger wiring duct	1.57 x 2.36	40 x 60	05304	22	2
05067	60 x 60 Grey wide finger wiring duct	2.36 x 2.36	60 x 60	05306	32	2
05069	80 x 60 Grey wide finger wiring duct	3.15 x 2.36	80 x 60	05308	24	2
05071	100 x 60 Grey wide finger wiring duct	3.94 x 2.36	100 x 60	05310	20	2
05073	120 x 60 Grey wide finger wiring duct	4.72 x 2.36	120 x 60	05312	14	2
05083	25 x 80 Grey wide finger wiring duct	0.98 x 3.15	25 x 80	05302	28	2
05085	40 x 80 Grey wide finger wiring duct	1.57 x 3.15	40 x 80	05304	36	2
05087	60 x 80 Grey wide finger wiring duct	2.36 x 3.15	60 x 80	05306	24	2
05089	80 x 80 Grey wide finger wiring duct	3.15 x 3.15	80 x 80	05308	16	2
05091	100 x 80 Grey wide finger wiring duct	3.94 x 3.15	100 x 80	05310	16	2
05093	120 x 80 Grey wide finger wiring duct	4.72 x 3.15	120 x 80	05312	12	2
05094	25 x 100 Grey wide finger wiring duct	0.98 x 3.94	25 x 100	05302	20	2
05095	40 x 100 Grey wide finger wiring duct	1.57 x 3.94	40 x 100	05304	28	2
05096	60 x 100 Grey wide finger wiring duct	2.36 x 3.94	60 x 100	05306	20	2
05097	80 x 100 Grey wide finger wiring duct	3.15 x 3.94	80 x 100	05308	14	2
05098	100 x 100 Grey wide finger wiring duct	3.94 x 3.94	100 x 100	05310	8	2
05099	150 x 100 Grey wide finger wiring duct	5.91 x 3.94	150 x 100	05314	8	2

\*Covers are included with all duct orders.


A

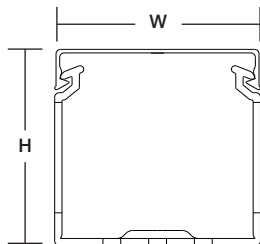

Front view with cover

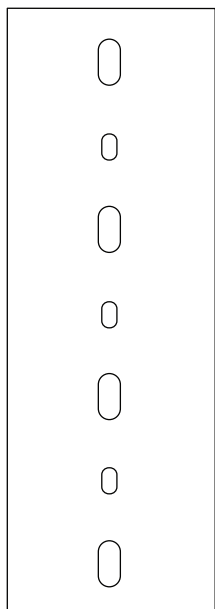

Bottom view

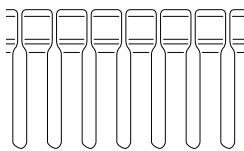

Side view

## Metric narrow slot wiring duct

For a complete listing of narrow slot dimensional details, see page B-9.

Cat. no.	Description (mm)	Size (W x H)		Cover cat. no.*	Duct std. ctn. qty. (meters)	Length (meters)
		In.	mm			
05119	15 x 17 Grey narrow finger wiring duct	0.59 x .67	15 x 17	05300	46	2
05133	25 x 30 Grey narrow finger wiring duct	0.98 x 1.18	25 x 30	05302	58	2
05135	40 x 30 Grey narrow finger wiring duct	1.57 x 1.18	40 x 30	05304	38	2
05137	60 x 30 Grey narrow finger wiring duct	2.36 x 1.18	60 x 30	05306	52	2
05143	25 x 40 Grey narrow finger wiring duct	0.98 x 1.57	25 x 40	05302	48	2
05145	40 x 40 Grey narrow finger wiring duct	1.57 x 1.57	40 x 40	05304	30	2
05147	60 x 40 Grey narrow finger wiring duct	2.36 x 1.57	60 x 40	05306	40	2
05149	80 x 40 Grey narrow finger wiring duct	3.15 x 1.57	80 x 40	05308	32	2
05151	100 x 40 Grey narrow finger wiring duct	3.94 x 1.57	100 x 40	05310	24	2
05153	120 x 40 Grey narrow finger wiring duct	4.72 x 1.57	120 x 40	05312	20	2
05163	25 x 60 Grey narrow finger wiring duct	0.98 x 2.36	25 x 60	05302	34	2
05165	40 x 60 Grey narrow finger wiring duct	1.57 x 2.36	40 x 60	05304	22	2
05167	60 x 60 Grey narrow finger wiring duct	2.36 x 2.36	60 x 60	05306	32	2
05169	80 x 60 Grey narrow finger wiring duct	3.15 x 2.36	80 x 60	05308	24	2
05171	100 x 60 Grey narrow finger wiring duct	3.94 x 2.36	100 x 60	05310	20	2
05173	120 x 60 Grey narrow finger wiring duct	4.72 x 2.36	120 x 60	05312	14	2
05183	25 x 80 Grey narrow finger wiring duct	0.98 x 3.15	25 x 80	05302	28	2
05185	40 x 80 Grey narrow finger wiring duct	1.57 x 3.15	40 x 80	05304	36	2
05187	60 x 80 Grey narrow finger wiring duct	2.36 x 3.15	60 x 80	05306	24	2
05189	80 x 80 Grey narrow finger wiring duct	3.15 x 3.15	80 x 80	05308	16	2
05191	100 x 80 Grey narrow finger wiring duct	3.94 x 3.15	100 x 80	05310	16	2
05193	120 x 80 Grey narrow finger wiring duct	4.72 x 3.15	120 x 80	05312	12	2
05194	25 x 100 Grey narrow finger wiring duct	0.98 x 3.94	25 x 100	05302	20	2
05195	40 x 100 Grey narrow finger wiring duct	1.57 x 3.94	40 x 100	05304	28	2
05196	60 x 100 Grey narrow finger wiring duct	2.36 x 3.94	60 x 100	05306	20	2
05197	80 x 100 Grey narrow finger wiring duct	3.15 x 3.94	80 x 100	05308	14	2
05198	100 x 100 Grey narrow finger wiring duct	3.94 x 3.94	100 x 100	05310	8	2
05199	150 x 100 Grey narrow finger wiring duct	5.91 x 3.94	150 x 100	05314	8	2

\*Covers are included with all duct orders.

## Replacement covers for wiring duct

Cat. no.	Description	Size (mm)	Length / pack qty (meters)
05300	15 mm wiring duct cover	15	2 / 200
05302	25 mm wiring duct cover	25	2 / 60
05304	40 mm wiring duct cover	40	2 / 40
05306	60 mm wiring duct cover	60	2 / 24
05308	80 mm wiring duct cover	80	2 / 16
05310	100 mm wiring duct cover	100	2 / 8
05312	120 mm wiring duct cover	120	2 / 36
05314	150 mm wiring duct cover	150	2 / 28