

## 2-030 Round Remodel GU10



### FEATUTRES

- Designed for 50W GU10 halogen 120V lamp
- GU10-LED lamp rated for 15W (max.)
- Designed for typical 5/8" drywall applications
- 18 Ga. galvanized steel junction box
- Over lamping protection
- Approved for branch circuit wiring
- Housing can is 18 GA. aluminum with a black powder coated paint finish

### DETAILS

Aperture: 4"  
Shape: Round  
Ceiling: Remodel

 


2-030-GU10-Specs • Subject to change without notice • Rev 2016.12.19 • 1/4



# Housing Types

## TRIMMED

### Ceiling Cutout



### Dimensions

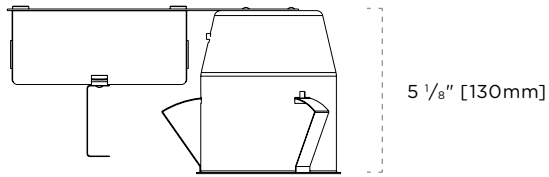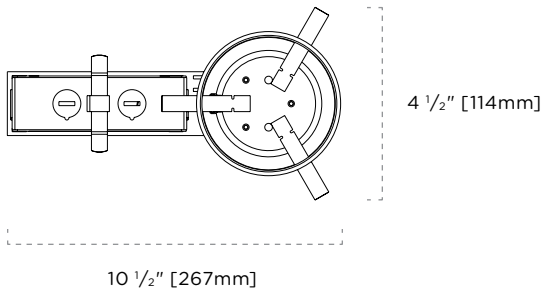 

















## MAXIMUM WATTAGES

LAMP TYPE	INPUT VOLTAGE
	120V
GU10	50W
GU10-LED	15W

# Compatible Trims

---

2-110 Coral	
2-112 Round Wall Wash	
2-115 Aqua	
2-120 Aurora	
2-125 Deep Aurora	
2-160 Demi	
2-167 Starlite	
2-170 Conus	
2-175 Corona	
2-180 Pinhole	
2-182 Flare Wall Wash	
2-185 Piccolo	
2-187 Lensed Piccolo	
2-190 Keyhole	
2-195 Pivot	
2-197 Linover	

---

2-030-GU10-Specs • Subject to change without notice • Rev 2016.12.19 • 3/4

# 2-030

## Round Remodel GU10

---

Project

Type

Notes

Product Code

\_\_\_\_\_

1

2

3

4

5

1. Housing

**2-030** Round

2. Housing Type

**R** Remodel

3. Lamp

**GU10-HAL** Halogen

**GU10-LED** LED<sup>1</sup>

4. Voltage

**120**

5. Options

**WPHI** White Painted Housing Interior

Notes

<sup>1</sup> **GU10-LED** is compatible with GU10 LED lamp, rated for a maximum 15W, sold separately.

---

**2-030-GU10-Specs** • Subject to change without notice • Rev 2016.12.19 • 4/4

---