


## 2-020 Round Non-Insulated MR16

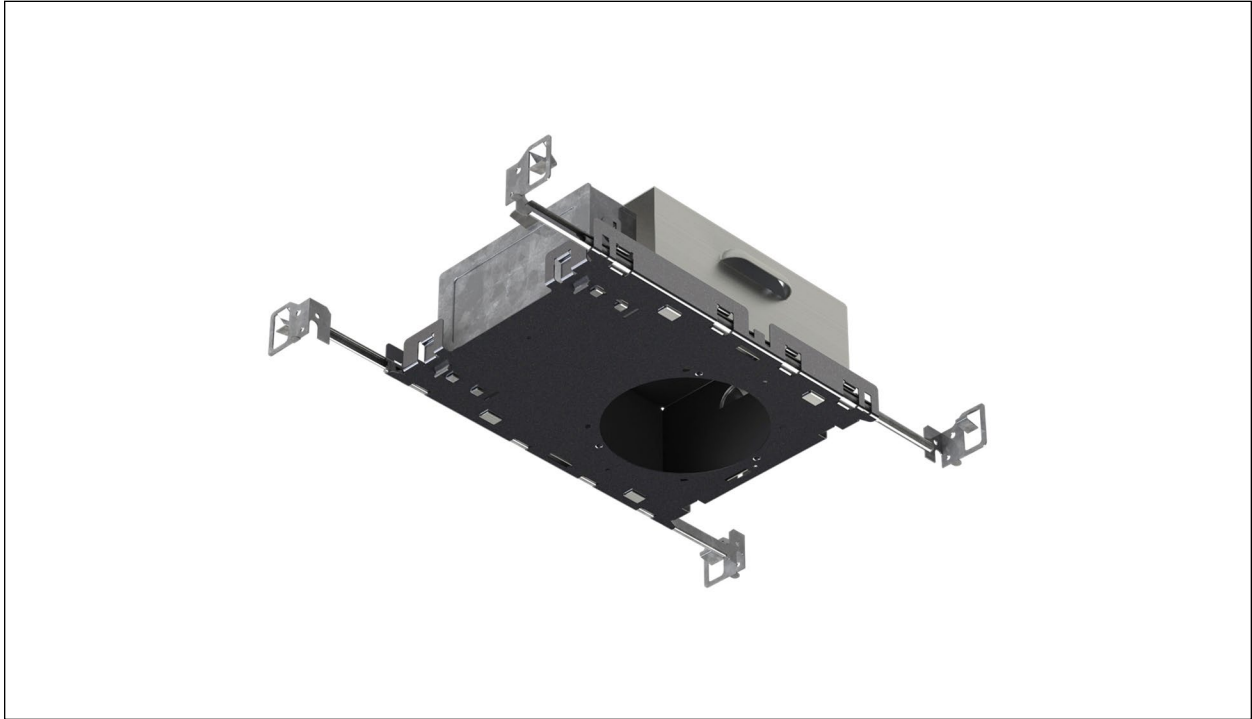

The 2-020 series housing is designed for non-insulated ceilings, allowing for installation of very shallow plenums, as low as 4". It's sleek footprint allows for compatibility with most ceiling applications.

### FEATURES

- Rated for non-insulated ceilings
- Low voltage (12V) MR16 lamp (sold separately)
- Porcelain Bi Pin socket type GX5.3
- MR16 LED lamp is compatible with E15 electronic transformer option
- 16" hanger bars standard
- 20 Ga. cold rolled steel baseplate
- 18 Ga. galvanized steel junction box
- 5 junction box knock outs
- Approved for branch circuit wiring
- Transformer accessible through the ceiling

### DETAILS

Aperture: 4"  
Shape: Round  
Ceiling: Insulated

 


2-020-MR16-Specs • Subject to change without notice • Rev 2016.12.19 • 1/5



# Housing Types

## TRIMMED

Ceiling Cutout




Dimensions

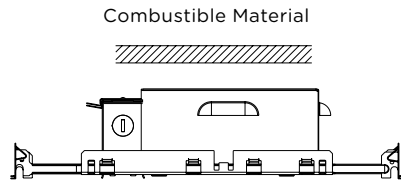
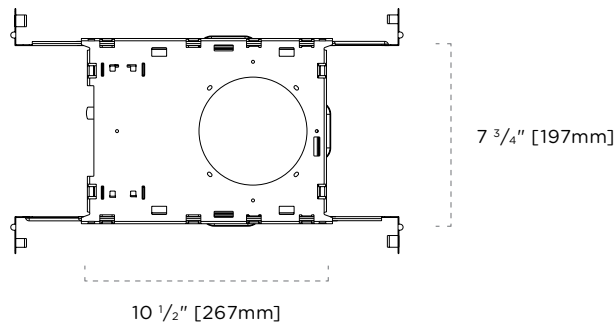


## TRIMLESS

 Ceiling Cutout



Dimensions

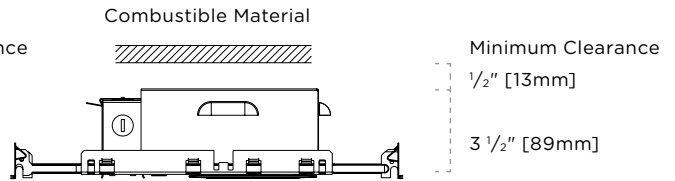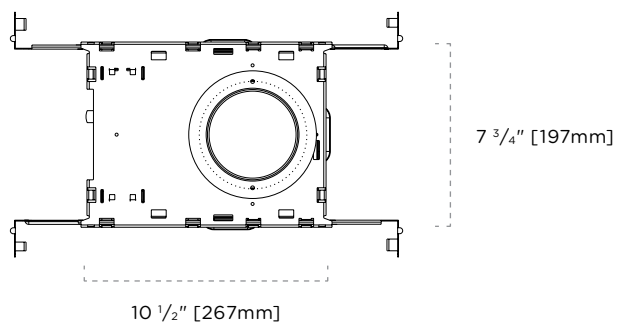















 





 


## MAXIMUM WATTAGES

TRANSFORMER TYPE	INPUT VOLTAGE			NOTES
	120V	277V	347V	
MAGNETIC	50W	50W	50W	Made of copper windings with a class H rating (180°C)
ELECTRONIC	50W	50W	—	
E15 ELECTRONIC	15W	15W	—	Only compatible with Soraa MR16 LED

 
2-020-MR16-Specs • Subject to change without notice • Rev 2016.12.19 • 2/5

## Compatible Trims

Trim	Trim Type	
	Trimmed	Trimless
2-110 Coral		—
2-112 Round Wall Wash		—
2-115 Aqua		
2-120 Aurora		
2-130 Sunburst		—
2-140 Eclipse		—
2-150 Siris		—
2-160 Demi		—
2-167 Starlite		
2-170 Conus		
2-175 Corona		—
2-180 Pinhole		
2-182 Flare Wall Wash		
2-185 Piccolo		
2-187 Lensed Piccolo		

2-020-MR16-Specs • Subject to change without notice • Rev 2016.12.19 • 3/5

2-190  
Keyhole



2-195  
Pivot



2-197  
Linover



2-200  
Split



# 2-020

## Round Non-Insulated MR16

---

Project

Type

Notes

Product Code

\_\_\_\_\_

1            2            3            4            5

### 1. Housing

**2-020** Round

### 2. Housing Type

**F** Non-Insulated

**F-TL** Trimless Non-Insulated

### 3. Transformer

**E** Electronic

**E15** 15W Electronic <sup>1</sup>

**M** Magnetic

### 4. Voltage

**120**

**277**

**347** <sup>2</sup>

### 5. Options

**BPHI** Black Painted Housing Interior

**WPHI** White Painted Housing Interior

### Notes

<sup>1</sup> **E15** transformer option is only compatible with Sora MR16 LED lamp.

<sup>2</sup> **347** voltage is only available with **M** magnetic transformer.

---

2-020-MR16-Specs • Subject to change without notice • Rev 2016.12.19 • 5/5

---