



## 2-200-T Split MR16



Split can provide direct downlight in its flush-mount position or pull down to highlight objects, artwork or signage on walls or shelving. Add an elongating lens for a smooth, vertical wash of light.

### FEATURES

- Utilizes MR16 halogen
- 359° rotation
- 85° aiming
- Die-cast aluminum
- Powder coated trim ring finishes
- Trim clips designed for 5/8" ceiling thickness
- Accepts 1 optional media
- Clear glass lens included
- Trimless version available (see separate specifications)

### DETAILS

Trim Class: 4"  
Category: Recessed Downlight  
Shape: Round  
Adjustability: Aiming With Rotation  
Lumen Output: 700-1000




2-200-T-Split-MR16-Specs • Subject to change without notice • Rev 2016.12.19 • 1/4


# Features & Lighting

---

## DIMENSIONS

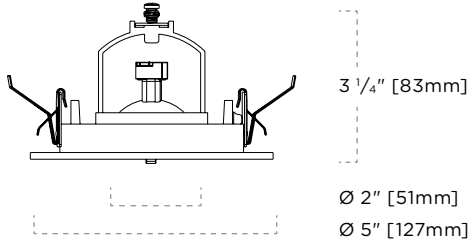

## CEILING CUTOUT

 


## FLANGE FINISHES

- White
- Black
- Matte Silver
- Bronze
- Matte Nickel


# Compatible Housings

## NON-INSULATED

2-020  
Round Non-Insulated  
L 10 1/2" [267mm]  
W 7 3/4" [197mm]  
H 3 1/2" [90mm]

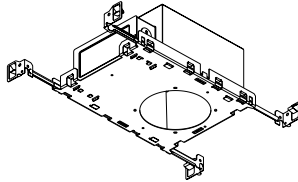


2-060  
Round Non-Insulated  
L 13 3/4" [349mm]  
W 10 7/8" [276mm]  
H 3 1/2" [90mm]

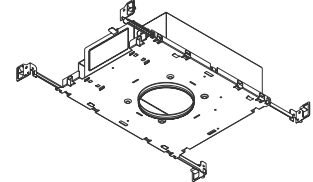


## INSULATED

2-010  
Round Insulated  
L 13 3/4" [350mm]  
W 10 7/8" [277mm]  
H 7" [178mm]

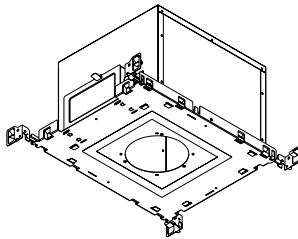


2-012  
Round Insulated  
L 22 1/2" [572mm]  
W 8 1/2" [216mm]  
H 5 7/8" [150mm]

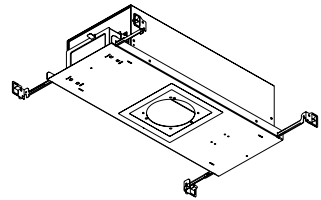


## REMODEL

2-030  
Round Remodel  
L 14" [356mm]  
W 4 1/2" [114mm]  
H 5 1/8" [130mm]

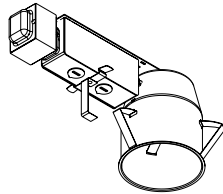


## SPECIALIZED

2-060  
Round Chicago Plenum  
L 13 3/4" [350mm]  
W 10 7/8" [277mm]  
H 4 1/2" [115mm]

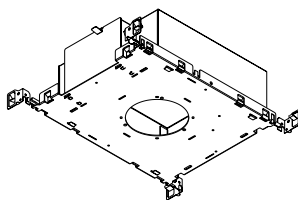

2-100  
Round Concrete Housing  
L 18" [457mm]  
W 12" [305mm]  
H 6" [152mm]

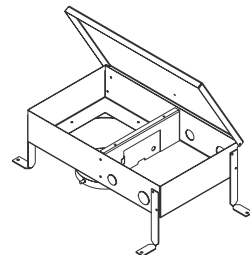

# 2-200-T Split MR16

---

Project

Type

Notes

Product Code

\_\_\_\_\_

1            2            3            4

1. Trim

**2-200-T** Split

2. Lamp

**MR16** Halogen

3. Flange Finish

**01** White

**04** Black

**05** Matte Silver

**06** Bronze

**11** Matte Nickel

**CC** Custom Color<sup>1</sup>

4. Optional Media (2 Maximum)

**EL** Elongating

**FRO** Frosted

**PER** Perimeter Frosted

**SL** Solite Softening

**SPDL** Spread

Notes

<sup>1</sup> **CC** custom color requires consultation with Lightheaded sales personnel.

---

**2-200-T-Split-MR16-Specs** • Subject to change without notice • Rev 2016.12.19 • 4/4

---