

## 2-115-T Aqua MR16



The small-aperture Aqua brings surprising performance and excellent glare control to wet locations. The fixture is a die cast trim which offers performance, versatility and excellent glare control. The Aqua trim features a silicone sealed glass lens.

### FEATURES

- Utilizes MR16
- Wet location listed
- 35° aiming
- Die-cast aluminum fixture
- Powder coated and plated trim ring finishes
- Trim clips designed for 5/8" ceiling thickness
- Trimless version available (see separate specifications)

### DETAILS


Trim Class: 4"  
Category: Recessed Downlight  
Shape: Round  
Adjustability: Aiming




2-115-T-Aqua-MR16-Specs • Subject to change without notice • Rev 2016.12.19 • 1/4

# Features & Lighting

## DIMENSIONS

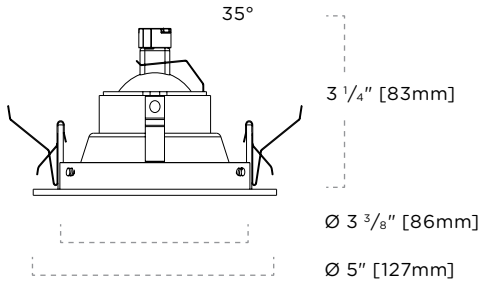

## CEILING CUTOUT

 

## FLANGE FINISHES

- White
- Chrome Plated
- Black
- Matte Silver
- Bronze
- Matte Nickel


## GLASS

- Frosted
- Clear


# Compatible Housings

## NON-INSULATED

2-020  
Round Non-Insulated  
L 10 1/2" [267mm]  
W 7 3/4" [197mm]  
H 3 1/2" [90mm]

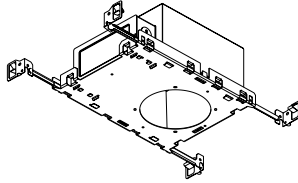


2-060  
Round Non-Insulated  
L 13 3/4" [349mm]  
W 10 7/8" [276mm]  
H 3 1/2" [90mm]

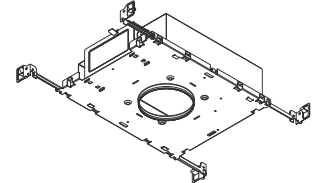


## INSULATED

2-010  
Round Insulated  
L 13 3/4" [350mm]  
W 10 7/8" [277mm]  
H 7" [178mm]

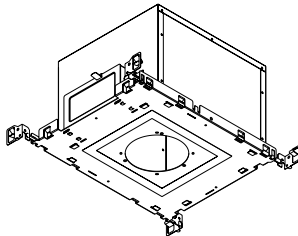


2-012  
Round Insulated  
L 22 1/2" [572mm]  
W 8 1/2" [216mm]  
H 5 7/8" [150mm]

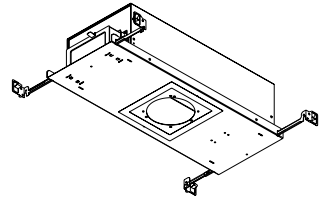


## REMODEL

2-030  
Round Remodel  
L 14" [356mm]  
W 4 1/2" [114mm]  
H 5 1/8" [130mm]

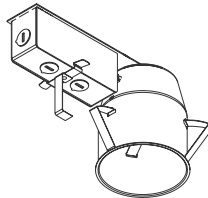


## SPECIALIZED

2-060  
Round Chicago Plenum  
L 13 3/4" [350mm]  
W 10 7/8" [277mm]  
H 4 1/2" [115mm]

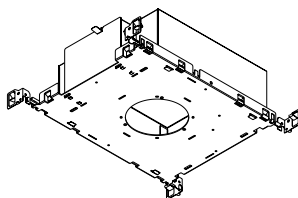

2-100  
Round Concrete Housing  
L 18" [457mm]  
W 12" [305mm]  
H 6" [152mm]

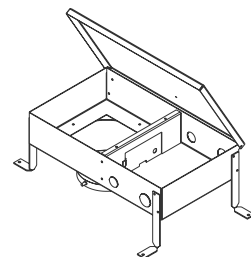

2-115-T-Aqua-MR16-Specs • Subject to change without notice • Rev 2016.12.19 • 3/4

# 2-115-T Aqua MR16

Project

Type

Notes

Product Code

\_\_\_\_\_

1            2            3            4

1. Trim

**2-115-T** Aqua

2. Lamp

**MR16** Halogen

3. Flange Finish

**01** White

**02** Chrome Plated

**04** Black

**05** Matte Silver

**06** Bronze

**11** Matte Nickel

**CC** Custom Color

4. Glass

**C** Clear Glass <sup>2</sup>

**F** Frosted Glass <sup>3</sup>

Notes

<sup>1</sup> **CC** custom color requires consultation with Lightheaded sales personnel.

<sup>2</sup> **C** clear glass reflector color is painted to match trim finish.

<sup>3</sup> **F** frosted glass requires all reflectors painted white.

**2-115-T-Aqua-MR16-Specs** • Subject to change without notice • Rev 2016.12.19 • 4/4