

## 2-230

### Mini Deep Aurora HAL



Mini Deep Aurora offers a variety of reflector, trim, and color temperature combinations to marry well with the larger-aperture Aurora family.

#### DETAILS

Trim Class: 2"  
Category: Accent & Cabinet  
Shape: Round  
Adjustability: Fixed

#### FEATURES


- Utilizes MR11 halogen
- Die-cast aluminum
- Accepts 1 optional media
- Clear glass lens included
- Trim clips designed for 5/8" ceiling thickness
- Max 20W without high wattage can option, requires R12S socket (sold separately)
- Max 35W when installed with the high wattage can option, includes R12S socket
- Powered by 12V class 2 electronic transformer (sold separately)
- Clearance required above the trim (see install sheet)
- Designed for non-insulated ceilings only




2-235-Mini-Deep-Aurora-HAL-Specs • Subject to change without notice • Rev 2017.09.26 • 1/3

# Features & Lighting


## DIMENSIONS

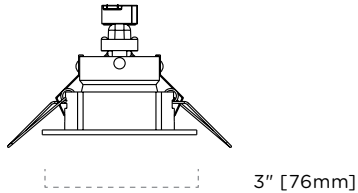

## HIGH WATTAGE CAN (OPTIONAL)

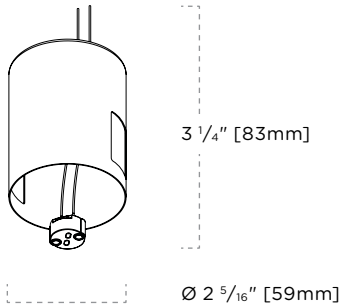

## CEILING CUTOUT

 

## FLANGE FINISHES

- White
- Chrome Plated
- Black
- Matte Silver
- Bronze
- Gold Plated
- Matte Nickel

## REFLECTOR FINISHES

- Black Open
- Silver Specular
- White Open
- Silver Satin

# 2-235

## Mini Deep Aurora HAL

Project

Type

Notes

Product Code

1 2 3 4 5

1. Trim

**2-235** Mini Deep Aurora

2. Lamp

**MR11** Halogen

3. Flange Finish

**01** White

**02** Chrome Plated

**04** Black

**05** Matte Silver

**06** Bronze

**09** Gold Plated

**11** Matte Nickel

4. Reflector Finish

**BLO** Black Open

**SA** Silver Specular

**SAS** Silver Satin

**WHO** White Open

5. Options

**2-050-RT** High Wattage Can

**2-235-Mini-Deep-Aurora-HAL-Specs** • Subject to change without notice • Rev 2017.09.26 • 3/3