

515 4W Cabinet Light LED



Illuminate a piece on exhibit or serve up a dash of task lighting using a single LED. The Cabinet is a small machined aluminum under-cabinet light which has been engineered to use the latest generation LED technology using only 4W. Just over 1/2" in depth, this luminaire can be recessed flush into any millworks.

FEATURES

- Utilizes low watt LED
- Machined aluminum
- Frosted glass cover standard
- Push fit installation for recessed fixture
- 6ft [2m] lead standard
- Powered by a remote 350mA constant current driver (sold separately)
- L70 @ 50,000 hours

DETAILS


Trim Class: 1.5"
Category: Accent & Cabinets
Shape: Round
Adjustability: Fixed
Lumen Output: 180




515-4W-Cabinet-Light-LED-Specs • Subject to change without notice • Rev 2016.12.15 • 1/4

Features & Lighting



RECESSED MOUNT

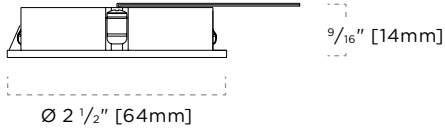



SURFACE MOUNT

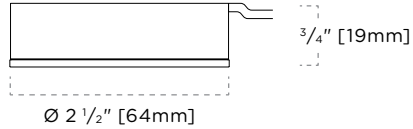


OPTIONAL INTEGRAL SNOOT

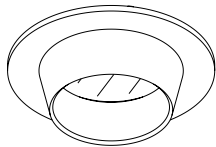 


OPTIONAL INTEGRAL EYELID

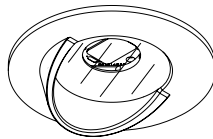 

CEILING CUTOUT

 

BEAM SPREAD

 

FLANGE FINISHES

- White
- Black
- Matte Silver
- Bronze
- Matte Nickel

COLOR TEMPERATURES

- 2700
- 3000

CRI & LUMENS

CRI VALUE	80
LUMEN OUTPUT	180
LED WATTAGE	4

515-4W-Cabinet-Light-LED-Specs • Subject to change without notice • Rev 2016.12.15 • 2/4


Compatible Drivers

ELECTRONIC LOW VOLTAGE (ELV)

Smooth, flicker-free dimming from 100% to 20%.


D10W-DIM

Channels: 1
Voltage: 120
Min. Load Units: 1
Max. Load Units: 3

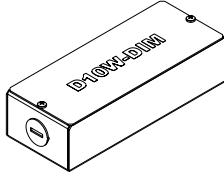

D15W-DIM

Channels: 1
Voltage: 120
Min. Load Units: 3
Max. Load Units: 4

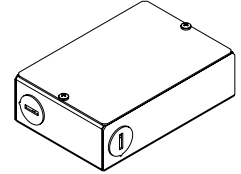


0-10V DIMMING

Smooth, flicker-free dimming from 100% to 10%.


D1CH-DIM

Channels: 1
Voltage: 120/277
Min. Load Units: 2
Max. Load Units: 4

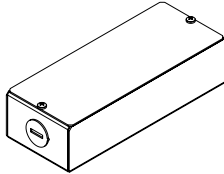


D2CH-DIM

Channels: 2
Voltage: 120/277
Min. Load Units: 1
Max. Load Units: 5/Ch

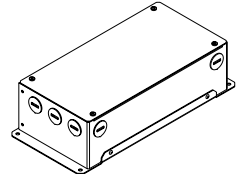

D4CH-DIM

Channels: 4
Voltage: 120/277
Min. Load Units: 1
Max. Load Units: 5/Ch

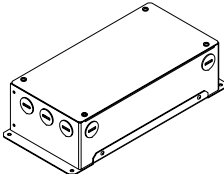

515

4W Cabinet Light LED

Project

Type

Notes

Product Code

1 2 3 4 5

1. Trim

515 4W Cabinet Light

2. Mounting

050 Recessed Mount

072 Surface Mount

3. Flange Finish

01 White

04 Black

05 Matte Silver

06 Bronze

11 Matte Nickel

4. Color Temperature

27 2700K

30 3000K

5. Options

EYELID Optional Integral Eyelid

SNOOT Optional Integral Snoot

515-4W-Cabinet-Light-LED-Specs • Subject to change without notice • Rev 2016.12.15 • 4/4
