



D15W-DIM 15W ELV LED Driver




- ELV dimming
- Dimmable 100–20%
- Overload, underload, over-current, short-circuit, and auto-recovery protection
- Compatible with an array of ELV dimmers, dimmable down to 20%
- 80% efficiency at full load
- 350mA constant current output
- 120V 50/60Hz input, 0.2A
- Power factor of >0.9
- Complies with UL60950-1, NEC Class 2, EN60598-A Class II
- Harmonics complies with EN61000-3-2 and EN61000-3-3
- Driver and enclosure UL approved as Class 2
- 50°C maximum ambient temperature



D15W-DIM-Specs • Subject to change without notice • Rev 2016.12.15 • 1/5

Features

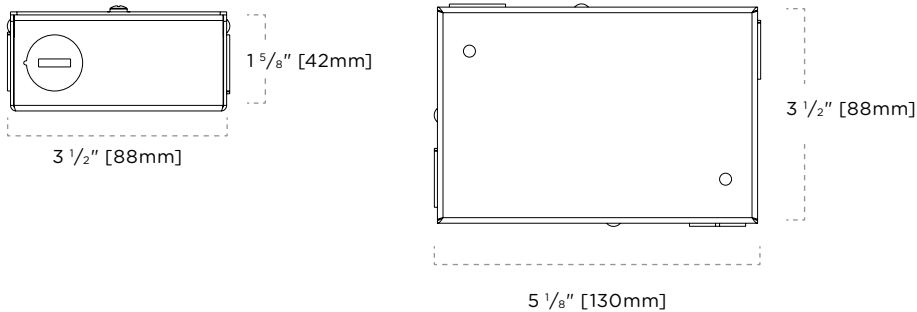

SERIES WIRING



SERIES WIRING NOTE


All LEDs **must** be wired in series. Failure to do so will cause immediate LED failure and void warranty.

WIRING SETUP

120 Volts
AC Input

WIRING NOTE


Ensure that power is switched **off** before connecting or hardwiring the LED product. Failure to do so will cause immediate LED failure

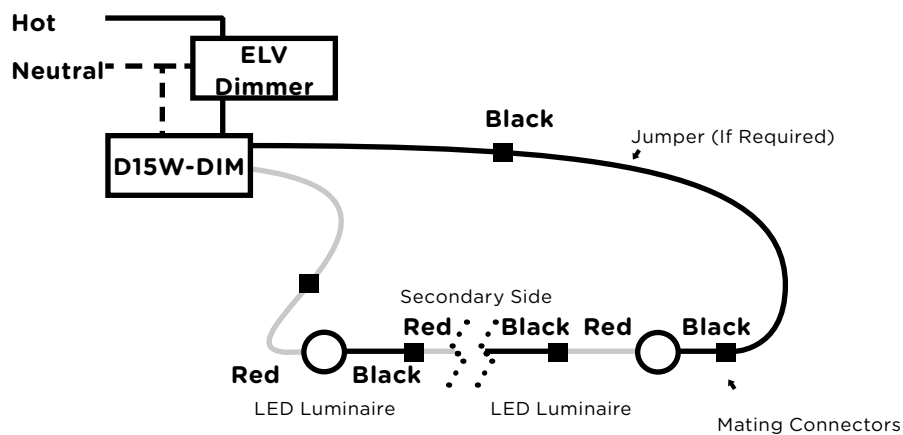


Compatible Trims

1W TRIMS


511
1W Cabinet Light
Min. Load Units: 9
Max. Load Units: 13

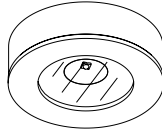


526
1W Cabinet Light
Min. Load Units: 9
Max. Load Units: 13

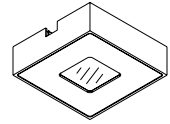

 
2-220
Mini Turno
Min. Load Units: 9
Max. Load Units: 13



 
2-230
Mini Aurora
Min. Load Units: 9
Max. Load Units: 13



 
2-235
Mini Deep Aurora
Min. Load Units: 9
Max. Load Units: 13




2-305
305 Wall Light
Min. Load Units: 9
Max. Load Units: 13

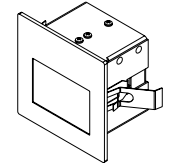


2-315
315 Wall Light
Min. Load Units: 9
Max. Load Units: 13

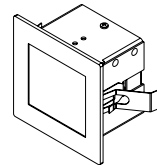

 
3-600
Compact Round
Min. Load Units: 9
Max. Load Units: 13



3-610
Compact Square
Min. Load Units: 9
Max. Load Units: 13

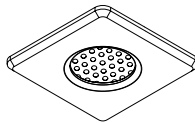


 3-620
Compact Eyelid
Min. Load Units: 9
Max. Load Units: 13




2W TRIM

538
2W Cabinet Light
Min. Load Units: 5
Max. Load Units: 6

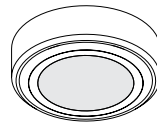


4W TRIM

515
4W Cabinet Light
Min. Load Units: 3
Max. Load Units: 4

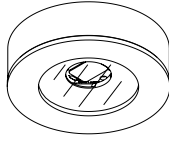


527
4W Cabinet Light
Min. Load Units: 3
Max. Load Units: 4

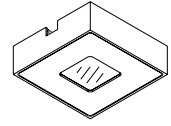


5W TRIM

 
2-210
Ring
Min. Load Units: 3
Max. Load Units: 3




2-400
SS Wall Light
Min. Load Units: 3
Max. Load Units: 3

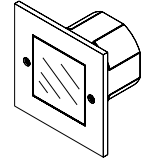

 3-630
Draco
Min. Load Units: 3
Max. Load Units: 3



 3-640
Vela
Min. Load Units: 3
Max. Load Units: 3



D15W-DIM

15W ELV LED Driver

Project

Type

Notes

Product Code

1

2

1. Driver

D15W-DIM 15W ELV LED Driver

2. Voltage

120V

D15W-DIM-Specs • Subject to change without notice • Rev 2016.12.15 • 5/5
