 


TRAC-LITES

 
One Circuit Trac System

R2, R4, R6, and R8


Electrical End Feeds




R21WH, R21BL
End Feed Connector and Outlet Box Cover. For outlet box feed. Includes: outlet box cover, fixture strap and ground screw.



 
R29WH, R29BL
Floating Electrical Feed. Permits mounting any point of trac under outlet box. Includes floating connector, outlet box cover plus extra trac dead end.



R34WH, R34BL
Conduit Feed. For surface wiring. Use standard 1/2" connector.

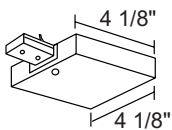

 
R36WH
T-Bar End Feed. Wiring compartment contains standard 1/2" KO's. Feeds surface trac from above, when T-bar is directly above trac.



R38WH, R38BL
Live End Feed Connector. Feed trac from above with flexible conduit, BX, etc., or end feed in pendant systems. Accepts standard 1/2" connector.




 T38X
Wiremold Attachment Clip. For use with **R38** connector and Wiremold Raceway #200. (Not available in Canada)




R22WH, R22BL
Cord and Plug Connector. Comes with 15' two-wire white cord. Includes surface wire retainers and in-line switch. Max cap. 7 amps.

 
Trac Joiners



 
R20WH, R20BL
Accordion Adjustable Joiner. Can flex to 90° angle to left, right, up or down. Joins two trac sections.




R23WH, R23BL
Miniature Straight Connector. Joins two trac sections end to end.

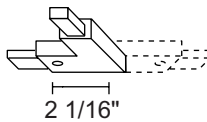

 R24WH, R24BL
Adjustable Connector. Joins two trac sections to make a 90° angle or straight run. Straight and right angle covers supplied. For outlet box feed, No. **T27** cover plate required.




R25WH, R25BL
"T" Connector. Joins three trac sections. For outlet box feed, No. **T27** cover plate required.

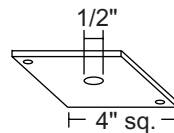


T27WH, T27BL
Outlet Box Cover. Use with Nos. **R26/R25** for outlet box electrical feed. Includes: nipple, locknut and ground screw.

Pendant Stems

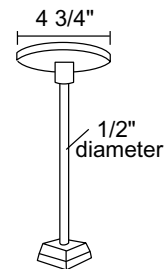

T90-12, T90-18, T90-24, T90-36, T90-48
T-Bar Pendant Stem Kit (12", 18", 24", 36", 48") - Use two for 2', 4', 6' of trac or three for 8' of trac. For electrical feed, order **T93** wireway cover. WH, BL

 T91-12, T91-18, T90-24, T91-36, T91-48
Rigid Ceiling Pendant Stem Kit (12", 18", 24", 36", 48") - Use two for 2', 4', 6' of trac or three for 8' of trac. For electrical feed, order **T93** wireway cover. WH, BL



T93WH, T93BL
Wireway Cover for Pendant Stem Kits T90 and T91. Conceals electrical feed wires from stem to connector. One cover required for each trac feed.



T94WH, T94BL
Sloped Ceiling Adapter. Allows **T90** or **T91** pendant to hang straight down from sloped ceilings. Can be used to feed electrical wires to Trac at up to 60° angle.



T96WH, T96BL
Pendant Stem Threaded Coupling. Enables multiple pendant stems to be joined for higher ceiling applications.



T56WH, T56BL
Solid Rod Pendant Mounting Kit. Attaches solid 5/16" threaded rod to Trac. Includes: plastic cap, mounting bracket and hardware. Rod not supplied.

 
Accessories



T37F
T-Bar Attachment Clip. To attach to inverted tee ceiling. Use two for 2' or 4' trac and three for 6', 8'.

T37D
Same as above with spacer for ceilings using drop tiles.

Mono-Point



R40WH, R40BL
Mono-Point Adaptor. Mounts directly to outlet box. Accepts one 120V Juno trac fixture.



Juno lighting

1300 S. Wolf Road, P.O. Box 5065, Des Plaines, IL 60017-5065 Phone 847.827.9880 FAX 847.827.2925
220 Chrysler Dr., Brampton, Ontario, Canada, L6S 6B6 Phone 905.792.7335 FAX 905.792.0064

Visit us at www.junolighting.com

Printed in U.S.A. ©2001 Juno Lighting, Inc.