

Catalog Number
Notes
Type

## FEATURES & SPECIFICATIONS

### INTENDED USE

For use with housings L5 and L5R.

### CONSTRUCTION

White polyester coat paint. Brushed nickel, oil-rubbed bronze, and white finishes are one piece aluminum with integral flange.

### INSTALLATION

Socket to trim interface.

Retaining clips pull and snap onto top of reflector to hold trim inside housing.

### LISTING

U.L. Listed to U.S. and Canadian safety standards.

Damp location listed.


Pull on clip Patent # (U.S.) 5707143, (Canada) 2193902.

Note: Specifications subject to change without notice.

5" Finishing Trim

# 501

OPEN SHALLOW  
Wide Flange

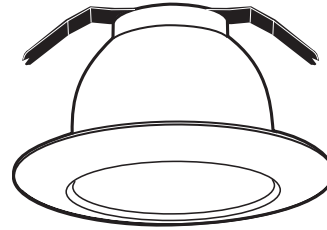


### Specifications

Height: 5-3/8" (13.7)

Lamp opening: 4-3/4" (12.1)

Diameter: 6-3/8" (16.2)

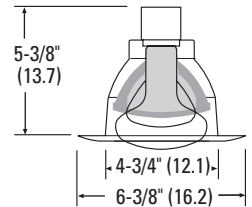

All dimensions are inches (centimeters).

### ORDERING INFORMATION

For shortest lead times, configure products using **bolded options**.

**Example: 501**

<b>501</b>	
Series	Finish
<b>501</b>	<b>(blank)</b> White BN Brushed nickel <sup>1</sup> ORB Oil-rubbed bronze <sup>1</sup>

HOUSING COMPATIBILITY			
Housing and trim ordered separately.			
APPLICATION	SOURCE	MAXIMUM WATTAGE	HOUSING
IC	Incandescent	65 BR30	L5, L5R
		75 PAR30	L5, L5R
		50 R20	L5, L5R

### Notes

1 Must submit a RFD (request for definition) to order special color finish.

# 501 5" Open Shallow Full Reflector Trim

---

For BR and PAR reflector lamps, see lamp manufacturer's published raw lamp data for photometrics.