

Adagio



INSTALLATION AND CONNECTION

Installation height 12 in (30 cm).

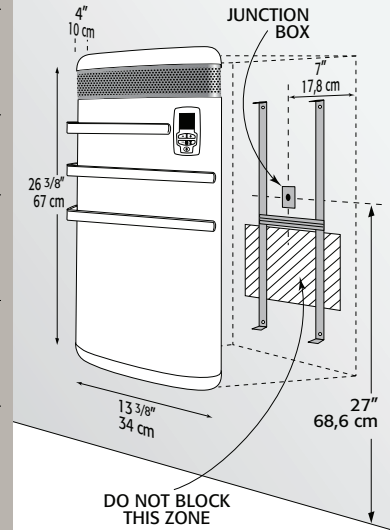
Clearances

- Front: 20 in (50 cm)
- ◀ Sides: 8 in (20 cm)
- ▲ Above: 8 in (20 cm).




Installation Quick mounted surface installation with easy snap-on bracket that also serves as marking template.

Connection 240-V unit: Flexible cord connection, including junction box. Installation requires 2 in X 3 in wall box (not included).


Note 3-conductor cable or 2-conductor cable with a third wire should be used if unit is to be linked with the Convectair Programmer module (7392 FP).




HEATING ELEMENTS

-  **Total capacity** 1400 W
-  **Convection (600 W)** X-shaped, monoblock element made of surface-treated extruded aluminum.
-  **Fan-forced heat on demand (800 W)** Low-thermal-mass heating element combined with low-pressure centrifugal blower.
- Thermal protection - Convection** Automatic reset overheat protection.
- Fan-forced heat** Resettable overheat protection. Reset by turning heater off.


TEMPERATURE CONTROL

-  **Electronic thermostat** Built-in electronic proportional-action thermostat ultraprecise to 1/5 °F (1/10 °C).
- Electronic timer** with indicator light, for 5 to 90 minutes of accelerated heating.
- Programmer** Programmer-compatible, pilot wire only.

CONTROL PANEL

-  **Location** Front panel.
- LCD screen** Back-lit with controls lockable by key combination.
- On/Off button** with indicator light.
- Timer button** with indicator light.
- 24-hr button** with indicator light stores the Chrono setting, for daily bathroom preheating.
- « + and - » buttons** control the temperature setting.
- Locked** indicator light.
- Heating** indicator light.

CABINET

-  **Steel** construction with polyester/epoxy anti-rust powder coating and resistant to UV rays.
- Cabinet** Splash-proof construction with rounded edges.
- Airflow** Bottom flow air outlet directs the hot air on the towels and towards the centre of the room.
- Accessories** Three (3) towel bars included.
- Colour BB** = White

MODEL	Catalogue No.	Colour	Power		Height		Width		Depth		Net Weight	
			240 V	208 V	cm	in	cm	in	cm	in	kg	lb
ADAGIO ②	7640-C14	BB	*600-1 400 W		67	26 3/8	34	13 3/8	10	4	9,1	20
*Convection (600 W); Fan-forced heat (800 W).					With bars		35,6	14 1/4	17	6 3/4	-	-

② Compatible with the Programmer system (see technical specifications for catalogue number 7392).

For guaranteed, dependable operation, we recommend that all units be installed by a licensed electrical contractor. Consult convectair.com to find the most recent installation instructions for our heaters.

