

# Product Specifications



## TLGU-4

### Description

Track cylinder for use with GU-10 lamps

Available Finishes:

Product Code:

Oil Rubbed Bronze  
Satin Nickel

**TLGU-4-ORB**  
**TLGU-4-SN**

- 105° vertical aiming capability with 300° horizontal rotation.
- Locking knobs provided.



### Specifications

120V / 60Hz / 50W max.


Bulb type: GU-10

Conforms to UL standard 1598

Certified to CSA C22-2 No. 250



Track connection block:  
W: 4 cm, L: 3.5 cm, H: 3.5 cm

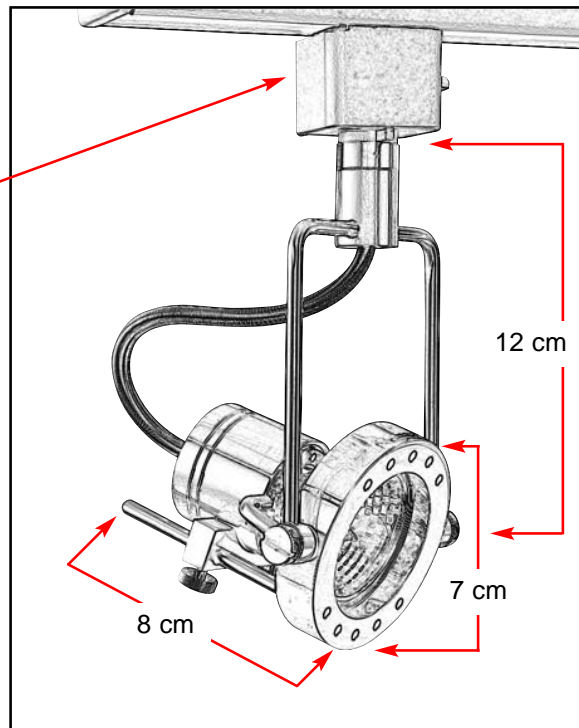

#110, 6780 Dennett Place, Delta, BC V4G 1N4 - P. (604) 952-5510 F. (604) 952-5513  
16650 - 114 Avenue Edmonton, Alberta T5M 3R8 - P. (780) 455-5500 F. (780) 452-1706  
#2, 6355 - Danville Rd, Mississauga, Ontario L5T 2L4 - P. (905) 565-9998 F. (905) 565-8881