

Complete fixture consists of the Trim and Frame-in Kit. Select each separately.

Reflector Trim		Frame-in Kit		Lamp	Voltage
377WHX	White frosted glass and white flange	Remodeler Non-IC	300MRSPX	50W MR16 / 37W MR16 IR	120V
		Remodeler Non-IC	3401MREX	50W MR16 / 37W MR16 IR	120V
377CHX	White frosted glass and chrome flange	Frame Non-IC	302MRLX	50W MR16 / 37W MR16 IR	120V
		Frame Non-IC	302MREX	50W MR16 / 37W MR16 IR	120V
		Frame Non-IC	302MRSPX	50W MR16 / 37W MR16 IR	120V
		Frame IC	302MRIC7SPX	37W MR16 IR	120V
		Frame IC	302MRIC9SPX	50W MR16 / 37W MR16 IR	120V
		Lytening Frame AirSeal®	302MRAICSPX	50W MR16 / 37W MR16 IR	120V
		Lytening Frame AirSeal®	302MRAICEX	50W MR16 / 37W MR16 IR	120V

Features

1. **Housing:** 25 ga steel. Black painted finish.
2. **Residence Mounting Clips:** Factory-installed; zinc plated spring steel; free-hand installation.
3. **Flange:** Die-cast aluminum 0.060" (1.5mm) thick. White finish.
4. **Glass:** Frosted glass.
5. **Gasket:** Seal unit for shower applications.
6. **Lampholder Support:** 27ga. steel.
7. **Mounting Clips (2):** 24 ga. spring steel, zinc plated. Provides easy snap-in / snap-out action.

Accessories

- 2" (51mm) dia. **Glass Colour Filters:** See ADF2 Specification Sheet.
- 2" (51mm) dia. **Specialized Filters:** See AF2 Specification Sheet.
- Square Faceplates**
- 300SQBK Black
- 300SQWH White


Frame-in Kit

See Frame-In Kit specification sheets for more details.

Marking

cCSAus Certified, suitable for wet locations.

Job Information	Type:
Job Name:	
Cat. No.:	
Lamp(s):	
Notes:	

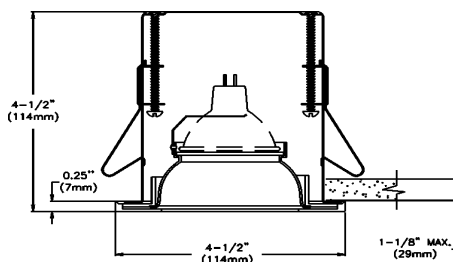

Le luminaire complet comprend la garniture et le cadre de montage : choisir chacun séparément.

Garniture du Réflecteur		Cadre de montage		Lampe	Voltage
377WHX	Verre givré blanc et bordure blanche	Rénovation Non-IC	300MRSPX	50W MR16 / 37W MR16 IR	120V
377CHX	Verre givré blanc et bordure chrome	Rénovation Non-IC	3401MREX	50W MR16 / 37W MR16 IR	120V
		Cadre Non-IC	302MRLX	50W MR16 / 37W MR16 IR	120V
		Cadre Non-IC	302MREX	50W MR16 / 37W MR16 IR	120V
		Cadre Non-IC	302MRSPX	50W MR16 / 37W MR16 IR	120V
		Cadre IC	302MRIC7SPX	35W MR16 IR	120V
		Cadre IC	302MRIC9SPX	50W MR16 / 37W MR16 IR	120V
		Lytening Cadre AirSeal®	302MRAICSPX	50W MR16 / 37W MR16 IR	120V
		Lytening Cadre AirSeal®	302MRAICEX	50W MR16 / 37W MR16 IR	120V

Description

- Boîtier** : en acier galvanisé 25ga.
- Attaches de montage Résidence** : pré-assemblé en usine. Ressort en acier plaqué zinc. Le luminaire tient en place dans le plafond sans besoin de le retenir pendant l'ajustement.
- Bordure** : en aluminium moulé sous pression de 0.060 po (1.5mm) d'épaisseur. Fini blanc
- Verre** : verre givré.
- Joint d'étanchéité** : permet l'étanchéité de l'appareil pour les applications de douches.
- Support du boîtier de lampe** : en acier de calibre 27ga.
- Attaches de montage (2)** : ressort en acier inoxydable de calibre 24. Facile à enlever et à remettre en place.

Cadre de Montage

Pour les caractéristiques des cadres de montage, voir les fiches techniques appropriées.

Marquage

Certifié cCSAus ; convient aux endroits mouillés.

Accessoires

Filtres colorés en verre de 2 po (51mm) dia. : voir la feuille de spécification ADF2.

Filtres spécialisées de 2 po (51mm) dia. : voir la feuille de spécification AF2.

Plaques de montages carrées

300SQBK

300SQWH

Information Projet

Type:

Nom Projet:

No. Cat.:

Lampe(s):

Notes: