

RPNP PLASTIC RUNNING MAN

The RPNP series of commercial or decorative plastic running man signs is designed using durable and lightweight high impact thermoplastic.



FEATURES & SPECIFICATIONS

CIRCUITRY - AC & AC/DC

- LED ultra bright light source
- 120/347 VAC Input, field selectable
- 120 V / 0.28 A 2.30 W;
347 V / 0.31 A 2.75 W max power consumption
- Emergency DC wattages as follows:
6 VDC = 1.42 W
12 VDC = 1.42 W
24 VDC = 1.42 W

CIRCUITRY - SELF-POWERED

- LED ultra bright light source
- 120 / 347 VAC Input, field selectable
- 120 V / 0.46 A 4.01 W;
347 V / 0.37 A 3.51 W max power consumption
- Ambient temperature 10°C to 35°C
- High-performance, sealed Ni-Cad battery

- 90 Minutes emergency duration (standard)
- Solid state transfer and battery charger

MECHANICAL





- High impact, UV stabilized, thermoplastic construction
- Quick snap faceplates and universal canopy for rapid and simple installation
- Flush wall mount backplate included

APPROVALS

- CSA Certified to C22.2 #141.15, C860

COMPLIANCE

- Meets requirements of ICES-005

OVERVIEW			
LIGHT SOURCE	LED	DC POWER (W)	1.42
INPUT VOLTAGE (VAC)	120/347		
DC VOLTAGE (VDC)	6, 12, 24		
<div>  QUICKSHIP  LED  ICES 005  SP Energy Verified <small>Energy Verified Energie Vérifiée</small> </div>			

QUICK SHIP GUIDE

PART NUMBER	DC VOLTS [VDC]	NBR OF FACES	LIGHT SOURCE	INPUT VOLTS [VAC]	COLOR
RPNPUWHT-BAT	BAT	UNIVERSAL	LED	120/347	WHITE
RPNPUWHT-UNVDC	UNVDC	UNIVERSAL	LED	120/347	WHITE

Quick ship product availability is subject to change without notice. Please contact your AimLite customer service representative to confirm inventory levels at time of order.

ORDERING GUIDE

RPNP	U	WHT	-	/
SERIES	NBR OF FACES - MOUNTING	COLOR	DC OUTPUT [VDC]	OPTIONS ¹
RPNP	U - UNIVERSAL	WHT - WHITE	UNVDC - UNIVERSAL DC BACKUP VOLTAGE FROM 6 TO 24 BAT - SELF-POWERED FOR 90 MINUTES	0 - NO INDICATORS (DOUBLE FACE ONLY)


¹ For detailed options descriptions, please consult the options page

WIREGUARD¹


	PART NUMBER	DIMENSIONS (IN)
WALL MOUNT	WGD540	14.5 X 10.5 X 6.25
CEILING MOUNT	WGD590	15.25 X 6.75 X 14.25
END MOUNT	WGD650	13.75 X 16.5 X 12.25

¹ Please contact AimLite customer service representative for more information

DIMENSIONS

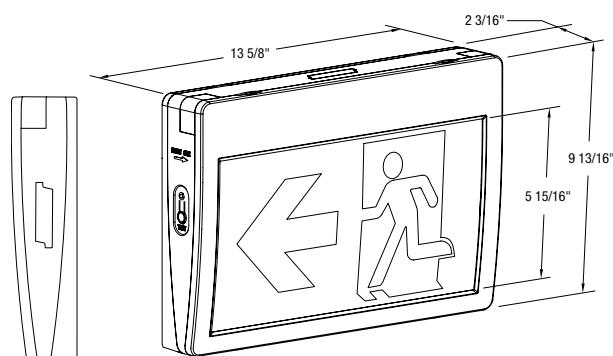

Flush mount

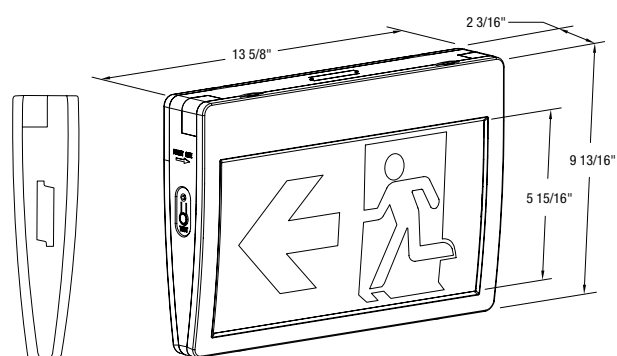

Tapered mount



Comes standard with three pictogram legends for direction selection.



For double face no arrow options, select "0" on the options column.