

ASKS

KICK SPACE HEATER



HIDE 'N HEAT

“Hide 'n heat” is what the SKS kick space heater by °STELPRO offers. Its sleek, redesigned grille is slimmer than ever for easy installation in narrow spaces under kitchen or bathroom cabinets or in stair risers. Enjoy comfortable forced-air heating from the most discreet fan heater on the market.

POWER SELECTOR SWITCH

EASY INSTALLATION

ATTRACTIVE GRILLE ONE-PIECE, FRAMELESS

COLORS

- **standard:** white, soft white
- **luxury finish:** stainless steel (see price list)
- **ORORA (optional):** refer to www.stelpro.com/en-CA/orora

FINISH

- epoxy-polyester powdercoat or stainless steel

MANUFACTURING

- 22-gauge steel cabinet and 16-gauge steel front
- quiet, 50 CFM capacity
- thermal protection with automatic reset
- added protection provided by a fuse-link (must be replaced once activated)

WATTAGE AND VOLTAGE

- power selector switch

ELEMENT

- tubular element sheathed with spiral-wound fins for improved heat dissipation

CONTROL

- wall thermostat (not included) – the use of an electronic thermostat is strongly recommended
- built-in thermostat (optional)

INSTALLATION

- recessed

WARRANTY

- five years, *three years on electronic components

IDEAL FOR:

under a kitchen or bathroom cabinet, in a stair riser

°STELPRO

°STELPRO reserves the right to modify descriptions, manufacturing specifications or prices without prior notice. Returns are not accepted for orders of products with optional colors. For all the latest models and prices, please refer to our website at www.stelpro.com.



FC_SKS_US_110518




TECHNICAL SPECIFICATIONS

PRODUCT	POWER	VOLTAGE	THROW DISTANCE (IN FRONT)	HEAT RISE	WEIGHT
CODE	WATTS	VOLTS	FT.	°F	LB
ASKS1001	500 OR 1000	120	4	99	10
ASKS1002	500/375 OR 1000/750	240/208	4	99	10

Add W for white, SW for soft white or SS for stainless steel (consult the optional colours chart or contact your °STELPRO representative for all other colours).

TECHNICAL DRAWINGS

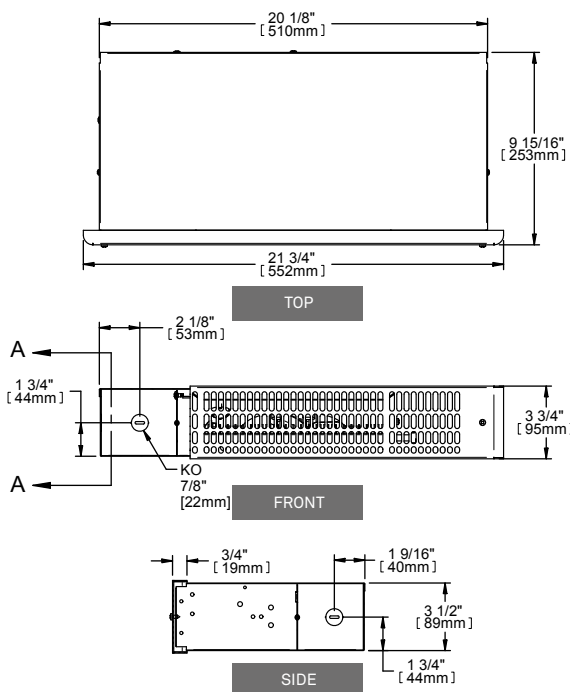

ACCESSORIES

PRODUCT	DESCRIPTION
SKST1	built-in single pole thermostat
SKST2	built-in tamper-proof double pole thermostat
SKSR*	extended grille (23 5/8 in. x 3 3/4 in. – 600 mm x 95 mm) allows to cover gaps or imperfections for a renovation project
SKSRSS	extended stainless steel grille (23 5/8 in. x 3 3/4 in. – 600 mm x 95 mm) allows to cover gaps or imperfections for a renovation project

* Add W for white or SW for soft white.