


Wire Strippers/Cutters

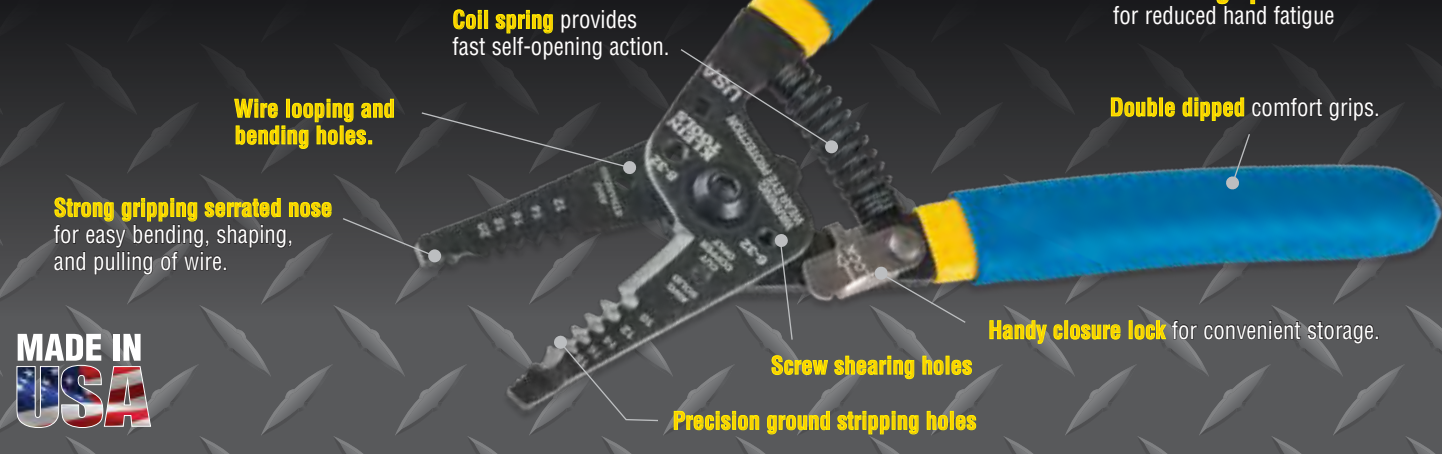

Wire Strippers/Cutters

Includes Klein-Kurve™ core features plus:

- Easy-to-read markings
- Precision shear-type blades
- Cat. No. 11054GLW features glow in the dark grips to easily locate your tool in dark or low lit areas



11054

Cat. No.	Strips and Cuts	Screw Shearing	Overall Length	Handle Color	Weight
11053	6 - 12 AWG Stranded (10 mm ² - 2.5 mm ²)	6-32 and 8-32	7-1/8" (181.0 mm)	Blue/Red	0.34 lb (0.15 kg)
11054	8 - 16 AWG Solid (8.4 mm ² - 1.3 mm ²), 10 - 18 AWG Stranded (5.3 mm ² - 0.82 mm ²)	6-32 and 8-32	7-1/8" (181.0 mm)	Blue/White	0.34 lb (0.15 kg)
11054GLW	8 - 16 AWG Solid (8.4 mm ² - 1.3 mm ²), 10 - 18 AWG Stranded (5.3 mm ² - 0.82 mm ²)	6-32 and 8-32	7-1/8" (181.0 mm)	Glow in the Dark	0.34 lb (0.15 kg)
11055	10 - 18 AWG Solid (4.0 mm ² - 0.75 mm ²), 12 - 20 AWG Stranded (2.5 mm ² - 0.50 mm ²)	6-32 and 8-32	7-1/8" (181.0 mm)	Blue/Yellow	0.34 lb (0.15 kg)
11057	20 - 30 AWG Solid (0.50 mm ² - 0.14 mm ²), 22 - 32 AWG Stranded (0.34 mm ² - 0.05 mm ²)	6-32 and 8-32	7-1/8" (181.0 mm)	Blue/Red	0.32 lb (0.15 kg)

Long-Nose Wire Stripper/Crimper

Includes Klein-Kurve™ core features plus:

- Crimps insulated and non-insulated connectors
- Tip designed to grab, pull and bend the smallest of wires
- Reinforced head (patent-pending design) reduces flex
- Optimized for ideal leverage when stripping and crimping
- Precision shear-type cutting blades for easier cutting
- Do no use to cut steel wire



1009

Cat. No.	Strips and Cuts	Bolt Size	Crimping Capacity	Overall Length	Handle Color	Weight
1009 NEW!	10 - 20 AWG Solid; 12 - 22 AWG Stranded	6 - 32 and 8 - 32	10 - 22 AWG (4.0 mm ² - 0.34 mm ²)	7-3/4" (196.9 mm)	Gray/Yellow	0.34 lb (0.15 kg)

