

# 1-Gang weatherproof boxes

## 1-Gang boxes


### Product description

Cast aluminum FS boxes  
Non-metallic FS boxes


### Cast aluminum weatherproof FS boxes

#### Features

- Electrostatically painted with a baked, weather-resistant powder finish for exceptional durability
- Accept single gang weatherproof cover and standard FS covers
- UL Listed for wet and damp locations with appropriate cover installed
- Mounting lugs provide strength and durability on any mounting surface
- Raised knockout studs on back of box provide alternative means for wall mounting. Strike desired studs with sharp hammer blow for clean mounting holes
- Easy access ground screw hole located inside back wall of box
- Threaded outlets for conduit and connectors
- Two closure plugs and mounting lugs furnished

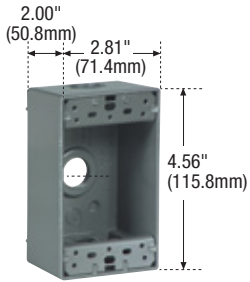

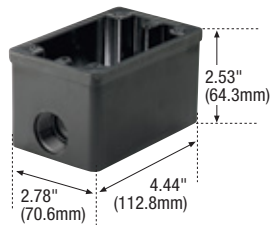


1113




6080

### 1-Gang FS boxes


Description	End openings	Back openings	Catalog no.		
3 hole 0.50" (12.70mm) dia.	1-1	1	□ 1113	•	•
4 hole 0.50" (12.70mm) dia.	2-1	1	□ 1114	•	•
5 hole 0.50" (12.70mm) dia.	2-2	1	□ 1115	•	•
3 hole 0.75" (19.05mm) dia.	1-1	1	□ 1116	•	•
5 hole 0.75" (19.05mm) dia.	2-2	1	□ 1118	•	•

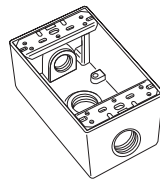


1113

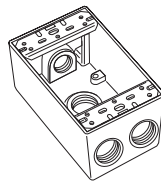


1114

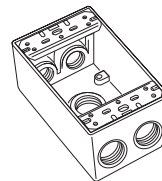

1115

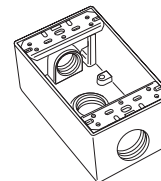

1116

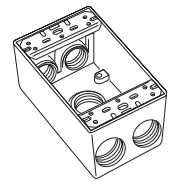

1118

### Non-metallic weatherproof 1-Gang FS boxes

Description	Color	Catalog no.
FS Box with (2) 0.75" (19.05mm) IPS molded-in knockouts	BK	□ 6080

### Color information:

BK (Black)



(Black)

Compliances, specifications and availability are subject to change without notice.

 Indicates NAFTA compliant - Page Q-32

 RoHS compliant - Page Q-32