




Quality Products. Service Excellence.

# Inner Panels

## 1418FS and HN4FS Series Enclosures



- Formed from 10 gauge or 12 gauge steel.
- All double door width panels are 10 gauge steel.
- Width panels are available in full or half height.
- Depth panels are available in full height only.
- Depth and width panels are provided with all mounting hardware and center support where required.
- Half panel can be mounted in the top or bottom half of the enclosure.
- Finished in white.

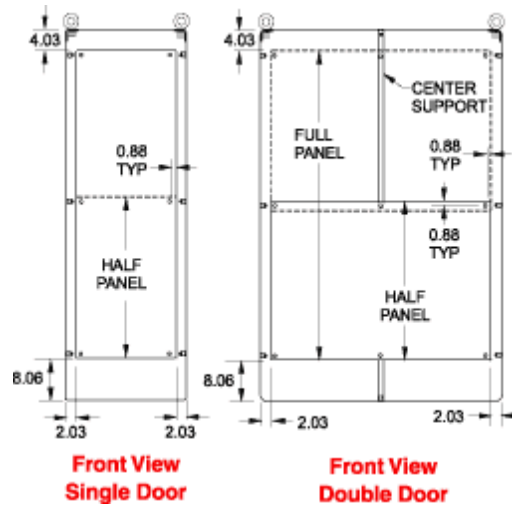

### Single Door Width Panels

Steel		Galv. Steel			
Part No.	Part No.	Description	Enclosure Size	Panel	
60TWF	60TWF	Full Panel	60 x 24	48.00 x 20	
60TWH	60TWH	Half Panel		24.87 x 20	
72WF	72WF	Full Panel	72 x 24	60.00 x 20	
72WH	72WH	Half Panel		30.87 x 20	
90YWF	90YWF	Full Panel	90 x 24	78.00 x 20	
90YWH	90YWH	Half Panel		39.87 x 20	
72XF	72XF	Full Panel	72 x 30	60.00 x 26	
72XH	72XH	Half Panel		30.87 x 26	
60TYF	60TYF	Full Panel	60 x 36	48.00 x 32	
60TYH	60TYH	Half Panel		24.87 x 32	
72YF	72YF	Full Panel	72 x 36	60.00 x 32	
72YH	72YH	Half Panel		30.87 x 32	
90YF	90YF	Full Panel	90 x 36	78.00 x 32	
90YH	90YH	Half Panel		39.87 x 32	

### Double Door Width Panels

Steel		Galv. Steel	
-------	--	-------------	--

Steel Part No.	Galv. Steel Part No.	Description	Enclosure	Panel Size
<b>60AWFW</b>	<b>60AWFWG</b>	Full Panel	60 x 48	48.00 x 44
<b>60AHW</b>	<b>60AHWG</b>	Half Panel		24.88 x 44
<b>72ZFW</b>	<b>72ZFWG</b>	Full Panel	72 x 48	60.00 x 44
<b>72ZHW</b>	<b>72ZHWG</b>	Half Panel		30.88 x 44
<b>72ZFW</b>	<b>72ZFWG</b>	Full Panel	72 x 60	60.00 x 56
<b>72ZHW</b>	<b>72ZHWG</b>	Half Panel		30.88 x 56
<b>72ZYFW</b>	<b>72ZYFWG</b>	Full Panel	72 x 72	60.00 x 68
<b>72ZYHW</b>	<b>72ZYHWG</b>	Half Panel		30.88 x 68
<b>90BFW</b>	<b>90BFWG</b>	Full Panel	90 x 48	78.00 x 44
<b>90BHW</b>	<b>90BHWG</b>	Half Panel		39.88 x 44
<b>90BYFW</b>	<b>90BYFWG</b>	Full Panel	90 x 72	78.00 x 68
<b>90BYHW</b>	<b>90BYHWG</b>	Half Panel		39.88 x 68

### Depth Panels

Part No.	Encl. Height	Encl. Min Depth	Panel W	Panel H
<b>60FD14</b>	60.00	18.00	14.00	48.00
<b>72FD9</b>	72.00	18.00	9.00	60.00
<b>72FD14</b>	72.00	18.00	14.00	60.00
<b>72FD20</b>	72.00	24.00	20.00	60.00
<b>72FD26</b>	72.00	36.00	26.00	60.00
<b>90FD9</b>	90.00	18.00	9.00	78.00
<b>90FD14</b>	90.00	18.00	14.00	78.00
<b>90FD20</b>	90.00	24.00	20.00	78.00
<b>90FD26</b>	90.00	36.00	26.00	78.00

*Data subject to change without notice*