


MSHD-LTB

[Print View..](#)
[Print to Pdf..](#)

General Information

Extended Product Type:	MSHD-LTB
Product ID:	1SAM201920R1011
EAN:	4013614441820
Catalog Description:	MSHD-LTB Handles
Long Description:	MSHD-LTB Handle, IP64, black, 3 times lockable, defeatable, 0-TRIP-I Suitable for Manual Motor Starter

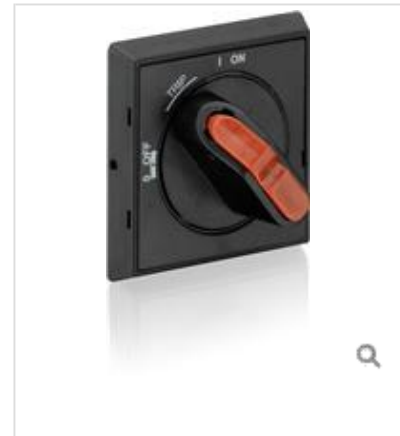

Categories

Products » Low Voltage Products and Systems » Control Products » Manual Motor Starters » Manual Motor Starters Accessories

Accessories [Show accessory images](#)

Ordering

EAN:	4013614441820
Minimum Order Quantity:	1 piece
Customs Tariff Number:	85389099

Container Information

Package Level 1 Width:	130.0 mm
Package Level 1 Length:	70.0 mm
Package Level 1 Height:	170.0 mm
Package Level 1 Gross Weight:	0.100 kg
Package Level 1 Units:	1 piece

Dimensions

Product Net Width:	65.6 mm
Product Net Height:	65.5 mm
Product Net Depth:	57.9 mm
Product Net Weight:	0.065 kg

Technical

Contact Position Indication:	ON / OFF / TRIP
Actuator Type:	Rotary Handle
Shaft Diameter:	6x6 mm
Color:	black
Degree of Protection:	IP64
Tightening Torque:	0.12 N·m
Product Name:	Handles
Suitable for Product Class:	Manual Motor Starters

Environmental

RoHS Status:	Following EU Directive 2002/95/EC August 18, 2005 and amendment
---------------------	---

Technical UL/CSA

Enclosure Type UL/CSA:	1 12 3R
Tightening Torque UL/CSA:	1.06 in·lb

Certificates and Declarations (Document Number)

Declaration of Conformity - CE:	1SAD938501-0188 1SAD938502-0183 1SAD938506-0125
RoHS Information:	1SAA963001-4407
