


# SWITCHES

## Specification Grade Decorator Switches 15 & 20A, 120/277 & 347VAC; 20A, 120VAC

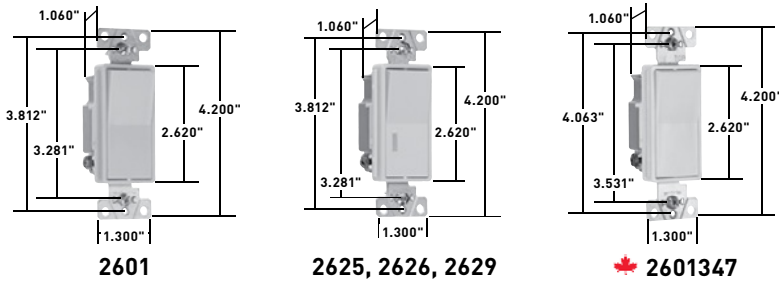

### Features

- Impact-resistant polycarbonate back body and frame.
- Cushioned thermoplastic paddle assures smooth, quiet long-term operation.
- Unique single rocking butterfly contact provides long-term consistent performance with significantly fewer moving parts.
- Internal screw-pressure-plate back and side wire capability for easy installation with #14 - #10 AWG stranded or solid copper/copper clad wire. Terminals made of high conductivity brass and serrated for maximum wire gripping.
- Silver alloy contacts integrally formed to the butterfly actuator assures reliable performance.
- Integral auto-ground clip for positive ground to metal boxes.
- Tri-drive ground, terminal and mounting screws. All terminal screws backed out, ready-to-install.

CATALOG NUMBER				RATING			3rd PARTY COMPLIANCE	
SINGLE POLE	DOUBLE POLE	THREE-WAY	FOUR-WAY	A.	VAC	COLOR	UL20	C22.2 111
<b>SPECIFICATION GRADE DECORATOR SWITCHES BACK &amp; SIDE WIRE</b>								
26011		2603I	2604I	15	120/277	Ivory	•	•
2601W		2603W	2604W	15	120/277	White	•	•
2601GRY		2603GRY		15	120/277	Gray	•	•
2601BK		2603BK		15	120/277	Black	•	•
2601LA		2603LA	2604LA	15	120/277	Light Almond	•	•
2621I	2622I	2623I	2624I	20	120/277	Ivory	•	•
2621W	2622W	2623W	2624W	20	120/277	White	•	•
2621	2622	2623	2624	20	120/277	Brown	•	•
2621GRY	2622GRY	2623GRY	2624GRY	20	120/277	Gray	•	•
2621BK	2622BK	2623BK	2624BK	20	120/277	Black	•	•
2621RED		2623RED	2624RED	20	120/277	Red	•	•
2621LA	2622LA	2623LA	2624LA	20	120/277	Light Almond	•	•
<b>ILLUMINATED DECORATOR SWITCHES (LIGHTED WHEN OFF) BACK &amp; SIDE WIRE</b>								
2625I		2626I	2628I	20	120	Ivory	•	•
2625W		2626W	2628W	20	120	White	•	•
2625				20	120	Brown	•	•
2625RED				20	120	Red	•	•
2625LA		2626LA	2628LA	20	120	Light Almond	•	•
<b>PILOT LIGHTED DECORATOR SWITCHES (LIGHTED WHEN ON) BACK &amp; SIDE WIRE</b>								
2629I				20	120	Ivory	•	•
2629W				20	120	White	•	•
2629LA				20	120	Light Almond	•	•

For Bulk Packaging Solutions consult factory.

CATALOG NUMBER			RATING		3rd PARTY COMPLIANCE		
SINGLE POLE	THREE-WAY	FOUR-WAY	A.	VAC	COLOR	UL20	C22.2 111
<b>SPECIFICATION GRADE DECORATOR SWITCHES BACK &amp; SIDE WIRE</b>							
2601347I	2603347I		15	347	Ivory	•	•
2601347W	2603347W		15	347	White	•	•
2601347GRY			15	347	Gray	•	•
2601347LA			15	347	Light Almond	•	•
2621347I	2623347I	2624347I	20	347	Ivory	•	•
2621347W	2623347W	2624347W	20	347	White	•	•
2621347GRY	2623347GRY		20	347	Gray	•	•
2621347BK	2623347BK		20	347	Black	•	•
2621347RED	2623347RED		20	347	Red	•	•
2621347LA	2623347LA	2624347LA	20	347	Light Almond	•	•


Denotes Canadian catalog number. All Canadian products have Combination Slotted/Robertson Head Brass Screws.

All devices listed on this page conform to NEMA WD-1 and WD-6.


# SWITCHES




## Decorator & Specification Grade Momentary & Maintained Contact Switches 15A, 120 & 120/277VAC

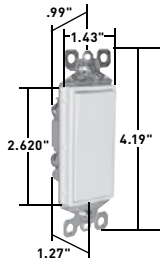

**TM870STMLACC6**

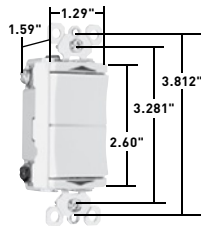

**Momentary Contact**

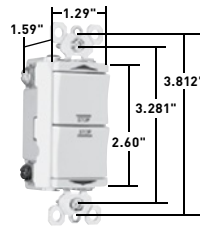

**Maintained Contact**

### Features

- Designer-style satin-finish rocker.
- High-impact resistant thermoplastic construction.
- External screw-pressure-plate back and side wired. Accepts #12 and #14 AWG.
- Push wire #14 AWG.
- Narrow back body leaves more room for wires in the box.
- Extra-long, through-body strap eliminates floating installations and imperfect applications.
- Smooth, quiet paddle action.
- Easy-access green hex head ground screw.
- Tri-drive ground, terminal and mounting screws.

CATALOG NUMBER	RATING		COLOR	3rd PARTY COMPLIANCE	
	A.	VAC		UL20	C22.2 111
<b>SINGLE POLE DECORATOR MOMENTARY CONTACT SWITCHES</b>					
TM870STMWCC6	15	120/277	White	•	•
TM870STMBKCC6	15	120/277	Black	•	•
M870STMLACC6	15	120/277	Light Almond	•	•


### Features

- Unique "Up/Down" switches match the look and feel of standard decorator switches.
- Impact-resistant face and body.
- Side and external screw-pressure-plate back wire accepts #12 and #14 AWG.
- All screws are tri-drive.
- Full wraparound heavy-gauge steel strap is plated for corrosion resistance and features lock-in tabs.
- Patent-pending split circuit tab – easily accessible, and can be reinstalled without a tool.

CATALOG NUMBER	RATING		COLOR	3rd PARTY COMPLIANCE		
	A.	VAC		cULus	UL20	UL508
<b>SPECIFICATION GRADE DOUBLE THROW MOMENTARY CONTACT SWITCHES</b>						
TM811DTMOI	15	120	Ivory	•		•
TM811DTMOW	15	120	White	•		•
TM811DTMOBK	15	120	Black	•		•
TM811DTMOLA	15	120	Light Almond	•		•
<b>SPECIFICATION GRADE DOUBLE THROW MAINTAINED CONTACT SWITCHES</b>						
TM811DTMAI	15	120	Ivory	•	•	
TM811DTMAW	15	120	White	•	•	
TM811DTMABK	15	120	Black	•	•	
TM811DTMALA	15	120	Light Almond	•	•	

# SWITCHES

## TradeMaster® Grounding Toggle Switches 15A, 120VAC

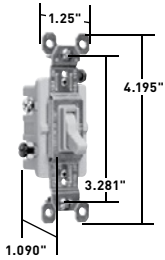

6631G

### Features

- Thermoplastic toggle and frame.
- Extra-long strap.
- High-impact resistant construction.
- Side wire #12 and #14 AWG; push wire #14 AWG.
- Tri-drive ground, terminal and mounting screws.
- Easy-access green hex head ground screw.
- Smooth, quiet toggle action.

CATALOG NUMBER	RATING		COLOR	3rd PARTY COMPLIANCE		
	A.	VAC		UL20	FSUL WS896	CSB C22.2 111
<b>SINGLE POLE TOGGLE SWITCHES GROUNDING</b>						
660IG*	15	120	Ivory	•		•
660WG*	15	120	White	•		•
660G*	15	120	Brown	•		•
660BKG	15	120	Black	•		•
660LAG*	15	120	Light Almond	•		•
<b>SINGLE POLE TOGGLE SWITCHES GROUNDING (WITHOUT EARS)</b>						
660IGMH	15	120	Ivory	•		•
660WGMH	15	120	White	•		•
660GMH	15	120	Brown	•		•
<b>NAFTA-COMPLIANT SINGLE POLE TOGGLE SWITCHES GROUNDING</b>						
660NAIG	15	120	Ivory		•	
660NAWG	15	120	White		•	
660NAG	15	120	Brown		•	
660NABKG	15	120	Black		•	
660NALAG	15	120	Light Almond		•	
<b>THREE-WAY TOGGLE SWITCHES GROUNDING</b>						
6631G**	15	120	Ivory	•		•
663WG**	15	120	White	•		•
663G**	15	120	Brown	•		•
663BKG	15	120	Black	•		•
663LAG**	15	120	Light Almond	•		•
<b>NAFTA-COMPLIANT THREE-WAY TOGGLE SWITCHES GROUNDING</b>						
6631G	15	120	Ivory		•	
663WG	15	120	White		•	
663G	15	120	Brown		•	
663BKG	15	120	Black		•	
663LAG	15	120	Light Almond		•	
<b>FOUR-WAY TOGGLE SWITCHES GROUNDING</b>						
6641G	15	120	Ivory	•		•
664WG	15	120	White	•		•
664G	15	120	Brown	•		•
664BKG	15	120	Black	•		•
664LAG	15	120	Light Almond	•		•
* 664ICN	15	120	Ivory	•		•
* 664WCN	15	120	White	•		•
<b>NAFTA-COMPLIANT FOUR-WAY TOGGLE SWITCHES GROUNDING</b>						
6641G	15	120	Ivory		•	
664WG	15	120	White		•	
664G	15	120	Brown		•	
664BKG	15	120	Black		•	
664LAG	15	120	Light Almond		•	

\* Denotes Canadian catalog number. All Canadian products have Combination Slotted/Robertson Head Brass Screws.

\* Available in bulk packs of 120. Add "U" to end of Catalog Number. Example: 660WGU.

\*\* Available in bulk packs of 90. Add "U" to end of Catalog Number. Example: 663WGU.

NAFTA-Compliant Switches are ideal for use on projects subject to the provisions of the Buy American Act.

All devices listed on this page conform to NEMA WD-1 and WD-6.