



# SURGE PROTECTIVE & ISOLATED GROUND DEVICES


## Isolated Ground Receptacles 2 Pole, 3 Wire Grounding 15 & 20A, 125 & 250V

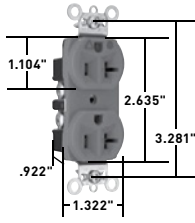


IG8300

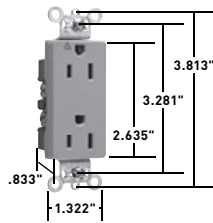

IG26262GRY



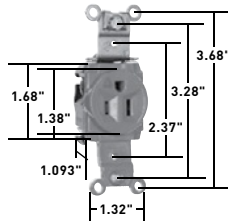


IG5261

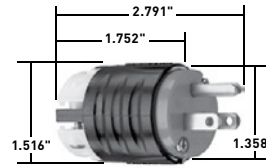

PSIG5266X

CATALOG NUMBER		RATING		NEMA CONFIG. NO.	COLOR	3rd PARTY COMPLIANCE		
SPEC GRADE	HOSPITAL GRADE	A.	V.			UL498	FSUL WC596	C22.2 No. 42
<b>DUPLEX RECEPTACLES BACK &amp; SIDE WIRE</b>								
IG5262I	IG8200I	15	125	5-15R	Ivory	•	•	•
IG5262W		15	125	5-15R	White	•	•	•
IG5262	IG8200	15	125	5-15R	Orange	•	•	•
IG5262GRY		15	125	5-15R	Gray	•	•	•
IG5262RED	IG8200RED	15	125	5-15R	Red	•	•	•
IG5262LA		15	125	5-15R	Light Almond	•	•	•
IG5362I	IG8300I	20	125	5-20R	Ivory	•	•	•
IG5362W	IG8300W	20	125	5-20R	White	•	•	•
IG5362	IG8300	20	125	5-20R	Orange	•	•	•
IG5362GRY		20	125	5-20R	Gray	•	•	•
IG5362BK		20	125	5-20R	Black	•	•	•
IG5362RED	IG8300RED	20	125	5-20R	Red	•	•	•
IG5362LA	IG8300LA	20	125	5-20R	Light Almond	•	•	•
IG5362BL		20	125	5-20R	Blue	•	•	•
IG5662		15	250	6-15R	Orange	•	•	•
IG5862	IG8800	20	250	6-20R	Orange	•	•	•
	IG8800LA	20	250	6-20R	Light Almond	•	•	•
<b>DECORATOR DUPLEX RECEPTACLES BACK &amp; SIDE WIRE</b>								
IG26262I		15	125	5-15R	Ivory	•	•	•
IG26262W	IG26262HGW	15	125	5-15R	White	•	•	•
IG26262	IG26262HG	15	125	5-15R	Orange	•	•	•
IG26262GRY		15	125	5-15R	Gray	•	•	•
IG26262BK		15	125	5-15R	Black	•	•	•
IG26262RED	IG26262HGRE	15	125	5-15R	Red	•	•	•
IG26262LA		15	125	5-15R	Light Almond	•	•	•
IG26362I		20	125	5-20R	Ivory	•	•	•
IG26362W	IG26362HGW	20	125	5-20R	White	•	•	•
IG26362	IG26362HG	20	125	5-20R	Orange	•	•	•
IG26362GRY		20	125	5-20R	Gray	•	•	•
IG26362BK	IG26362HGBK	20	125	5-20R	Black	•	•	•
IG26362RED	IG26362HGRE	20	125	5-20R	Red	•	•	•
IG26362LA		20	125	5-20R	Light Almond	•	•	•
<b>SINGLE RECEPTACLES BACK &amp; SIDE WIRE</b>								
IG5261		15	125	5-15R	Orange	•	•	•
IG5361	IG8301	20	125	5-20R	Orange	•	•	•

 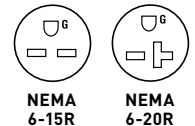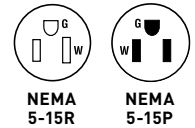

CATALOG NUMBER	RATING		NEMA CONFIG. NO.	CORD DIAMETER	3rd PARTY COMPLIANCE		
	A.	V.			UL498	FSUL WC596	C22.2 No. 42
<b>STRAIGHT BLADE PLUGS, ORANGE</b>							
PSIG5266X	15	125	5-15P	.230" - .720"	•	•	•

Consult Straight Blade Section F for complete line of Straight Blade Plugs & Connectors.

For Wall Plates for Isolated Ground Systems, consult Wall Plates Section P.

For Bulk Packaging Solutions consult factory.

All devices listed on this page conform to NEMA WD-1 and WD-6.