

# Premium LED bulbs Vintage Filament

## 5ST19/VIN/822/E26/CL-A/DIM BC 1PK

Featuring a classic heritage design, the new Philips Vintage LED lamp family is reminiscent of familiar incandescent bulbs. Available in an array of giant shapes, candles and other familiar form factors, they provide a seamless fit across your space. When used as a statement piece, they add a sense of nostalgia and create a highly desirable atmosphere for socialization and relaxing.

### Product data

General Information	
Cap-Base	E26 [ Single Contact Medium Screw]
Nominal Lifetime (Nom)	15000 h
Switching Cycle	20000X
Technical Type	5-40W
Light Technical	
Color Code	822 [ CCT of 2200K]
Luminous Flux (Nom)	350 lm
Luminous Flux (Rated) (Nom)	350 lm
Color Designation	Flame
Correlated Color Temperature (Nom)	2200 K
Luminous Efficacy (rated) (Nom)	70.00 lm/W
Color Consistency	<6
Color Rendering Index (Nom)	80
LLMF At End Of Nominal Lifetime (Nom)	70 %
Operating and Electrical	
Input Frequency	60 Hz
Power (Rated) (Nom)	5 W


Lamp Current (Nom)	50 mA
Wattage Equivalent	40 W
Starting Time (Nom)	0.5 s
Warm Up Time to 60% Light (Nom)	0.5 s
Power Factor (Nom)	0.7
Voltage (Nom)	120 V
Temperature	
T-Case Maximum (Nom)	52 °C
Controls and Dimming	
Dimmable	Yes
Mechanical and Housing	
Bulb Finish	Amber
Product Data	
Order product name	5ST19/VIN/822/E26/CL-A/DIM BC 1PK
EAN/UPC - Product	046677470401
Order code	929001334403

## Premium LED bulbs Vintage Filament

Numerator - Quantity Per Pack	1
Numerator - Packs per outer box	4
Material Nr. (12NC)	929001334403

Net Weight (Piece)	0.060 kg
--------------------	----------

### Dimensional drawing

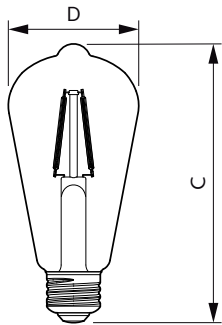

Product	D	C
5ST19/VIN/822/E26/CL-A/DIM BC 1PK	64 mm	138 mm

Bulb ST19 120V 5-40W 400lm 2000K D Amber

